


TABLE A

PART NO	LENGTH
ZL-C0-CBL11-1P	1000mm [3.3 ft]
ZL-C0-CBL11-2P	2000mm [6.6 ft]

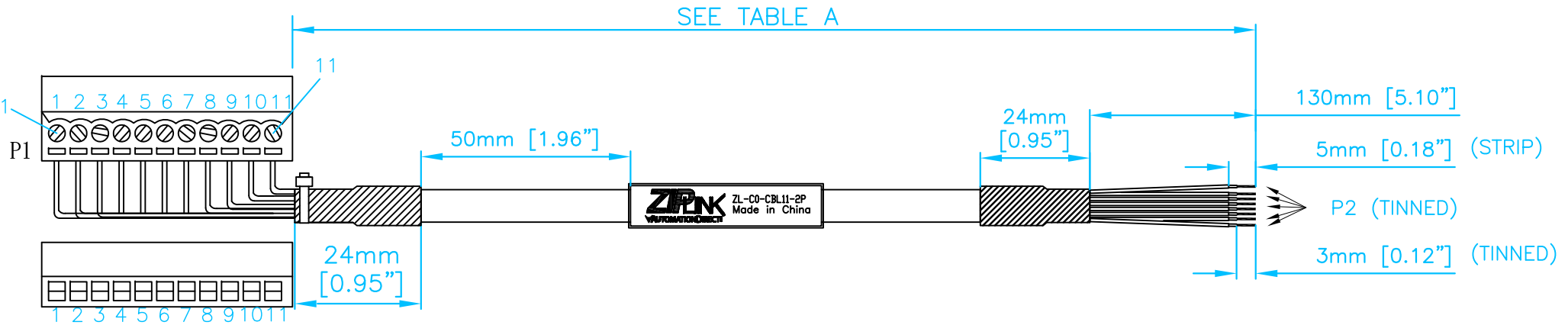

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	BLACK RED	7	ORANGE/WHITE GREEN/WHITE
2	ORANGE GREEN	8	PURPLE/WHITE GRAY/BLACK
3	PURPLE YELLOW	9	GREEN/BLACK WHITE
4	LIGHTGREEN LIGHTBLUE	10	RED/BLACK BROWN
5	PINK BLUE	11	ORANGE/BLACK GRAY
6	BROWN/WHITE RED/WHITE	N. C	BLACK/WHITE
		N. C	YELLOW/BLACK

NOTES:

- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT – 2A per conductor, 40A maximum cable current
- VOLTAGE –
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- P1 CONNECTOR – 11 position terminal block for Click PLC AutomationDirect part # C0-8TB
- P2 CONNECTION – 11 tinned pig-tail leads (only 22 leads are connected to P1, per cable pin-out diagram)
- MINIMUM BEND RADIUS – 65.6 mm [2.58 in]

ZL-C0-CBL11-nP	
Rev: original	Date: 10/2009
Units: mm [inches]	
Scale: none	
ZIPLINK Click PLC Cable	