


TABLE A

PART NO	LENGTH
ZL-CBL50-1P	1.0m [39.37"]
ZL-CBL50-2P	2.0m [78.74"]

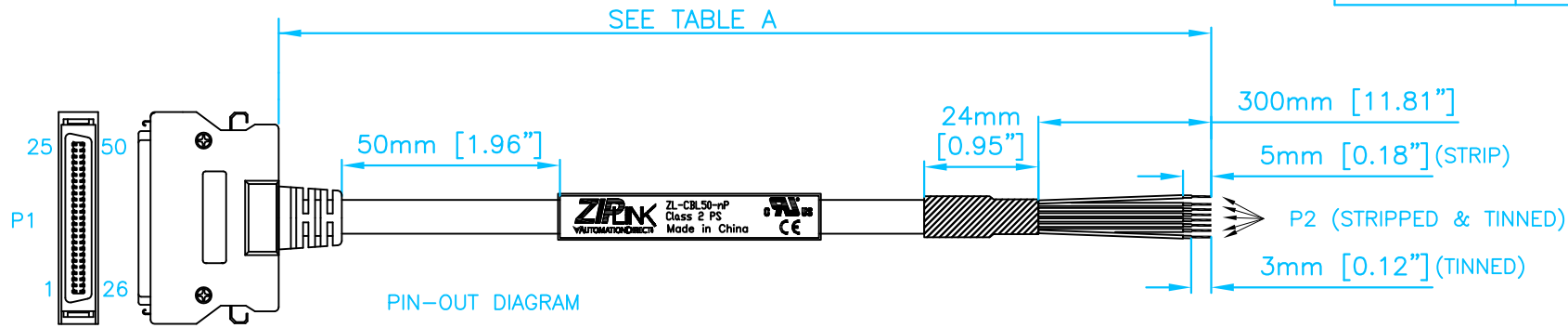

PIN-OUT DIAGRAM

P1	1 ○ Black	P1	14 ○ Pink/Blue
26 ○ Black/White	2 ○ Brown	39 ○ Pink/Green	15 ○ Light Blue
27 ○ Brown/White	3 ○ Red	40 ○ Light Yellow	16 ○ Light Blue/Black
28 ○ Red/White	4 ○ Orange	41 ○ Light Blue/Red	17 ○ Light Blue/Blue
29 ○ Orange/White	5 ○ Yellow	42 ○ Light Blue/Green	18 ○ Grey/Red
30 ○ Yellow/Black	6 ○ Green	43 ○ Grey/Green	19 ○ Blue/Black
31 ○ Green/White	7 ○ Blue	44 ○ Purple/Black	20 ○ Light Green/Black
32 ○ Blue/White	8 ○ Purple	45 ○ Light green/Red	21 ○ Light Green/Blue
33 ○ Purple/White	9 ○ Grey	46 ○ Light Green/Green	22 ○ Light Yellow/Black
34 ○ Grey/Black	10 ○ White	47 ○ Light Yellow/Red	23 ○ Light Yellow/Blue
35 ○ Orange/Black	11 ○ Pink	48 ○ Light Yellow/Green	24 ○ White/Black
36 ○ Red/Black	12 ○ Light Green	49 ○ White/Red	25 ○ White/Blue
37 ○ Green/Black	13 ○ Pink/Black	50 ○ White/green	
38 ○ Pink/Red			

SHELL_BRAID+DRAIN_SHELL

NOTES:

- CABLE – 50 conductor, 28 AWG, black PVC jacket insulation rating 80°C (176°F), 30V
- VOLTAGE –
AC/DC rated operating voltage 24V
AC/DC maximum voltage 30V
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- P1 CONNECTOR –
HPCN-50M MALE PIN/5U"BLACK
NICKEL-SHELL PH:1.27
IDC-ASSEMBLY TYPE OD: 9.0MM (FMC50MML/A693)
- MINIMUM BEND RADIUS – 64mm [2.52in]

ZL-CBL50-nP	
Rev: C1	Date: 05/2013
Units: mm [inches]	
Scale: none	
ZIPLINK SureServo Cable	
AUTOMATIONDIRECT	