



TABLE A

PART NO	LENGTH
ZL-D0-CBL10-1P	1000mm [39.37"]
ZL-D0-CBL10-2P	2000mm [78.74"]

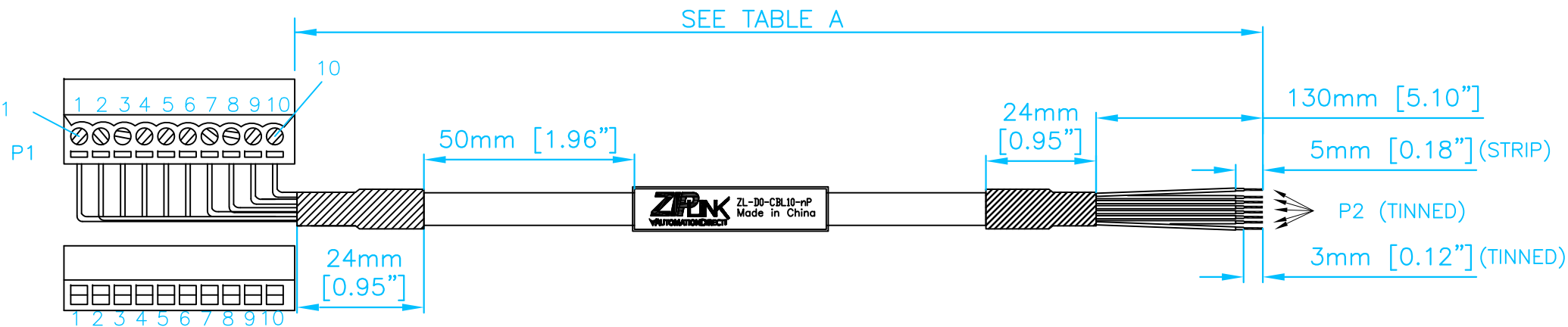


PIN-OUT DIAGRAM

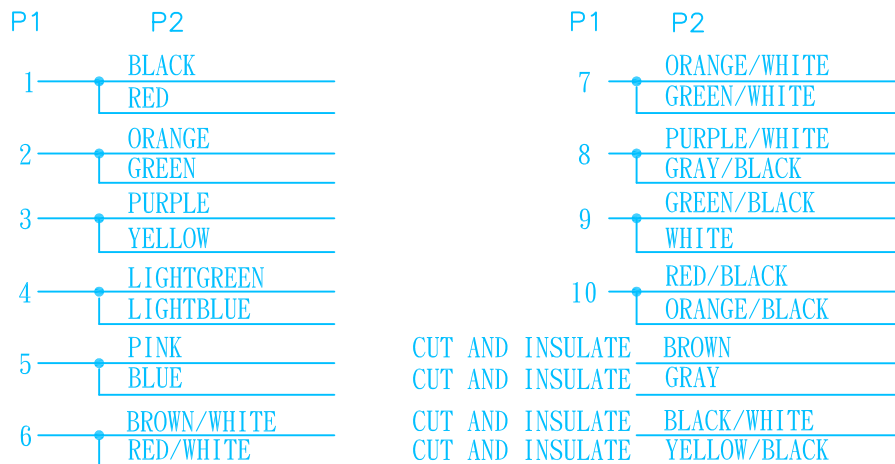

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 10 position terminal block for DL05/DL06 PLC. Automation Direct Order # DO-ACC-4
- PMINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-D0-CBL10-nP	
Rev: A	Date: 10/2009
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL05/DL06 Cable	
 AUTOMATIONDIRECT .com	