


TABLE A

PART NO	LENGTH
ZL-D06Y-CBL20	0.5m [1.6 ft]
ZL-D06Y-CBL20-1	1.0m [3.3 ft]
ZL-D06Y-CBL20-2	2.0m [6.6 ft]

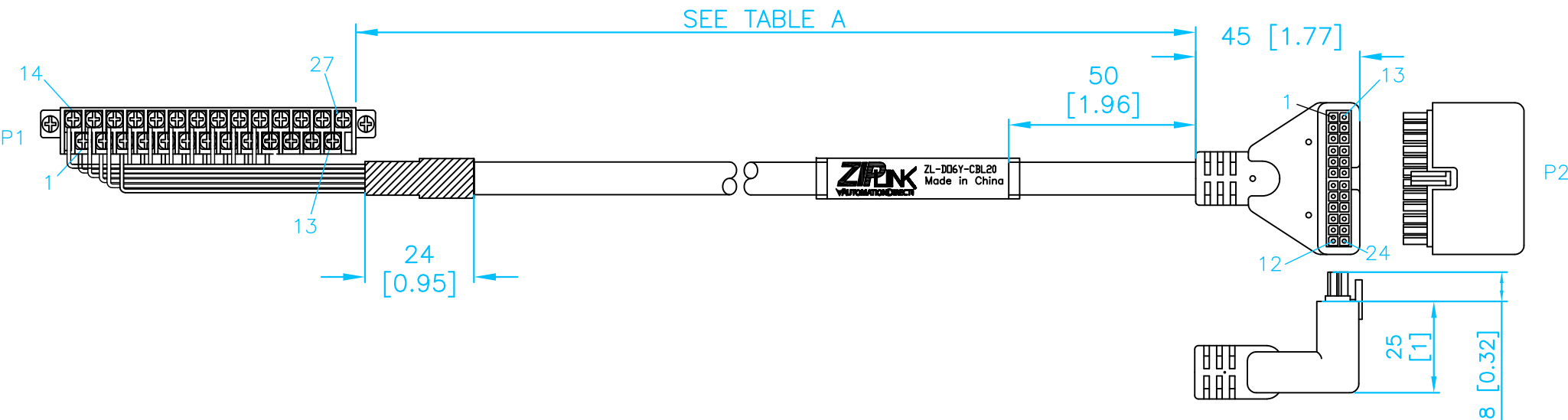

PIN-OUT DIAGRAM

P1	P2	P1	P2
19	2	3	8
24	14	8	20
10	1	7	7
23	13	21	19
9	3	7	9
22	4	20	10
5	5	6	11
18	6	16	12
4	15	2	21
17	16	15	22
	17	1	23
	18		24

P1 11, 12, 13, 14, 25, 26, 27 NOT CONNECTED

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 32A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 27-pin terminal block for Direct Logic 06, AutomationDirect part # D0-ACC-2
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-D06Y-CBL20-n	
Rev: original	Date: 10/2009
Units: mm [inches]	
Scale: none	
ZIPLINK DL06 OUTPUT CABLE	