



TABLE A

PART NO	LENGTH
ZL-D2-CBL10-1P	1000mm [39.37"]
ZL-D2-CBL10-2P	2000mm [78.74"]

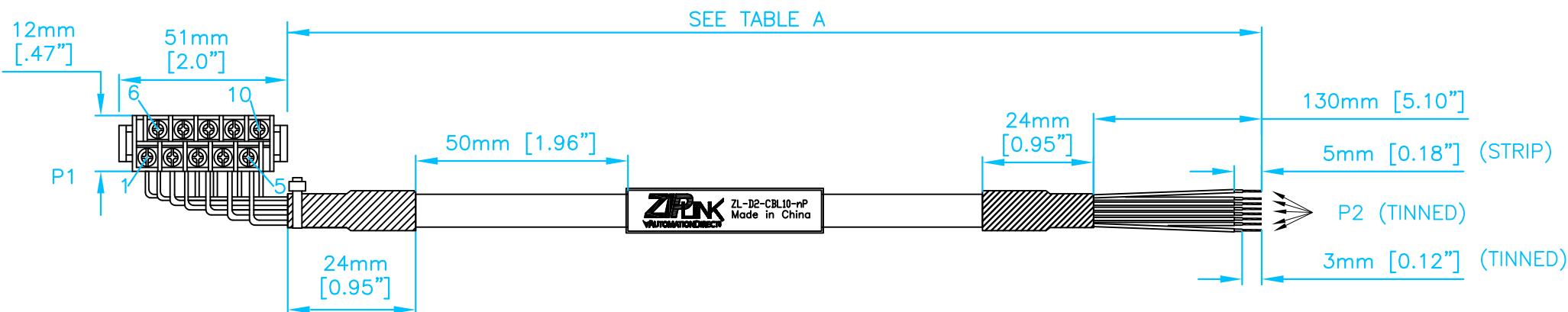


PIN-OUT DIAGRAM

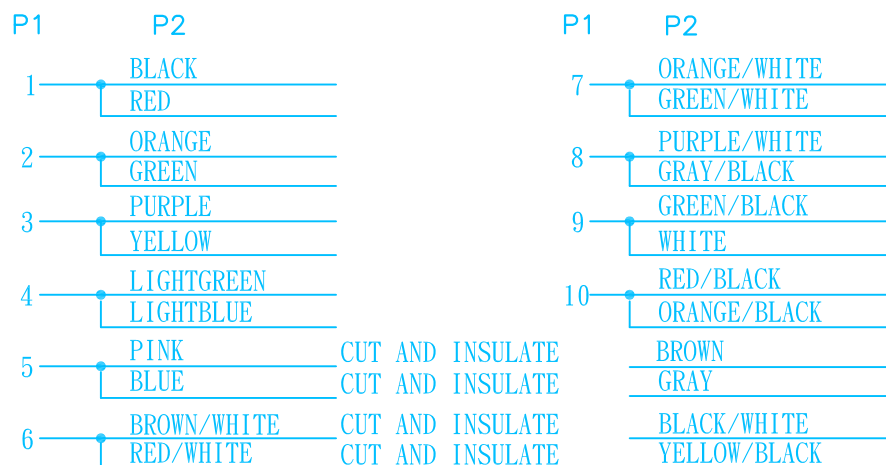

NOTES:

1. CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
2. CURRENT - 2A per conductor, 20A maximum cable current
3. VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
4. OPERATING TEMPERATURE - 0-60°C (32-140°F)
5. P1 CONNECTOR - 10 position terminal block for DL205 PLC, AutomationDirect part # D2-8IOCON
6. MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-D2-CBL10-nP	
Rev: A	Date: 10/2009
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL205 Cable	
 AUTOMATIONDIRECT .com	