


PART NO	LENGTH
ZL-D2-CBL19-1P	1.0m [3.3 ft]
ZL-D2-CBL19-2P	2.0m [6.6 ft]

TABLE A

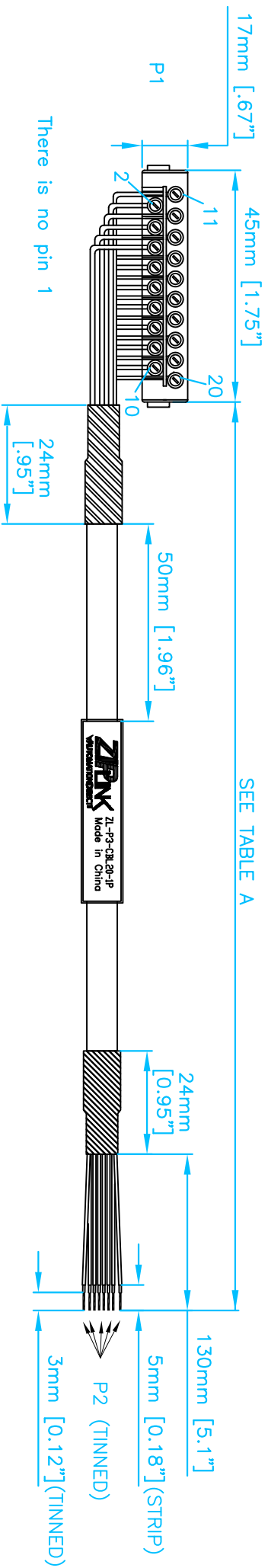

SEE TABLE A

There is no pin 1

PIN-OUT DIAGRAM

P1	P2(TIN)
11	BLACK/WHITE
2	BROWN
12	BROWN/WHITE
3	RED
13	RED/WHITE
4	ORANGE
14	ORANGE/WHITE
5	GREEN
15	GREEN/WHITE
6	PURPLE
16	PURPLE/WHITE
7	YELLOW
17	YELLOW/BLACK
8	GRAY
18	GRAY/BLACK
9	LIGHT GREEN
19	GREEN/BLACK
10	LIGHT BLUE
20	WHITE

- NOTES:
- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
  - CURRENT – 2A per conductor, 40A maximum cable current
  - VOLTAGE – 240V AC/DC rated operating voltage  
265V AC/DC maximum voltage
  - OPERATING TEMPERATURE – 0–60°C (32–140°F)
  - P1 CONNECTOR – 19 position terminal block, Automation Direct Part # D2-16IOCON
  - P2 CONNECTION – 24 tinned pig-tail leads (only 19 leads are connected to P1, per cable pin-out diagram)
  - MINIMUM BEND RADIUS – 65.6 mm [2.58 in]

ZL-D2-CBL19-nP	
Rev: A1	Date: 10/2009

Units: mm [inches]

Scale: .03940

ZIPLINK DL205 PLC CABLE

