


TABLE A

PART NO	LENGTH
ZL-D24-CBL40	0.5m [1.6 ft]
ZL-D24-CBL40-1	1.0m [3.3 ft]
ZL-D24-CBL40-2	2.0m [6.6 ft]

PIN-OUT DIAGRAM

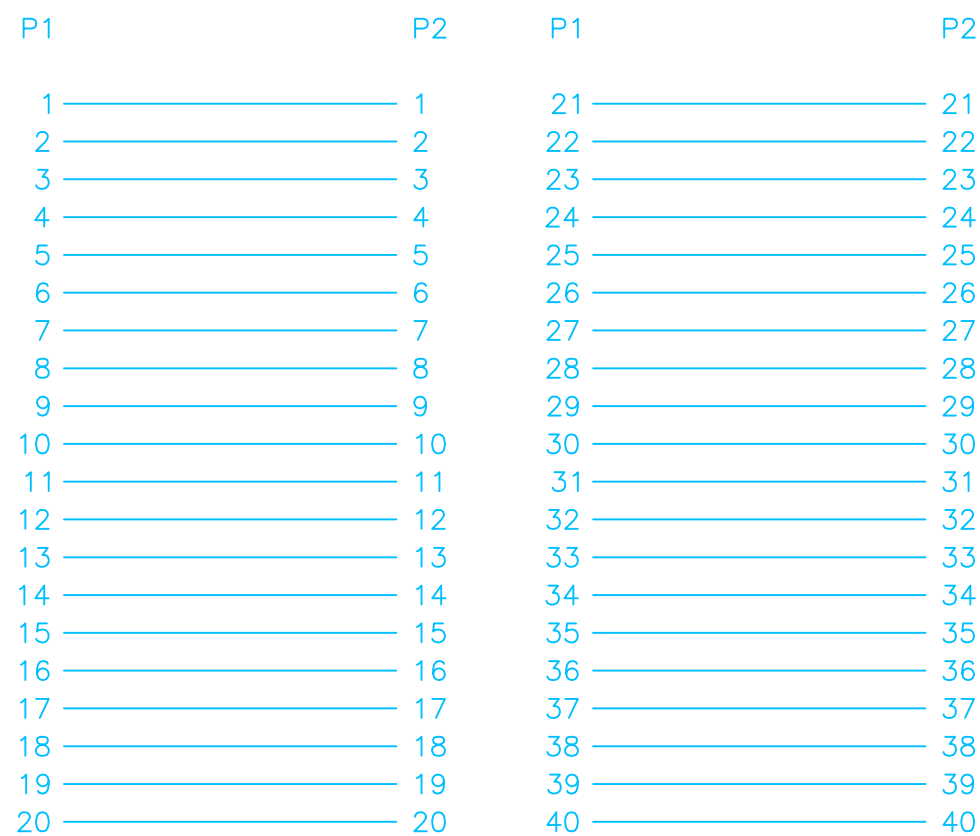

NOTES:

- CABLE - 40 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 0.5A per conductor, 32A maximum cable current
- VOLTAGE - 24V AC/DC rated operating voltage, 30V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - Fujitsu soldering type jack for FCN-360 series, AutomationDirect Order # ZL-D24-CON
- P2 CONNECTOR - Equivalent to 3M 34000 Series IDC Connector, Strain relief is required to latch to header. Example: Socket 3417-7640, Strain relief 3448-3040
- MINIMUM BEND RADIUS - 80 mm [3.15 in]

ZL-D24-CBL40-x	
Rev: E7	Date: 09/2011
Units: mm [inches]	
Scale: .03940	
ZIPLINK D2 & D4 PLC CABLE	