



PART NO	LENGTH
ZL-D4-CBL20	0.5m [1.6 ft]
ZL-D4-CBL20-1	1.0m [3.3 ft]
ZL-D4-CBL20-2	2.0m [6.6 ft]

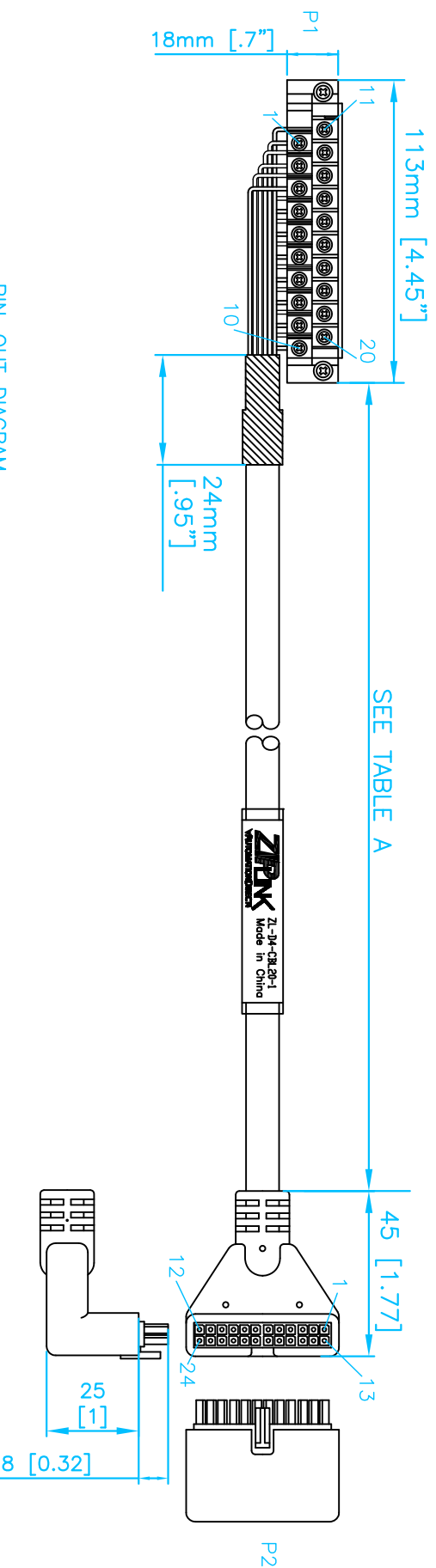

PIN-OUT DIAGRAM

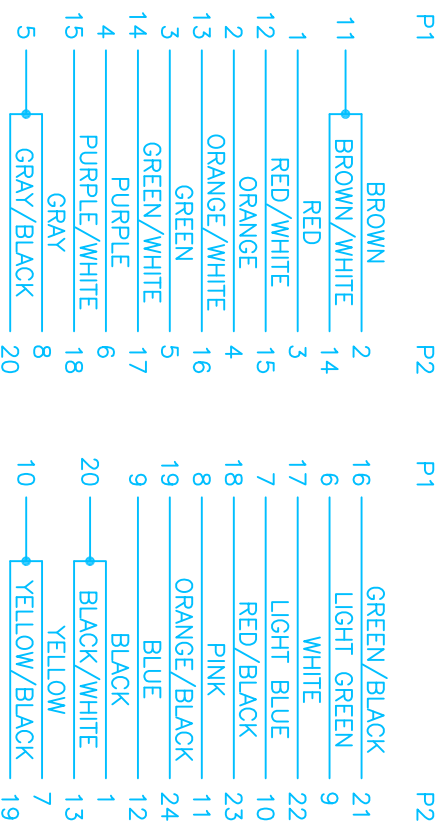

- NOTES:
1. CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
 2. CURRENT – 2A per conductor, 32A maximum cable current
 3. VOLTAGE –
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
 4. OPERATING TEMPERATURE – 0–60°C (32–140°F)
 5. P1 CONNECTOR – 20 position terminal block for Direct Logic DL405 PLC, AutomationDirect part # D4-16IOCON
 6. P2 CONNECTOR – 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
 6. MINIMUM BEND RADIUS – 65.6mm [2.58in]

ZL-D4-CBL20-n	
Rev: B	Date: 02/2011
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL405 PLC Cable	