


TABLE A

PART NO	LENGTH
ZL-D4-CBL20	0.5m [1.6 ft]
ZL-D4-CBL20-1	1.0m [3.3 ft]
ZL-D4-CBL20-2	2.0m [6.6 ft]

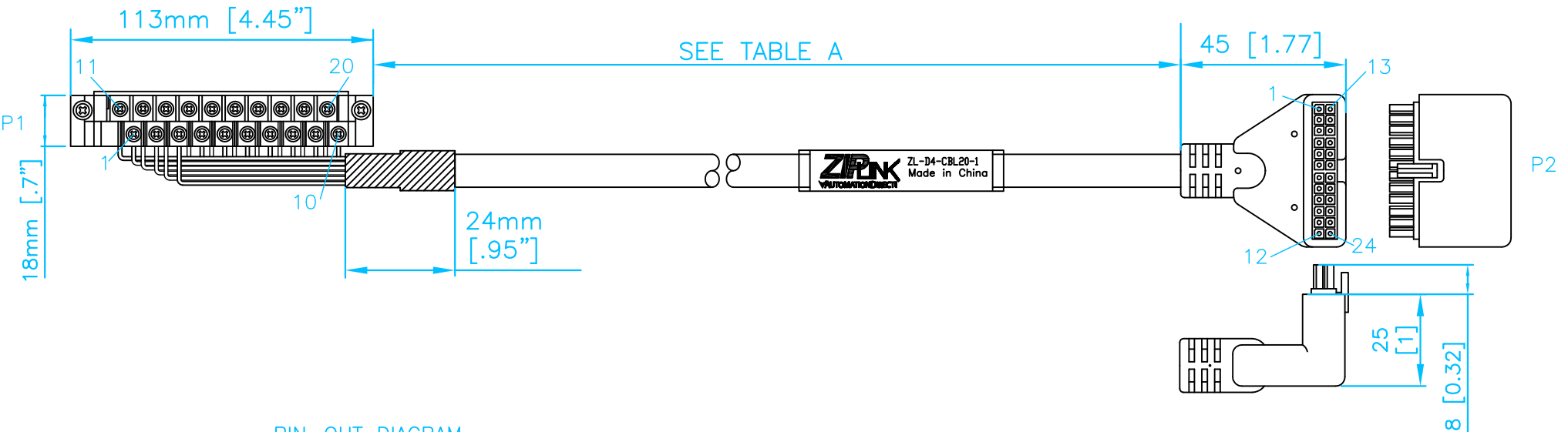

PIN-OUT DIAGRAM

P1	P2	P1	P2
11	2	16	21
1	14	6	9
12	3	17	22
2	15	7	10
13	4	18	23
3	16	8	11
14	5	19	24
4	17	9	12
15	6	20	1
5	18	10	13
	8		7
	20		19

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 32A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 20 position terminal block for Direct Logic DL405 PLC, AutomationDirect part # D4-16IOCON
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 80mm [3.15in]

ZL-D4-CBL20-n	
Rev: A	Date: 07/2009
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL405 PLC Cable	
