
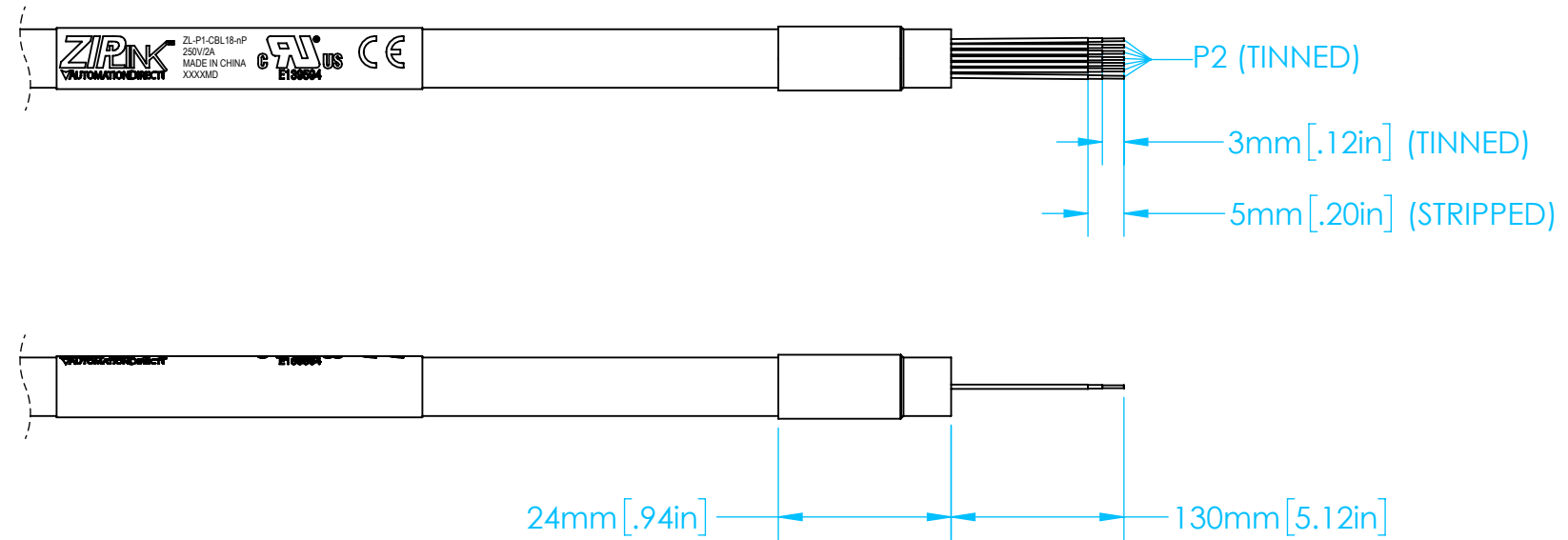


TABLE A

PART NO.	LENGTH
ZL-P1-CBL18-1P	1.0m (3.3ft)
ZL-P1-CBL18-2P	2.0m (6.6ft)

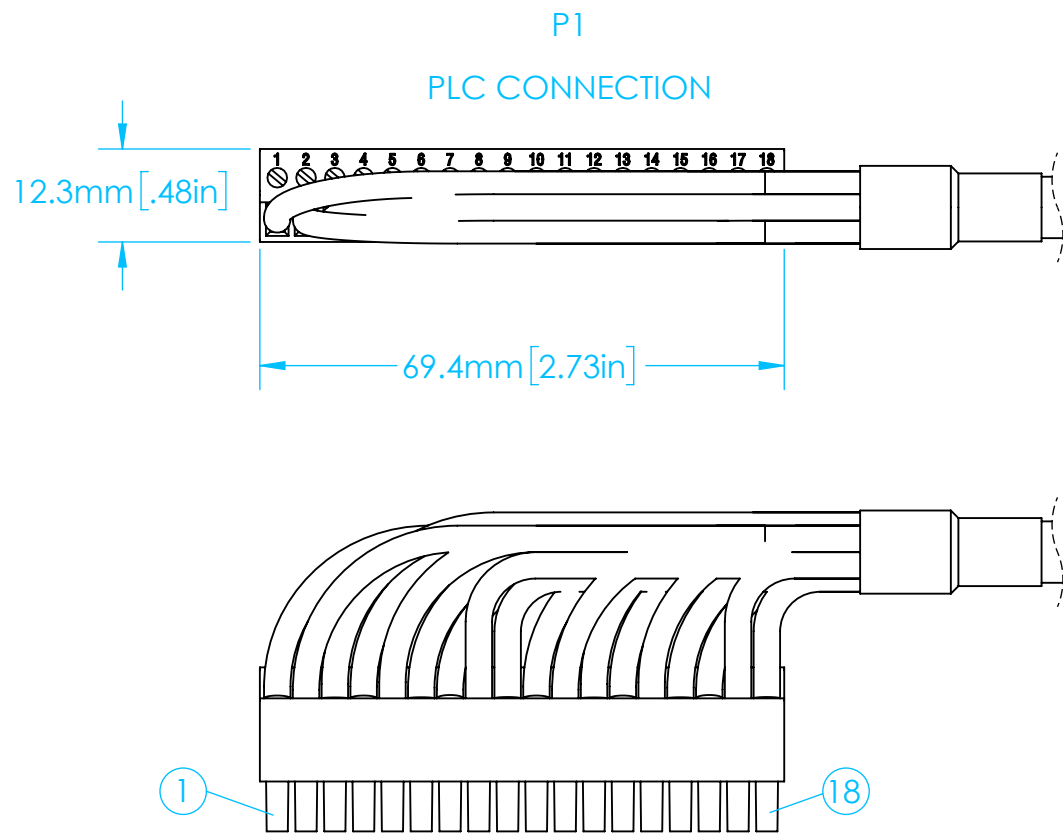

PIN-OUT DIAGRAM

P1	P2
1	BLUE
	PINK
2	LIGHT BLUE
3	LIGHT GREEN
4	GRAY
5	YELLOW
6	PURPLE
	GREEN
7	ORANGE
8	RED
9	BROWN
	BROWN/WHITE
10	BLACK
	BLACK/WHITE
11	ORANGE/BLACK
	RED/BLACK
12	WHITE
13	GREEN/BLACK
14	GRAY/BLACK
15	YELLOW/BLACK
16	PURPLE/WHITE
	GREEN/WHITE
17	ORANGE/WHITE
18	RED/WHITE

NOTES:

- CABLE: 24 CONDUCTOR, 24 AWG, PVC JACKET INSULATION RATING 80°C (176°F), 300V
- CURRENT: 2A PER CONDUCTOR, 40A MAXIMUM CABLE CURRENT
- VOLTAGE
 - 240V AC/DC RATED OPERATING VOLTAGE
 - 265V AC/DC MAXIMUM VOLTAGE
- OPERATING TEMPERATURE: 0-60°C (32-140°F)
- P1 CONNECTOR: 18 POSITION TERMINAL BLOCK FOR PRODUCTIVITY1000 PLC
- P2 CONNECTOR: 24 TINNED PIG-TAIL LEADS
- MINIMUM BEND RADIUS: 65.6MM [2.58IN]

ZL-P1-CBL18-nP	
Rev: D	Date: 10/4/2017
Units: mm [inches]	
Scale: 1:1	
Productivity 1000 ZIPLink Cable	
AUTOMATIONDIRECT.com	