


PART NO	LENGTH
ZL-P3-CBL20-P	0.5m [1.6 ft]
ZL-P3-CBL20-1P	1.0m [3.3 ft]
ZL-P3-CBL20-2P	2.0m [6.6 ft]

TABLE A

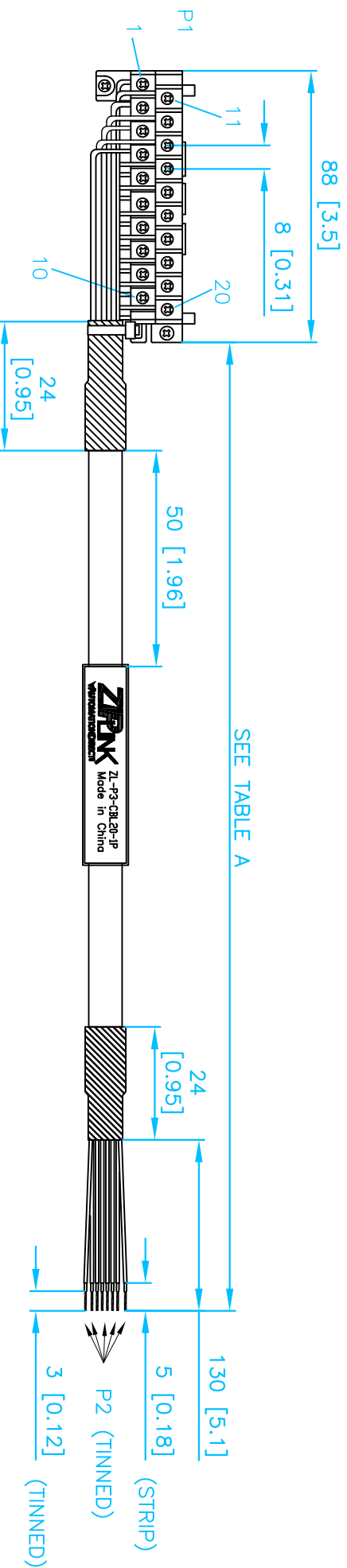

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	BLACK	6	VIOLET
11	BLACK/WHITE	16	VIOLET/WHITE
2	BROWN	7	YELLOW
12	BROWN/WHITE	17	YELLOW/BLACK
3	RED	8	GRAY
13	RED/WHITE	18	GRAY/BLACK
4	ORANGE	9	LIGHT GREEN
14	ORANGE/WHITE	19	GREEN/BLACK
5	GREEN	10	LIGHT BLUE
15	GREEN/WHITE	20	WHITE

NOTES:

- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT – 2A per conductor, 40A maximum cable current
- VOLTAGE –  
240V AC/DC rated operating voltage  
265V AC/DC maximum voltage
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- P1 CONNECTOR – 20-pin terminal block for Productivity 3000, AutomationDirect part # P3-RTB
- P2 CONNECTION – 24 tinned pig-tail leads (only 20 leads are connected to P1, per cable pin-out diagram)
- MINIMUM BEND RADIUS – 65.6 mm [2.58 in]

ZL-P3-CBL20-XP	
Rev: original	Date: 06/2009

Units: mm [inches]

Scale: none

ZIPLINK Productivity 3000 Cable

