


TABLE A

PART NO	LENGTH
ZL-P3-CBL20	0.5m [1.6 ft]
ZL-P3-CBL20-1	1.0m [3.3 ft]
ZL-P3-CBL20-2	2.0m [6.6 ft]

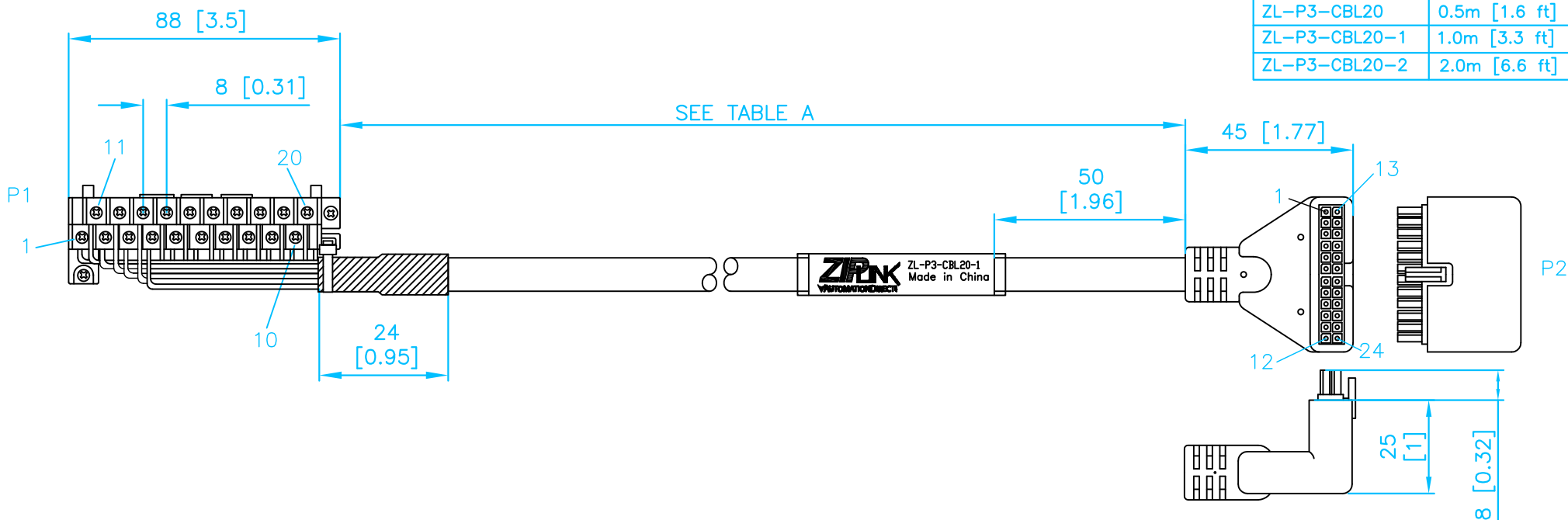

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	2	6	8
	14		20
11	1	16	7
	13		19
2	3	7	9
12	4	17	10
3	5	8	11
13	6	18	12
4	15	9	21
14	16	19	22
5	17	10	23
15	18	20	24

NOTES:

- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT – 2A per conductor, 32A maximum cable current
- VOLTAGE –
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- P1 CONNECTOR – 20-pin terminal block for Productivity 3000, AutomationDirect part # P3-RTB
- P2 CONNECTOR – 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS – 65.6 mm [2.58 in]

ZL-P3-CBL20-x	
Rev: original	Date: 06/2009
Units: mm [inches]	
Scale: none	
ZIPLINK Productivity 3000 Cable	
