



Pliers & Cutting Tools


Pliers Sets

CHANNELLOCK® tool sets offer the top-quality tools you need to get the job done. Whether you on the job site or in the garage, CHANNELLOCK tool sets can handle a wide range of tasks with precision and ease.

Features

- Set includes: 10.0in tongue and groove pliers, 7.0in XLT™ diagonal cutting pliers, and 8.0in long nose pliers with cutter
- Model 430: The original straight jaw tongue and groove pliers provide a strong, versatile grip for use in both directions
 - Strong 90-degree teeth for superior grip and longevity
- Model 337: Diagonal cutters with Xtreme Leverage Technology (XLT™) to increase performance and reduce hand fatigue
 - Laser heat-treated cutting edges perform better and last longer
- Model 317: Long nose pliers with precise narrow nose design provides accessibility for hard-to-reach applications
 - Crosshatch teeth provide maximum grip
- Forged high-carbon steel for maximum strength and durability is specially coated for ultimate rust prevention
- CHANNELLOCK BLUE® grips for comfort



Assorted Pliers Sets				
Part Number	Part Image	Description	Set Includes	Price
GS-6		CHANNELLOCK Classic pliers and cutters set, diagonal, long nose and tongue and groove, 3 pieces.	(1) classic grip long nose pliers 8in, (1) high leverage diagonal cutters 7in, (1) classic grip tongue and groove pliers 10in	\$-6hlu:



Pliers & Cutting Tools




 

Technician's Pliers Set

A convenient assortment of popular CHANNELLOCK® tools. A perfect pliers set for people that know what real work is all about.

Features

- Set includes: 9.5in tongue and groove pliers, 9.5in crimping pliers, 7.75in high leverage diagonal cutting pliers, 8.0in long nose pliers, and 6.5in slip joint pliers.
- Laser heat-treated teeth and cutting edges grip better and last longer
- High-carbon steel for superior performance on the job and specially coated for ultimate rust prevention
- CHANNELLOCK BLUE® grips for comfort
- Premium tool roll for convenient and secure storage



Technician's Pliers Set								
Part Number	Number of Pieces	Part Image	Type	Application	Overall Length	Jaw Thickness	Jaw Opening/Width	Price
<u>TOOLROLL-1</u>	5		Crimping Pliers: 22-10 AWG capacity	Crimping	9.5in (241mm)	N/A	N/A	\$06ncq:
			Tongue and Groove	Gripping	9.5in (241mm)	0.47in (11.9mm)	1.50in (38.1mm)	
			Long Nose	Gripping Wire cutting	8.0in (203mm)	0.41in (10.4mm)	0.87in (22.1mm)	
			Curved Diagonal	Wire cutting	7.7in (196mm)	0.49in (12.4mm)	1.06in (26.9mm)	
			Slip Joint	Gripping	6.5in (165mm)	0.43in (10.9mm)	1.28in (32.5mm)	



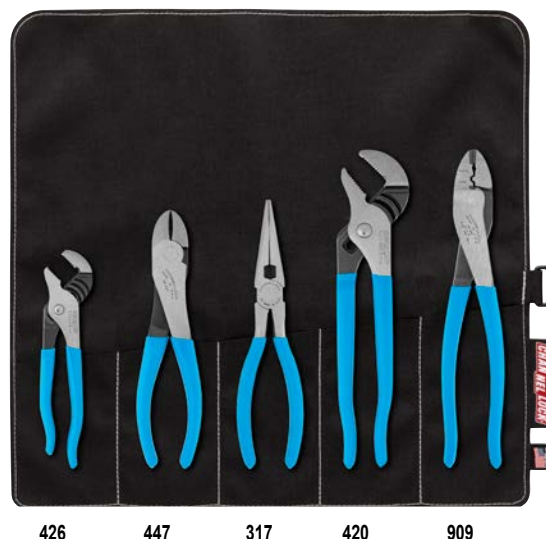
Pliers & Cutting Tools






Technician's Pliers Set

A convenient assortment of popular CHANNELLOCK® tools. A perfect plier set for people that know what real work is all about.

Features

- Set includes: 6.5in and 9.5in tongue and groove pliers, 9.5in crimping pliers, 7.75in high leverage diagonal cutting pliers, and 8.0in long nose pliers
- Laser heat-treated teeth and cutting edges grip better and last longer
- CHANNELLOCK uses high-carbon steel for superior performance on the job that is specially coated for ultimate rust prevention
- CHANNELLOCK BLUE® grips for comfort
- Premium tool roll for convenient and secure storage



Technician's Pliers Set								
Part Number	Number of Pieces	Part Image	Type	Application	Overall Length	Jaw Thickness	Jaw Opening/Width	Price
TOOLROLL-2	5		Crimping Pliers: 22-10 AWG capacity	Crimping	9.5in (241mm)	N/A	N/A	\$06ncs:
			Tongue and Groove	Gripping	9.5in (241mm)	0.47in (11.9mm)	1.50in (38.1mm)	
			Long Nose	Gripping Wire cutting	8.0in (203mm)	0.41in (10.4mm)	0.87in (22.1mm)	
			Curved Diagonal	Wire cutting	7.7in (196mm)	0.49in (12.4mm)	1.06in (26.9mm)	
			Pliers	Gripping	6.5in (165mm)	0.43in (10.9mm)	1.28in (32.5mm)	