





Stripping & Crimping Tools

Stripping & Crimping Tools

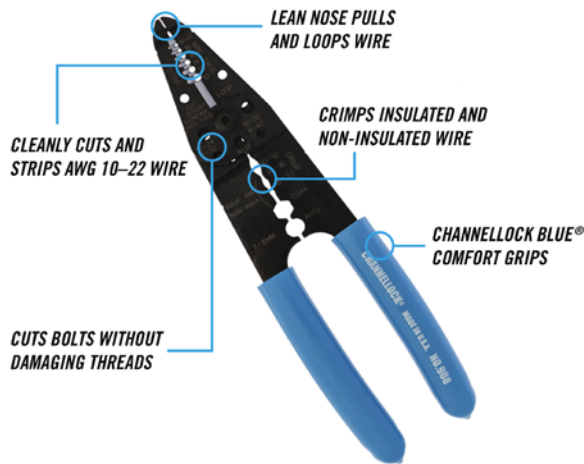


Whether you're cutting metal, installing fencing, or stripping wire, we have the specialty hand tools your trade demands. Forged for strength and durability right here in the U.S.A., CHANNELLOCK® snips, crimpers, and strippers are built to tackle the most challenging jobs.

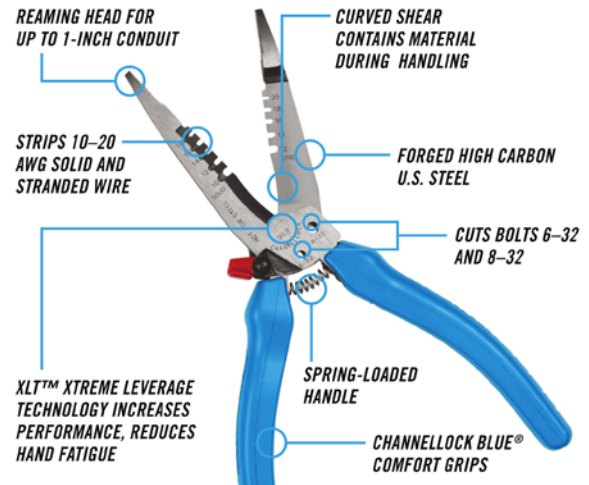

908



968

Stripping & Crimping Tools						
Part Number	Part Image	Application	Overall Length	Wire Stripping/Crimping Capacity	Tool Features	Price
<u>968</u>		Wire stripping Wire cutting Deburring Reaming Bolt cutting	7.5in (190mm)	20-12 AWG stranded 18-10 AWG solid	Integrated screw shears (6-32, 8-32) 1in conduit reamer and deburrer	\$-6hlo:
<u>908</u>		Wire stripping Wire cutting Crimping Bolt cutting	8.0in (203mm)	22-12 AWG stranded 20-10 AWG solid	Integrated screw shears (10-24, 6-32, 8-32, 10-32, 4-40) lean nose for pulling and looping wire	\$-6hli:
<u>958</u>		Wire stripping Wire cutting	6.0in (152mm)	20-12 AWG stranded 18-10 AWG solid	Lean nose for pulling and looping wire	\$-6hln:
<u>909</u>		Crimping	9.5in (241mm)	22-10 AWG capacity	Induction hardened beveled cutting edges	\$-6hle: