




Reinforced PVC - Potable Water Hose

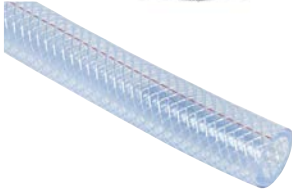

Reinforced Construction

HydroMode™ reinforced PVC hose incorporates a polyester spiraled yarn which allows use in higher pressure applications. Hose provides good chemical resistance and is flexible and lightweight. It is Phthalate free and NSF 61® certified for use in potable water and food beverage applications.

Features

- NSF-61 certified
- Shore A 73 PVC
- Clear blue in color
- Flexible and lightweight
- Phthalate free

Reinforced PVC - Potable Water Hose

Temp. Range		+15°F to +150°F (-9.4°C to +65.6°C)						
Hardness		Shore A 73 PVC						
Part Number	Price	Hose I.D. (inch)	Hose O.D. (inch)	Working Pressure (psi) @ 70°F	Working Pressure (psi) @ 125°F	Wall Thickness (inch)	PKG Length	Package Weight (lbs)
HBV316-100CBL	\$;11y,:	0.187	0.375	250	145	0.094	100 ft	4.4
HBV316-300CBL	\$011z0:	0.187	0.375	250	145	0.094	300 ft	13.2
HBV14-100CBL	\$11z4:	0.250	0.438	250	145	0.094	100 ft	5.8
HBV14-300CBL	\$011z5:	0.250	0.438	250	145	0.094	300 ft	17.5
HBV516-100CBL	\$11z6:	0.313	0.531	250	130	0.109	100 ft	7.4
HBV516-300CBL	\$011z7:	0.313	0.531	250	130	0.109	300 ft	22.2
HBV38-100CBL	\$11z8:	0.375	0.594	225	120	0.110	100 ft	9.0
HBV38-300CBL	\$011z9:	0.375	0.594	225	120	0.110	300 ft	27.1
HBV12-100CBL	\$11za:	0.500	0.750	200	95	0.125	100 ft	13.3
HBV12-300CBL	\$011zb:	0.500	0.750	200	95	0.125	300 ft	40.0
HBV58-100CBL	\$011zc:	0.625	0.891	200	95	0.133	100 ft	15.9
HBV58-300CBL	\$011zd:	0.625	0.891	200	95	0.133	300 ft	47.8
HBV34-100CBL	\$011ze:	0.750	1.030	150	80	0.140	100 ft	20.7
HBV34-300CBL	\$;011zf:	0.750	1.030	150	80	0.140	300 ft	62.2
HBV1-100CBL	\$011zg:	1.000	1.300	125	70	0.150	100 ft	29.1
HBV1-200CBL	\$011zh:	1.000	1.300	125	70	0.150	200 ft	58.2