



stay connected



Connection Cables - Sensor and Signal

FDA Compliant M12 A-coded Cable to Pigtail

Features

- Industry standard axial and 90-degree M12 connectors with open leads
- 2m [6.5 ft], 3m [9.8 ft], 5m [16.4 ft], 7m [22.9 ft], 10m [32.8 ft], 15m [49.2 ft], 20m [65.6 ft] and 25m [82ft] cable lengths
- IP69K rated to withstand high pressure, high temperature wash-down applications
- Food grade TPE-S (Styrene-Butadiene Thermoplastic Elastomer) jacket for food and beverage industrial applications

M12 A-Coded Cable to Pigtail											
Part Number	Price	Number of Wires	Connector	Cable Jacket/ Wire Insulation Material	Jacket Color	Dimensions (mm [in])					
						A	B	C	L (m [ft])		
7024-12181-3150500	\$4196:	3	Axial female	TPE-S/PP	Ice blue	39 [1.5]	15 [0.6]	n/a	5 [16.4]		
7024-12221-3210200	\$4198:	4							2 [6.5]		
7024-12221-3210300	\$4199:								3 [9.8]		
7024-12221-3210500	\$419a:								5 [16.4]		
7024-12221-3210700	\$419b:								7 [22.9]		
7024-12221-3211000	\$419c:								10 [32.8]		
7024-12221-3211500	\$419d:								15 [49.2]		
7024-12221-3212000	\$419e:								20 [65.6]		
7024-12221-3212500	\$419f:								25 [82]		
7024-12241-3390200	\$419p:	5							2 [6.5]		
7024-12241-3390300	\$419q:								3 [9.8]		
7024-12241-3390500	\$419s:								5 [16.4]		
7024-12241-3390700	\$419t:								7 [22.9]		
7024-12241-3391000	\$419u:								10 [32.8]		
7024-12241-3391500	\$419v:								15 [49.2]		
7024-12241-3392000	\$419x:								20 [65.6]		
7024-12241-3392500	\$419y:								25 [82]		
7024-12321-3150500	\$4197:	3	90-degree female			TPE-S/PP	Ice blue	37 [1.46]	15 [0.6]	29 [1.1]	5 [16.4]
7024-12341-3210200	\$419g:	4									2 [6.5]
7024-12341-3210300	\$419h:										3 [9.8]
7024-12341-3210500	\$419i:										5 [16.4]
7024-12341-3210700	\$419j:										7 [22.9]
7024-12341-3211000	\$419k:										10 [32.8]
7024-12341-3211500	\$419l:										15 [49.2]
7024-12341-3212000	\$419n:										20 [65.6]
7024-12341-3212500	\$419o:										25 [82]
7024-12361-3390200	\$419z:	5									2 [6.5]
7024-12361-3390300	\$419j:										3 [9.8]
7024-12361-3390500	\$419j:										5 [16.4]
7024-12361-3390700	\$419_:										7 [22.9]
7024-12361-3391000	\$419#:										10 [32.8]
7024-12361-3391500	\$419!:										15 [49.2]
7024-12361-3392000	\$419?:										20 [65.6]
7024-12361-3392500	\$419,::										25 [82]

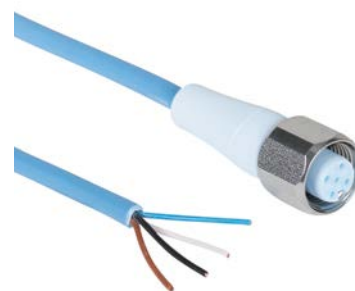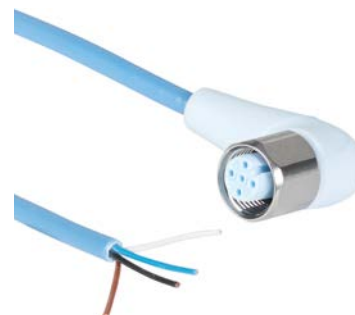[7024-12181-3150500](#)[7024-12221-3210200](#)[7024-12341-3210200](#)[7024-12361-3390300](#)



Connection Cables - Sensor and Signal

M12 A-coded Cable to Pigtail Specifications

Model	7024 Series		
	3-Wire, 5-Pole	4-Wire, 5-Pole	5-Wire, 5-Pole
Max Voltage	250 VAC/VDC		125 VAC/VDC
Max Voltage - UL Rating	30 VAC/VDC		
Max contact Per Contact	4A		
Protection Degree	IP65 / IP68 / IP69K		
Nut Material	Stainless steel		
Cable Jacket/Wire Insulation Material	TPE-S/PP		
Contacts Material	Copper-Tin alloy		
Tightening Torque	0.6 N·m [0.44 ft-lb]		
Conductors Cross Section	0.34 mm² [22AWG]		
Ø Outer Cable	4.3 mm [0.17 in]	4.7 mm [0.18 in]	5.0 mm [0.20 in]
Temperature Range - Stationary Use	-40 to 105°C [-40 to 221°F]		
Temperature Range - Flexible Use	-25 to 105°C [-13 to 221°F]		
Min Bend Radius	Stationary use: 5 x cable diameter; Flexible use: 10 x cable diameter		
Approvals*	cULus		

* To obtain the most current agency approval information, see the Agency Compliance & Certifications Checklist section on the specific part number's web page.




Dimensions

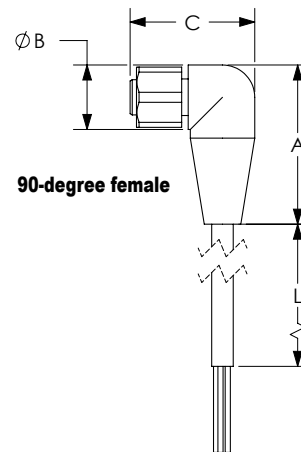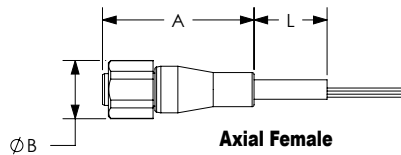

Contact Diagrams

Female 3-Wire, 5-Pole	Female 4-Wire, 5-Pole	Female 5-Wire, 5-Pole

Wiring Diagrams

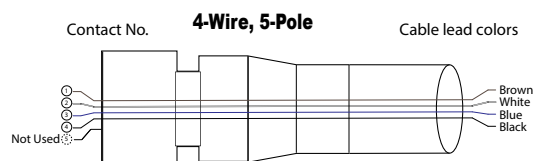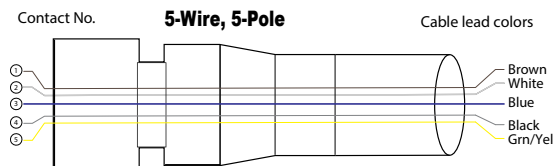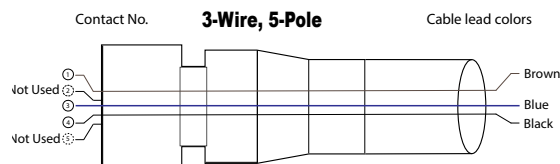



stay connected

Connection Cables - Sensor and Signal

FDA Compliant M12 A-Coded Male to Female Cables

Features

- Available patch cables include:
- Industry standard M12 screw-lock connectors
- One male and one female connector
- Axial and 90-degree connector models
- 1m [3.2 ft], 3m [9.8 ft] and 5m [16.4 ft] cable lengths
- IP69K rating, suitable for food and beverage industrial applications
- TPE-S (Styrene-Butadiene Thermoplastic Elastomer) jacket for food and beverage industrial applications

**7024-40021-3210100****7024-40261-3210100**


M12 A-coded Male to Female Cables (Euro, Micro DC-Single Key)										
Part Number	Price	Number of Wires	Connectors	Cable Jacket/ Wire Insulation Material	Jacket Color	Dimensions (mm [in])				
						A	B	C	D	L (m [ft])
7024-40021-3210100	\$41a0:	4	Axial male to axial female	TPE-S /PP	Ice Blue	42 [1.65]	39 [1.5]	15 [0.6]	n/a	1 [3.2]
7024-40021-3210300	\$41a1:									3 [9.8]
7024-40021-3210500	\$41a2:		5 [16.4]							
7024-40261-3210100	\$41a3:		90-degree male to 90-degree female			32 [1.26]	29 [1.1]	15 [0.6]	37 [1.46]	1 [3.2]
7024-40261-3210300	\$41a4:									3 [9.8]
7024-40261-3210500	\$41a5:					5 [16.4]				
7024-40041-3390100	\$41a6:	5	Axial male to axial female			42 [1.65]	39 [1.5]	15 [0.6]	n/a	1 [3.2]
7024-40041-3390300	\$41a7:									3 [9.8]
7024-40041-3390500	\$41a8:					5 [16.4]				

M12 A-coded Male to Female Cables Specifications		
Model	7024 Series	
Type	4-Wire, 5-Pole	5-Wire, 5-Pole
Max Voltage	250 VAC/VDC	125 VAC/VDC
Max Voltage - UL Rating	30 VAC/VDC	
Max Current Per Contact	4A	
Protection Degree	IP65 / IP68 / IP69K	
Nut Material	Stainless steel	
Cable Jacket/Wire Insulation Material	TPE-S/PP	
Contact Material	Copper-Tin Alloy	
Tightening Torque	0.6 N·m [0.44 ft-lb]	
Conductors Cross Section	0.34 mm² [22AWG]	
Ø Outer Cable	4.7 mm [0.18 in]	5.0 mm [0.20 in]
Temperature Range - Stationary Use	-40 to 105°C [-40 to 221°F]	
Temperature Range - Flexible Use	-25 to 105°C [-13 to 221°F]	
Min Bend Radius	Stationary use: 5 x cable diameter; Flexible use: 10 x cable diameter	
Approvals*	cULus	

* To obtain the most current agency approval information, see the Agency Compliance & Certifications Checklist section on the specific part number's web page.

Connection Cables - Sensor and Signal

Dimensions

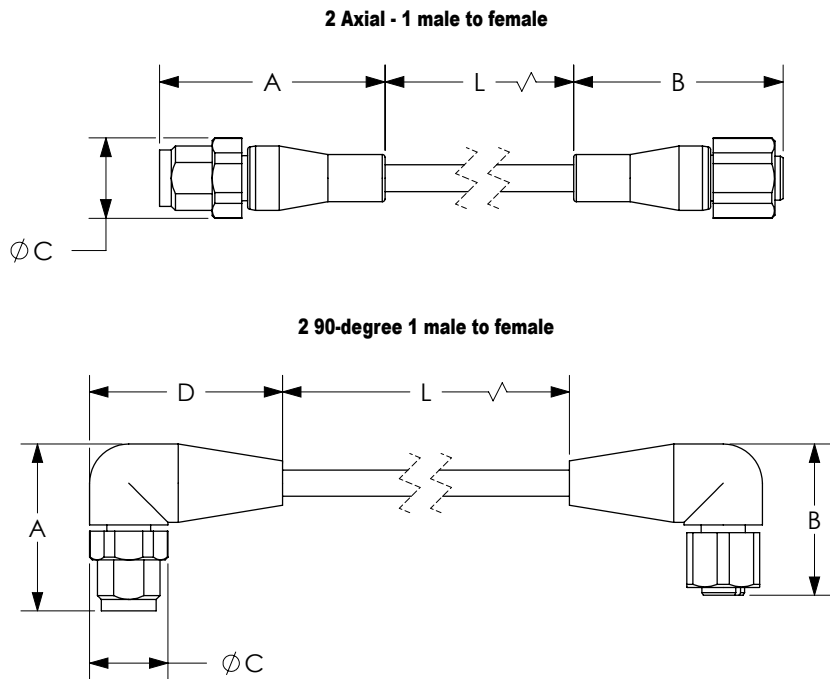

Contact Diagrams

Male 4-Wire, 5-Pole	Female 4-Wire, 5-Pole	Male 5-Wire, 5-Pole	Female 5-Wire, 5-Pole

Wiring Diagrams

