




# Brass Adapter Fittings

**NITRA** brass fittings are machined from quality brass bar stock or forgings. They work well with air, water, oil, oxygen, nitrogen and argon. Available in most popular styles and sizes, the fittings all have NPT threaded connections.


## Features

- 10 different styles
- Machined from yellow brass bar stock or forging
- Work with water, oil, air and other gases
- Maximum pressure of 800 psi

**Note: Actual product dimensions and appearance may vary**

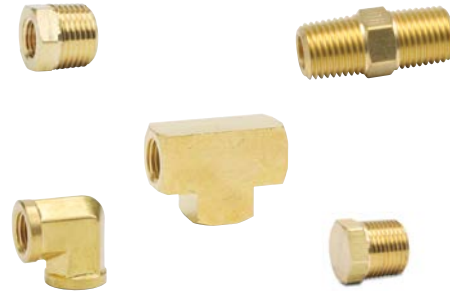


**BFMC-14N**

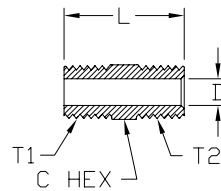

NITRA™ Male Brass Connectors									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D
<b>BFMC-18N</b>	\$57a:	Male connector, 1/8 inch NPT to 1/8 inch NPT	5	0.1	1/8	1/8	7/16	0.97	0.22
<b>BFMC-14N-18N</b>	\$579:	Male connector, 1/4 inch NPT to 1/8 inch NPT	5	0.1	1/4	1/8	9/16	1.19	0.22
<b>BFMC-14N</b>	\$578:	Male connector, 1/4 inch NPT to 1/4 inch NPT	5	0.1	1/4	1/4	9/16	1.38	0.31
<b>BFMC-38N-18N</b>	\$057d:	Male connector, 3/8 inch NPT to 1/8 inch NPT	5	0.3	3/8	1/8	11/16	1.22	0.22
<b>BFMC-38N-14N</b>	\$057c:	Male connector, 3/8 inch NPT to 1/4 inch NPT	5	0.3	3/8	1/4	11/16	1.41	0.31
<b>BFMC-38N</b>	\$057b:	Male connector, 3/8 inch NPT to 3/8 inch NPT	5	0.3	3/8	3/8	11/16	1.41	0.44
<b>BFMC-12N-14N</b>	\$576:	Male connector, 1/2 inch NPT to 1/4 inch NPT	2	0.3	1/2	1/4	7/8	1.62	0.31
<b>BFMC-12N-38N</b>	\$577:	Male connector, 1/2 inch NPT to 3/8 inch NPT	2	0.2	1/2	3/8	7/8	1.62	0.44
<b>BFMC-12N</b>	\$575:	Male connector, 1/2 inch NPT to 1/2 inch NPT	2	0.3	1/2	1/2	7/8	1.81	0.56



**BFFC-12N-14N**

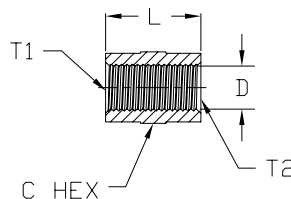

NITRA™ Female Brass Connectors									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D
<b>BFFC-18N</b>	\$572:	Female connector, 1/8 inch NPT to 1/8 inch NPT	5	0.1	1/8	1/8	9/16	0.75	0.34
<b>BFFC-14N-18N</b>	\$0571:	Female connector, 1/4 inch NPT to 1/8 inch NPT	5	0.1	1/4	1/8	3/4	0.97	0.34
<b>BFFC-14N</b>	\$0570:	Female connector, 1/4 inch NPT to 1/4 inch NPT	5	0.2	1/4	1/4	3/4	1.12	0.44
<b>BFFC-38N-14N</b>	\$0574:	Female connector, 3/8 inch NPT to 1/4 inch NPT	5	0.2	3/8	1/4	7/8	1.16	0.44
<b>BFFC-38N</b>	\$0573:	Female connector, 3/8 inch NPT to 3/8 inch NPT	5	0.3	3/8	3/8	7/8	1.12	0.52
<b>BFFC-12N-14N</b>	\$0567:	Female connector, 1/2 inch NPT to 1/4 inch NPT	2	0.4	1/2	1/4	1-1/16	1.28	0.44
<b>BFFC-12N-38N</b>	\$0568:	Female connector, 1/2 inch NPT to 3/8 inch NPT	2	0.2	1/2	3/8	15/16	1.32	0.52
<b>BFFC-12N</b>	\$0569:	Female connector, 1/2 inch NPT to 1/2 inch NPT	2	0.4	1/2	1/2	1-1/16	1.50	0.70




# Brass Adapter Fittings

**Note: Actual product dimensions and appearance may vary**




**BFMFR-38N-14N**

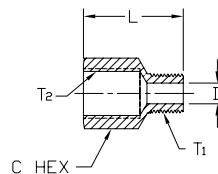

NITRA™ Male to Female Brass Connectors										
Inch Sizes - dimensions in inches										
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D	
<b>BFMFR-14N-18N</b>	\$052h:	Male to female connector, 1/8 inch NPT male to 1/4 inch NPT female	5	0.1	1/4	1/8	3/4	1.06	0.22	
<b>BFMFR-38N-18N</b>	\$-052j:	Male to female connector, 1/8 inch NPT male to 3/8 inch NPT female	5	0.1	3/8	1/8	7/8	1.1	0.22	
<b>BFMFR-38N-14N</b>	\$-052i:	Male to female connector, 1/4 inch NPT male to 3/8 inch NPT female	5	0.1	3/8	1/4	7/8	1.25	0.314	
<b>BFMFR-12N-38N</b>	\$052g:	Male to female connector, 3/8 inch NPT male to 1/2 inch NPT female	5	0.4	1/2	3/8	1-1/16	1.47	0.44	




**BFHB-12N-14N**

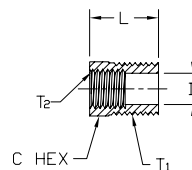

NITRA™ Brass Hex Bushing										
Inch Sizes - dimensions in inches										
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D	
<b>BFHB-14N-18N</b>	\$529:	Hex bushing, 1/4 inch NPT male to 1/8 inch NPT female	5	0.3	1/4	1/8	9/16	0.75	0.34	
<b>BFHB-38N-18N</b>	\$052b:	Hex bushing, 3/8 inch NPT male to 1/8 inch NPT female	5	0.3	3/8	1/8	11/16	0.75	0.34	
<b>BFHB-38N-14N</b>	\$052a:	Hex bushing, 3/8 inch NPT male to 1/4 inch NPT female	5	0.3	3/8	1/4	3/4	0.75	0.44	
<b>BFHB-12N-18N</b>	\$527:	Hex bushing, 1/2 inch NPT male to 1/8 inch NPT female	2	0.3	1/2	1/8	7/8	1.0	0.34	
<b>BFHB-12N-14N</b>	\$526:	Hex bushing, 1/2 inch NPT male to 1/4 inch NPT female	2	0.3	1/2	1/4	7/8	1.0	0.44	
<b>BFHB-12N-38N</b>	\$528:	Hex bushing, 1/2 inch NPT male to 3/8 inch NPT female	2	0.2	1/2	3/8	7/8	1.0	0.57	




**BFFE-14N**

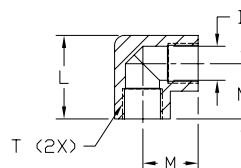

NITRA™ Brass Female Elbow								
Inch Sizes - dimensions in inches								
Part No.	Price	Description	Parts Per Pkg	Weight	T	M	Flow Dia. D	L
<b>BFFE-18N</b>	\$520:	Female elbow, 1/8 inch NPT female	2	0.2	1/8	0.55	0.339	0.83
<b>BFFE-14N</b>	\$;51,:	Female elbow, 1/4 inch NPT female	2	0.2	1/4	0.78	0.441	1.06
<b>BFFE-38N</b>	\$0521:	Female elbow, 3/8 inch NPT female	2	0.4	3/8	0.84	0.571	1.30



**BFSE-38N**

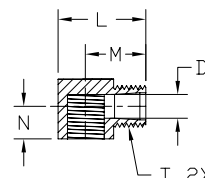

NITRA™ Female to Male Brass Street Elbow									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T	M	N	Flow Dia. D	L
<b>BFSE-18N</b>	\$52u:	Street elbow, 1/8 inch NPT female to 1/8 male	2	0.2	1/8	0.66	0.35	0.22	0.81
<b>BFSE-14N</b>	\$;52t:	Street elbow, 1/4 inch NPT female to 1/4 male	2	0.2	1/4	0.91	0.47	0.34	1.25
<b>BFSE-38N</b>	\$52v:	Street elbow, 3/8 inch NPT female to 3/8 male	2	0.3	3/8	0.97	0.49	0.41	1.42
<b>BFSE-12N</b>	\$052s:	Street elbow, 1/2 inch NPT female to 1/2 male	2	0.4	1/2	1.25	1.03	0.56	1.61




# Brass Adapter Fittings

• **Note: Actual product dimensions and appearance may vary**



**BFMT-14N**

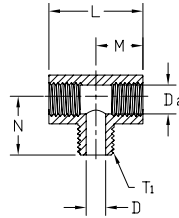


## NITRA™ Brass Male Tee Fittings

*Inch Sizes - dimensions in inches*

Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	L	M	N	Flow Dia. D
<b>BFMT-18N</b>	\$-52l:	Male tee, 1/8 inch NPT male	2	0.3	1/8	1/8	1.06	0.53	0.66	0.22
<b>BFMT-14N</b>	\$052k:	Male tee, 1/4 inch NPT male	2	0.3	1/4	1/4	1.52	0.76	0.91	0.31
<b>BFMT-38N</b>	\$052n:	Male tee, 3/8 inch NPT male	2	0.4	3/8	3/8	1.68	0.84	0.97	0.44



**BFFT-14N**

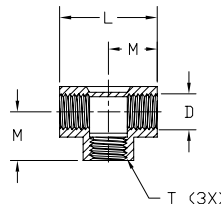


## NITRA™ Brass Female Tee Fittings

*Inch Sizes - dimensions in inches*

Part No.	Price	Description	Parts Per Pkg	Weight	T	L	M	Flow Dia. D
<b>BFFT-18N</b>	\$524:	Female tee, 1/8 inch NPT female	2	0.3	1/8	1.06	0.53	0.34
<b>BFFT-14N</b>	\$0523:	Female tee, 1/4 inch NPT female	2	0.3	1/4	1.52	0.76	0.44
<b>BFFT-38N</b>	\$0525:	Female tee, 3/8 inch NPT female	2	0.5	3/8	1.68	0.84	0.57
<b>BFFT-12N</b>	\$0522:	Female tee, 1/2 inch NPT female	2	0.9	1/2	2.14	1.07	0.70



**BFRHP-38N**

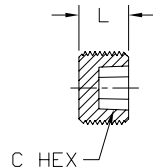


## NITRA™ Brass Recessed Hex Plug Fittings

*Inch Sizes - dimensions in inches*

Part No.	Price	Description	Parts Per Pkg	Weight	C Hex	L
<b>BFRHP-14N</b>	\$52p:	Recessed hex plug, 1/4 inch NPT male	5	0.1	1/4	0.46
<b>BFRHP-38N</b>	\$52q:	Recessed hex plug, 3/8 inch NPT male	5	0.2	5/16	0.46
<b>BFRHP-12N</b>	\$052o:	Recessed hex plug, 1/2 inch NPT male	5	0.2	3/8	0.61



**BFHHP-38N**

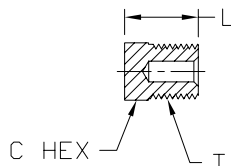

## NITRA™ Brass Hex Plug Fittings

*Inch Sizes - dimensions in inches*

Part No.	Price	Description	Parts Per Pkg	Weight	T	C Hex	L
<b>BFHHP-18N</b>	\$52e:	Hex head plug, 1/8 inch NPT male	5	0.1	1/8	7/16	0.56
<b>BFHHP-14N</b>	\$52d:	Hex head plug, 1/4 inch NPT male	5	0.1	1/4	9/16	0.75
<b>BFHHP-38N</b>	\$52f:	Hex head plug, 3/8 inch NPT male	5	0.1	3/8	11/16	0.78
<b>BFHHP-12N</b>	\$052c:	Hex head plug, 1/2 inch NPT male	5	0.2	1/2		0.97




# Brass Adapter Fittings

• **Note: Actual product dimensions and appearance may vary**



**BAHB-316-18N**

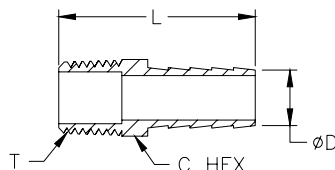


NITRA™ Brass Straight Barb Fitting							
Inch Sizes - dimensions in inches							
Part No.	Price	Description	Weight	T	L	ØD	C Hex
<a href="#">BAHB-316-18N</a>	\$,11!z:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/8in male NPT to (1) 3/16in hose. Package of 5.	0.1	1/8	1.20 [305]	0.20 [5.1]	0.44 [11.1]
<a href="#">BAHB-316-14N</a>	\$,;11!j:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/4in male NPT to (1) 3/16in hose. Package of 5.	0.2	1/4	1.43 [36.2]	0.20 [5.1]	0.56 [14.3]
<a href="#">BAHB-14-18N</a>	\$,;11!f:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/8in male NPT to (1) 1/4in hose. Package of 5.	0.1	1/8	1.49 [37.7]	0.24 [6.1]	0.44 [11.1]
<a href="#">BAHB-14-14N</a>	\$,;11!_:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/4in male NPT to (1) 1/4in hose. Package of 5.	0.2	1/4	1.69 [42.9]	0.24 [6.1]	0.56 [14.3]
<a href="#">BAHB-14-38N</a>	\$,;11!#:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/8in male NPT to (1) 1/4in hose. Package of 5.	0.3	3/8	1.70 [43.3]	0.24 [6.1]	0.69 [17.5]
<a href="#">BAHB-516-18N</a>	\$,;11!l:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/8in male NPT to (1) 5/16in (8mm) hose. Package of 5.	0.1	1/8	1.40 [35.6]	0.29 [7.4]	0.44 [11.1]
<a href="#">BAHB-516-14N</a>	\$,;11!?:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/4in male NPT to (1) 5/16in (8mm) hose. Package of 5.	0.2	1/4	1.70 [43.3]	0.29 [7.4]	0.56 [14.3]
<a href="#">BAHB-516-38N</a>	\$,;11!,:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/8in male NPT to (1) 5/16in (8mm) hose. Package of 5.	0.3	3/8	1.49 [37.8]	0.29 [7.4]	0.69 [17.5]
<a href="#">BAHB-38-14N</a>	\$11?0:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/4in male NPT to (1) 3/8in hose. Package of 5.	0.2	1/4	1.70 [43.3]	0.36 [9.2]	0.56 [14.3]
<a href="#">BAHB-38-38N</a>	\$11?1:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/8in male NPT to (1) 3/8in hose. Package of 5.	0.3	3/8	1.70 [43.3]	0.36 [9.2]	0.69 [17.4]
<a href="#">BAHB-38-12N</a>	\$11?2:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/2in male NPT to (1) 3/8in hose. Package of 5.	0.5	1/2	1.89 [48.0]	0.36 [9.2]	0.88 [22.2]
<a href="#">BAHB-12-14N</a>	\$11?3:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/4in male NPT to (1) 1/2in hose. Package of 5.	0.3	1/4	1.70 [43.3]	0.48 [12.3]	0.56 [14.3]
<a href="#">BAHB-12-38N</a>	\$11?4:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/8in male NPT to (1) 1/2in hose. Package of 5.	0.3	3/8	1.76 [44.8]	0.48 [12.3]	0.69 [17.5]
<a href="#">BAHB-12-12N</a>	\$11?5:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/2in male NPT to (1) 1/2in hose. Package of 5.	0.5	1/2	1.86 [47.2]	0.48 [12.3]	0.88 [22.2]
<a href="#">BAHB-58-38N</a>	\$11?6:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/8in male NPT to (1) 5/8in hose. Package of 3.	0.2	3/8	1.84 [46.7]	0.60 [15.3]	0.88 [22.2]
<a href="#">BAHB-58-12N</a>	\$11?7:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/2in male NPT to (1) 5/8in hose. Package of 3.	0.4	1/2	1.98 [50.4]	0.60 [15.3]	0.88 [22.2]
<a href="#">BAHB-58-34N</a>	\$11?8:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/4in male NPT to (1) 5/8in hose. Package of 3.	0.5	3/4	1.89 [48.1]	0.60 [15.3]	1.06 [27.0]
<a href="#">BAHB-34-12N</a>	\$11?9:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1/2in male NPT to (1) 3/4in hose. Package of 3.	0.4	1/2	1.99 [50.5]	0.73 [18.5]	0.88 [22.2]
<a href="#">BAHB-34-34N</a>	\$11?a:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/4in male NPT to (1) 3/4in hose. Package of 3.	0.3	3/4	2.03 [51.6]	0.73 [18.5]	1.06 [27.0]
<a href="#">BAHB-34-1N</a>	\$11?b:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1in male NPT to (1) 3/4in hose. Package of 3.	0.8	1	2.25 [57.2]	0.73 [18.5]	1.38 [34.9]
<a href="#">BAHB-1-34N</a>	\$11?c:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 3/4in male NPT to (1) 1in hose. Package of 1.	0.2	3/4	2.17 [55.0]	0.99 [25.1]	1.06 [27.0]
<a href="#">BAHB-1-1N</a>	\$11?d:	NITRA water, oil, air or gases threaded fitting, hose barb, brass body, brass threads, (1) 1in male NPT to (1) 1in hose. Package of 1.	0.3	1	2.36 [60.0]	0.99 [25.1]	1.38 [34.9]



# Brass Adapter Fittings


- Note: Actual product dimensions and appearance may vary

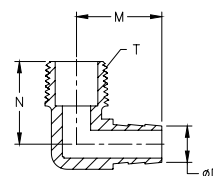**BAHBL-316-18N**

## NITRA™ Brass Male Elbow Barb Fitting

Inch Sizes - dimensions in inches

Part No.	Price	Description	Weight	T	M	N	ØD
<b>BAHBL-316-18N</b>	\$11?e:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/8in male NPT to (1) 3/16in hose. Package of 5.	0.1	1/8	0.95 [24.0]	0.71 [18.2]	0.20 [5.1]
<b>BAHBL-316-14N</b>	\$11?f:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/4in male NPT to (1) 3/16in hose. Package of 5.	0.3	1/4	1.00 [25.4]	0.83 [21.1]	0.20 [5.1]
<b>BAHBL-14-18N</b>	\$11?g:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/8in male NPT to (1) 1/4in hose. Package of 5.	0.2	1/8	1.25 [31.8]	0.60 [15.3]	0.24 [6.1]
<b>BAHBL-14-14N</b>	\$11?h:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/4in male NPT to (1) 1/4in hose. Package of 5.	0.3	1/4	1.33 [33.8]	0.84 [21.4]	0.24 [6.1]
<b>BAHBL-14-38N</b>	\$11?i:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/8in male NPT to (1) 1/4in hose. Package of 5.	0.4	3/8	1.22 [31.0]	0.94 [23.9]	0.24 [6.1]
<b>BAHBL-516-38N</b>	\$11?l:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/8in male NPT to (1) 5/16in (8mm) hose. Package of 5.	0.4	3/8	1.22 [31.1]	0.90 [22.9]	0.29 [7.4]
<b>BAHBL-38-14N</b>	\$11?n:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/4in male NPT to (1) 3/8in hose. Package of 5.	0.4	1/4	1.32 [33.4]	0.83 [21.1]	0.36 [9.2]
<b>BAHBL-38-38N</b>	\$11?o:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/8in male NPT to (1) 3/8in hose. Package of 5.	0.6	3/8	1.42 [35.9]	0.95 [24.0]	0.36 [9.2]
<b>BAHBL-12-14N</b>	\$11?q:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/4in male NPT to (1) 1/2in hose. Package of 5.	0.4	1/4	1.29 [32.7]	0.98 [24.9]	0.48 [12.3]
<b>BAHBL-12-38N</b>	\$11?s:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/8in male NPT to (1) 1/2in hose. Package of 5.	0.5	3/8	1.36 [34.6]	1.01 [25.5]	0.48 [12.3]
<b>BAHBL-12-12N</b>	\$11?t:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/2in male NPT to (1) 1/2in hose. Package of 5.	0.6	1/2	1.14 [28.8]	1.10 [28.0]	0.48 [12.3]
<b>BAHBL-58-38N</b>	\$11?u:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/8in male NPT to (1) 5/8in hose. Package of 3.	0.4	3/8	1.45 [37.0]	1.16 [29.5]	0.60 [15.3]
<b>BAHBL-58-12N</b>	\$11?v:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/2in male NPT to (1) 5/8in hose. Package of 3.	0.5	1/2	1.45 [37.0]	1.14 [29.1]	0.60 [15.3]
<b>BAHBL-34-12N</b>	\$11?x:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1/2in male NPT to (1) 3/4in hose. Package of 3.	0.6	1/2	1.35 [34.4]	1.25 [31.8]	0.73 [18.5]
<b>BAHBL-34-34N</b>	\$11?y:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/4in male NPT to (1) 3/4in hose. Package of 3.	0.7	3/4	1.54 [39.0]	1.31 [33.2]	0.73 [18.5]
<b>BAHBL-1-34N</b>	\$11?z:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 3/4in male NPT to (1) 1in hose. Package of 1.	0.4	3/4	1.70 [43.1]	1.42 [36.2]	0.99 [25.1]
<b>BAHBL-1-1N</b>	\$11?j:	NITRA water, oil, air or gases threaded fitting, hose barb elbow, brass body, brass threads, (1) 1in male NPT to (1) 1in hose. Package of 1.	0.4	1	1.78 [45.2]	1.63 [41.5]	0.99 [25.1]

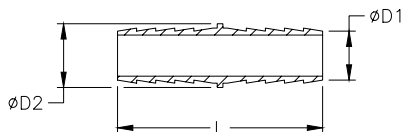**BAHM-58**

## NITRA™ Brass Hose Mender Fitting

Inch Sizes - dimensions in inches

Part No.	Price	Description	Weight	L	ØD1	ØD2
<b>BAHM-316</b>	\$11?l:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 3/16in hose to (1) 3/16in hose. Package of 5.	0.1	1.45 [36.7]	0.20 [5.1]	0.23 [5.8]
<b>BAHM-14</b>	\$11?n:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 1/4in hose to (1) 1/4in hose. Package of 5.	0.1	2.00 [50.8]	0.24 [6.1]	0.50 [12.7]
<b>BAHM-516</b>	\$11?#:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 5/16in (8mm) hose to (1) 5/16in (8mm) hose. Package of 5.	0.1	1.67 [42.4]	0.29 [7.4]	0.36 [9.1]
<b>BAHM-38</b>	\$11?l:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 3/8in hose to (1) 3/8in hose. Package of 5.	0.2	2.00 [50.8]	0.36 [9.2]	0.50 [12.7]
<b>BAHM-12</b>	\$11?l:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 1/2in hose to (1) 1/2in hose. Package of 5.	0.3	2.01 [51.1]	0.48 [12.3]	0.63 [15.9]
<b>BAHM-58</b>	\$11?l:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 5/8in hose to (1) 5/8in hose. Package of 3.	0.3	2.29 [58.0]	0.60 [15.3]	0.75 [19.1]
<b>BAHM-34</b>	\$11?l:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 3/4in hose to (1) 3/4in hose. Package of 3.	0.3	2.00 [50.8]	0.73 [18.5]	0.88 [22.2]
<b>BAHM-1</b>	\$11?l:	NITRA water, oil, air or gases barbed fitting, hose mender, brass body, brass threads, (1) 1in hose to (1) 1in hose. Package of 3.	0.6	2.49 [63.2]	0.99 [25.1]	1.19 [30.2]