



Brass Pneumatic Air Jets



Part No. AJS-35

NITRA brass pneumatic air jets are useful for numerous applications including cooling, chip removal, moving small parts, etc.

Features

- 36 possible Air Jet combinations
- Several component options
- Variety of nozzels for multiple application use
- Made in USA



Nitra Brass Pneumatic Air Jet Set			
Part No.	Description	Price	Weight (lbs)
<u>AJS-35</u>	NITRA pneumatic 35 piece air jet set, brass. Includes (3) AJB-10, (3) AJB-15, (3) AJB-20, (2) AJN16-1, (2) AJN16-2, (2) AJN16-1-45, (2) AJN16-1-90, (2) AJN16-1-CD, (2) AJN16-3, (9) AJ-NUT, (3) AJH, (2) AJNV-M10N, (1) durable plastic divider container	\$;03,ag:	1.55


Nitra Brass Pneumatic Air Jet Set Individual Pieces				
Items	Part No.	Description	Price	Weight (lbs)
	<u>AJB-10</u>	NITRA pneumatic air jet base, 1in length, brass, #10-32 female threaded.	\$;3,ah:	0.05
	<u>AJB-15</u>	NITRA pneumatic air jet base, 1.5in length, brass, #10-32 female threaded.	\$;-3,ai:	0.05
	<u>AJB-20</u>	NITRA pneumatic air jet base, 2in length, brass, #10-32 female threaded.	\$;-3,aj:	0.05
	<u>AJTB-18N</u>	NITRA pneumatic air jet base, 1in length, brass, 1/8in male NPT.	\$;3,ak:	0.03
	<u>AJPB-14</u>	NITRA pneumatic air jet base, 1.1in length, brass, 1/4in push-to-connect.	\$;-3,al:	0.02
	<u>AJN16-1</u>	NITRA pneumatic air jet nozzle, 1in length, straight, brass.	\$;3,an:	0.02
	<u>AJN16-2</u>	NITRA pneumatic air jet nozzle, 2in length, straight, brass.	\$;3,ao:	0.02



Brass Pneumatic Air Jets

Nitra Brass Pneumatic Air Jet Set Individual Pieces Continued				
Items	Part No.	Description	Price	Weight (lbs)
	<u>AJN16-1-45</u>	NITRA pneumatic air jet nozzle, 1in length, 45 degree, brass.	\$;3,ap:	0.02
	<u>AJN16-1-90</u>	NITRA pneumatic air jet nozzle, 1in length, 90 degree, brass.	\$;3,aq:	0.02
	<u>AJN16-1-CD</u>	NITRA pneumatic air jet nozzle, 1in length, compound angle, brass.	\$;3,as:	0.02
	<u>AJN16-3</u>	NITRA pneumatic air jet nozzle, 3in length, straight, brass.	\$;3,at:	0.02
	<u>AJ-NUT</u>	NITRA pneumatic air jet nut, brass.	\$;3,au:	0.15
	<u>AJH-1</u>	NITRA pneumatic air jet holder, anodized aluminum.	\$;3,oq:	0.05
	<u>AJNV-M10N</u>	NITRA pneumatic air jet needle valve, brass, #10-32 female threaded.	\$;3,ax:	0.05

Air Jet Assembly Example

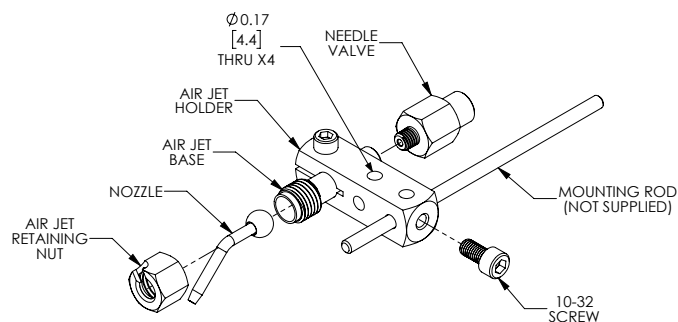

Flow at Pressure (T=70F @ 14.7 psia Atmospheric Pressure)

