



Quick-Disconnect Fittings

NITRA pneumatic quick-disconnect hose couplings allow easy changing of tools or hose connections. Couplers and plugs are sold separately. Industrial Interchange, ARO210 and Truflate plugs are available in steel and chrome-plated steel. Couplers are available in Industrial Interchange manual or automatic and universal automatic.



Features

- Plugs and couplers for 1/4 and 3/8 inch hose sizes
- Male and female NPT threaded
- Thread sealant supplied on all male fittings
- Maximum pressure of 250 psi, including safety coupler fittings

NITRA™ Quick-Disconnect 1/4 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>HC14-14F-A</u>	\$51d:	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<u>HC14-38F-A</u>	\$-51j:	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<u>HC14-14M-A</u>	\$51g:	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<u>HC14-38M-A</u>	\$51n:	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<u>HC14-14F-B</u>	\$051e:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<u>HC14-38F-B</u>	\$051k:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<u>HC14-14M-B</u>	\$051h:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<u>HC14-38M-B</u>	\$051o:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<u>HC14-14F-C</u>	\$.051f:	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<u>HC14-38F-C</u>	\$.051l:	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<u>HC14-14M-C</u>	\$.051i:	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<u>HC14-38M-C</u>	\$051p:	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2




HC14-38F-A



HC14-38F-B



HC14-14M-C

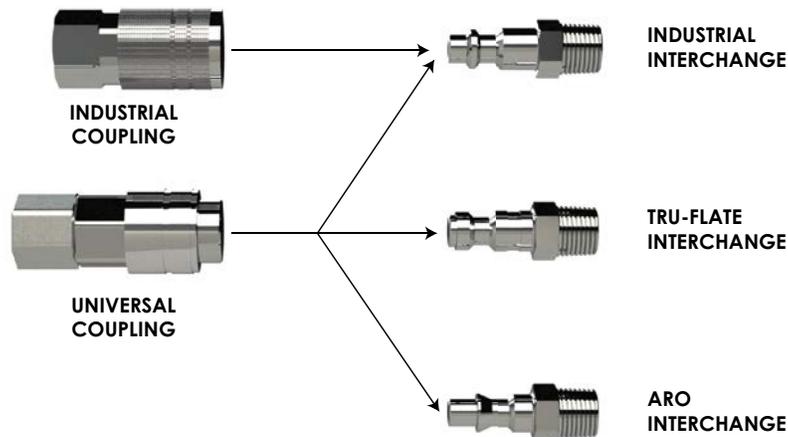



Quick-Disconnect Fittings

**HCP14-14F-J****HCP14-14M-K****HCP14-14M-L****HCP14-14F-M**

NITRA™ Quick-Disconnect 1/4 in. I.D. Plug Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>HCP14-14F-J</u>	\$51q:	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<u>HCP14-38F-J</u>	\$.51j:	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<u>HCP14-14M-J</u>	\$51v:	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<u>HCP14-38M-J</u>	\$51#::	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<u>HCP14-14F-K</u>	\$51s:	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<u>HCP14-14M-K</u>	\$51x:	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<u>HCP14-14F-L</u>	\$.51t:	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<u>HCP14-14M-L</u>	\$51y:	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<u>HCP14-38M-L</u>	\$.51l:	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<u>HCP14-14F-M</u>	\$51u:	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<u>HCP14-38F-M</u>	\$51_:	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<u>HCP14-14M-M</u>	\$51z:	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<u>HCP14-38M-M</u>	\$51?:	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1

**HC38-14F-A****HC38-14M-A****HC38-14M-B**

NITRA™ Quick-Disconnect 3/8 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>HC38-14F-A</u>	\$06x_:	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3
<u>HC38-38F-A</u>	\$.06x.:	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.3
<u>HC38-12F-A</u>	\$06xy:	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.3
<u>HC38-14M-A</u>	\$.06x!:	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
<u>HC38-38M-A</u>	\$06y1:	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.3
<u>HC38-12M-A</u>	\$.06x]:	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.3
<u>HC38-14F-B</u>	\$06x#:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
<u>HC38-38F-B</u>	\$06y0:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
<u>HC38-14M-B</u>	\$06x?:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
<u>HC38-38M-B</u>	\$06y2:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
<u>HC38-12M-B</u>	\$.06x[:	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.2



Quick-Disconnect Fittings



HCP38-14M-J



HCP38-14F-M

NITRA™ Quick-Disconnect 3/8 in. I.D. Plug Fittings Cont'd				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>HCP38-14F-J</u>	\$6y5:	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<u>HCP38-38F-J</u>	\$.6xt:	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<u>HCP38-14M-J</u>	\$6y7:	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<u>HCP38-38M-J</u>	\$6xv:	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<u>HCP38-14F-M</u>	\$6y6:	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
<u>HCP38-38F-M</u>	\$6xu:	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
<u>HCP38-12F-M</u>	\$6y3:	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
<u>HCP38-14M-M</u>	\$6y8:	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
<u>HCP38-38M-M</u>	\$6xx:	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
<u>HCP38-12M-M</u>	\$6y4:	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.1