



1/4" NPT Stainless Steel Manifolds

**MRS-2CB****NITRA** stainless steel manifolds

- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA

**STAINLESS
STEEL**




NITRA 1/4" NPT Stainless Steel Manifolds

Part No.	Description	A	Parts Per Pkg	Weight (lbs)	Price
<u>MRS-2CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 2 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	1.75 [44.5]	1	0.4	\$1120:
<u>MRS-3CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 3 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	2.50 [63.0]	1	0.5	\$1121:
<u>MRS-4CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 4 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	3.25 [82.6]	1	0.7	\$01122:
<u>MRS-5CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 5 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	4.00 [101.6]	1	0.9	\$01123:
<u>MRS-6CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 6 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	4.75 [120.7]	1	1.1	\$01124:
<u>MRS-7CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 7 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	5.50 [139.7]	1	1.2	\$01125:
<u>MRS-8CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 8 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	6.25 [158.8]	1	1.4	\$01126:
<u>MRS-9CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 9 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	7.00 [177.8]	1	1.6	\$01127:
<u>MRS-10CB</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 10 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	7.75 [196.9]	1	1.7	\$01128:

Dimensions

inches [mm]

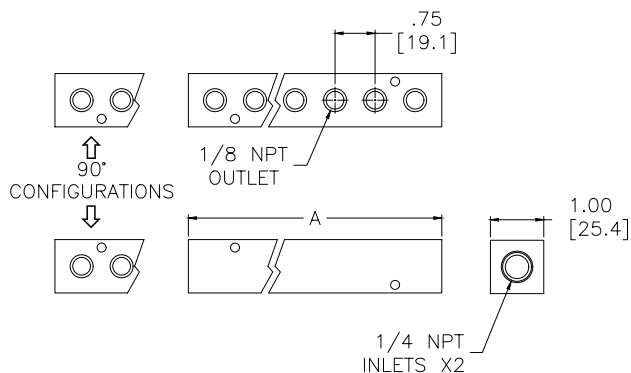

See our website www.AutomationDirect.com for complete Engineering drawings.



3/8" NPT Stainless Steel Manifolds

**MRS-2DC**

NITRA stainless steel manifolds

- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA




NITRA 3/8" NPT Stainless Steel Manifolds

Part No.	Description	A	Parts Per Pkg	Weight (lbs)	Price
<u>MRS-2DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 2 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	2.13 [54.1]	1	0.7	\$01129:
<u>MRS-3DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 3 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	3.00 [76.2]	1	1.0	\$0112a:
<u>MRS-4DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 4 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	3.88 [98.6]	1	1.3	\$0112b:
<u>MRS-5DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 5 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	4.75 [120.7]	1	1.6	\$0112c:
<u>MRS-6DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 6 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	5.63 [143.0]	1	1.9	\$0112d:
<u>MRS-7DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 7 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	6.50 [165.1]	1	2.2	\$0112e:
<u>MRS-8DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 8 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	7.38 [187.5]	1	2.5	\$,0112f:
<u>MRS-9DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 9 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	8.25 [209.6]	1	2.8	\$0112g:
<u>MRS-10DC</u>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 10 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	9.13 [231.9]	1	3.1	\$0112h:

Dimensions

inches [mm]

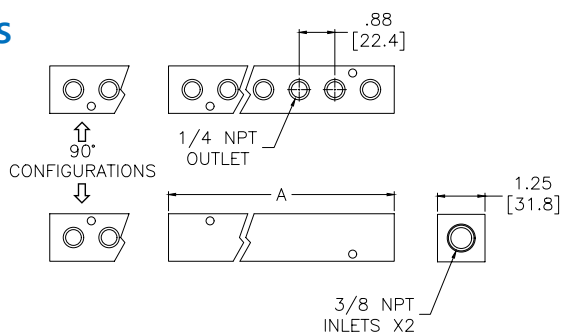

See our website www.AutomationDirect.com for complete Engineering drawings.