


Wera Screwdrivers

Medium Ratcheting Multi-Bit Screwdrivers

Wera's Rapidaptor ratcheting multi-bit screwdrivers feature a packed bitholding screwdriver built into a small footprint. The driver's Rapidaptor quick-release chuck allows lightning-fast bit changes without any extra tools. The ratchet mechanism with fine toothing is integrated in the handle (36 teeth/return angle 10°). This innovative function eases and accelerates screwdriving without having to reposition the tool, boasting three positions (clockwise/counterclockwise/no ratcheting).

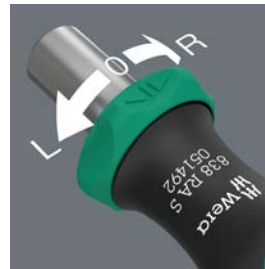

Directional Ratchet Switch



Take-it-Easy Tool Finder

Medium Ratcheting Rapidaptor Multi-Bit Screwdrivers								
Part Number	Number of Pieces	Part Image	Type	Bit Size	Overall Length	Handle Type	Set Includes	Price
05051493001	1		n/a		4.8in (122mm)	Kraftform ergonomic handle	Handle only	\$6d9n:
05051061001	15			Phillips #1, #2, #3			(1) Kraftform Kompakt Rapidaptor bit holding ratcheting screwdriver, (14) 3.5in standard bits (Phillips: #1, #2, #3 Pozidriv: #1, #2, #3, torx: T10, T15, T20, T25, hex: 3mm, 4mm, 5mm, slotted: 5.5mm), (1) robust textile pouch, (1) hook and loop fastener strip for storage	\$6d9k:
				Slotted 5.5mm				
				External Hex 3mm, 4mm, 5mm				
				Torx T10, T15, T20, T25				
				Pozidriv #1, #2, #3				
05051066001	15			Phillips #1, #2, #3			(1) Kraftform Kompakt Rapidaptor bit holding ratcheting screwdriver, (14) 3.5in standard bits (Phillips: #1, #2, #3, torx: T10, T15, T20, T25, hex: 1/8in, 5/32in, 3/16in, square: #1, #2, #3, slotted: 5.5mm), (1) robust textile pouch, (1) hook and loop fastener strip for storage	\$-6d9l:
				Slotted 5.5mm				
				External Hex 1/8in, 5/32in, 3/16in				
				Torx T10, T15, T20, T25				
				Square #1, #2, #3				

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.