


Wera Screwdrivers

Small Ratcheting Multi-Bit Screwdrivers

Wera's small ratcheting multi-bit screwdrivers are an extremely small bitholding screwdriver designed for use with 1/4 in drive bits. The ratchet mechanism with fine toothing is integrated in the handle (36 teeth/return angle 10°). This innovative function eases and accelerates screwdriving without having to reposition the tool, boasting three positions (clockwise/counterclockwise/no ratcheting).

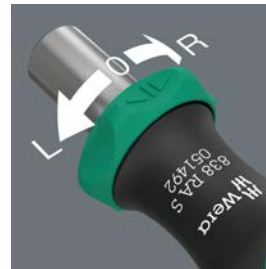

Directional Ratchet Switch



Take-it-Easy Tool Finder

Small Ratcheting Multi-Bit Screwdrivers

Part Number	Number of Pieces	Part Image	Type	Bit Size	Overall Length	Handle Type	Set Includes	Price
05051492001	1		n/a		4.0in (102mm)	Kraftform ergonomic handle	Handle only	\$-6d9j:
05051060001	14		Phillips	#1, #2			(1) Kraftform Kompakt ratcheting screwdriver, (13) 2in standard bits (Phillips: #1, #2, Pozidriv: #1, #2, torx: T10, T15, T20, T25, hex: 2.5mm, 3mm, 4mm, 5mm, slotted: 5.5mm), (1) robust textile pouch, (1) hook and loop fastener strip for storage	\$6d9h:
			Slotted	5.5mm				
			External Hex	2.5mm, 3mm, 4mm, 5mm				
			Torx	T10, T15, T20, T25				
			Pozidriv	#1, #2				
05051065001	14		Phillips	#1, #2			(1) Kraftform Kompakt ratcheting screwdriver, (13) 2in standard bits (Phillips: #1, #2, square: #1, #2, torx: T10, T15, T20, T25, hex: 9/64in, 5/32in, 3/16in, 7/32in, slotted: 5.5mm), (1) robust textile pouch, (1) hook and loop fastener strip for storage	\$-6d9i:
			Slotted	5.5mm				
			External Hex	9/64in, 5/32in, 3/16in, 7/32in				
			Torx	T10, T15, T20, T25				
			Square	#1, #2				

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.