


Wera Screwdrivers

Stubby Multi-Bit Screwdrivers

Wera Stubby multi-bit screwdrivers is a small, bitholding screwdriver with short bit mounting for hard to reach areas. The handle boasts a magazine in the handle for up to 6 bits. The bit holder has a strong permanent magnet, ensuring a secure holding of the bit.

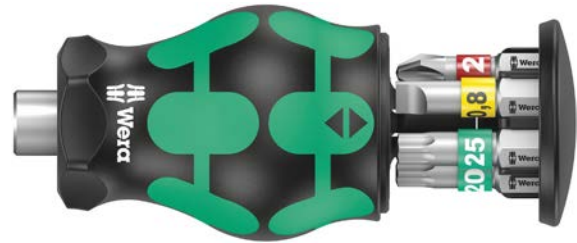

Bit Holder w/ Magnet



Take-it-Easy Tool Finder

| Stubby Multi-Bit Screwdrivers | | | | | | | | |
|-------------------------------|------------------|------------|----------|-------------------|-----------------|-----------------|---|---------|
| Part Number | Number of Pieces | Part Image | Type | Bit Size | Overall Length | Handle Length | Set Includes | Price |
| 05008873001 | 6 | | Phillips | #1 #2 | 2.5in (64mm) | 2.3in (58mm) | (1) Kraftform ergonomic stubby handle with bit storage screwdriver, (6) 1in standard bits (Phillips: #1, #2, torx: T15, T20, T25, slotted: 5.5mm) | \$6d9v: |
| | | | Slotted | 5.5mm | | | | |
| | | | Torx | T15 T20 T25 | | | | |
| 05008874001 | 6 | | Phillips | #1 #2 | 2.5in (64mm) | 2.3in (58mm) | (1) Kraftform ergonomic stubby handle with bit storage screwdriver, (6) 1in standard bits (Phillips: #1, #2, Pozidriv: #1, #2, slotted: 5.5mm, 6.5mm) | \$6d9y: |
| | | | Slotted | 5.5mm, 6.5mm | | | | |
| | | | Pozidriv | #1 #2 | | | | |

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.