

FlatSIGN Signal Lights

WERMA FlatSIGN 691 Series

Features

- Industrial signal light
- Red/Yellow/Green LEDs
- Permanent or blinking (DIP switch selectable)
- 160-degree viewing angle
- Wall mount installation
- Audible alert option with 8
- DIP switch-selectable tones (DC models) or continuous
- (AC models)
- 2-year warranty



FlatSIGN 691 Series Technical Specifications

Part Number	Price	Drawing Link	Description	Voltage	Housing Color	Current	Operating Temp/ Protection	Life Duration	Housing Material	Weight g [oz]	Wiring Diagram	Connection	Agency Approval						
Base Mount																			
69110055	\$;-00cti:	PDF	Permanent or blinking LED	24V AC/DC	Transparent	30mA per tier	-30 to 50°C (-22 to 122°F) IP65 when mounted	max. 50,000h	PC transparent or coated cap/ PC/ABS blend housing	230 [8.11]	Diagram 1	Membrane grommet Cable diameter max. 13mm Terminal screw 0.5 -1.5 mm²	UL file E164155, CE, RoH						
69130055	\$;00ctn:	PDF			Silver														
69110068	\$;-00ctj:	PDF		115-230 VAC	Transparent														
69130068	\$;00cto:	PDF			Silver														
69120055	\$;00ctk:	PDF	Permanent or blinking LED Audible alert (8 selectable tones, 80dB at 1 meter)	24V AC/DC	Transparent											235 [8.29]	Diagram 2		
69140055	\$;00ctp:	PDF			Silver														
69120068	\$;-00ctl:	PDF	Permanent or blinking LED Audible alert (continuous tone, 80dB at 1 meter)	115-230 VAC	Transparent														
69140068	\$;00ctq:	PDF			Silver														

Wiring Diagrams

Diagram 1

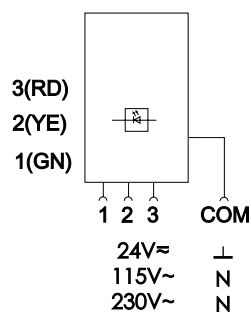


Diagram 2

