

Premium Efficiency motors

... at AutomationDirect prices!



IRONHORSE



AC TC-Frame


AC T-Frame



Premium Efficiency motors that pay for themselves...

IronHorse™ Premium Efficiency AC electric motors meet the requirements of the Energy Independence and Security Act of 2007. Starting at \$155, the MTCP Series gives you a low cost of entry so you get a quicker payback on your investment. All our Ironhorse motors are in stock and ready for **same-day** shipment; if your order is over \$300, you get **free shipping** too!


Also Available

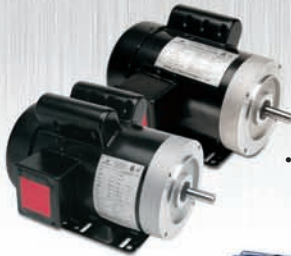

- Single-phase and Three-phase **Rolled steel general purpose motors** up to 2 hp, starting at \$78



- **Inverter-duty AC motors** up to 100 hp, starting at \$141

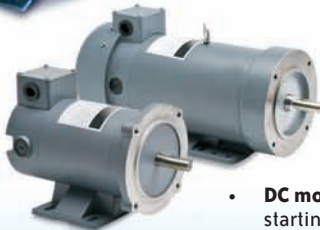

- **DC motors** up to 2 hp, starting at \$131

Features

- Meets or exceeds Premium Efficiency standards
- T-frame motors from 1 to 200 hp; TC-frame models from 1 to 100 hp
- T-frame EPACT motors in 250 and 300 hp also available
- 1200, 1800 and 3600 rpm, electrically reversible
- Ribbed frame design for maximum cooling
- Maintenance free bearings (10hp and below)
- V-ring shaft seals on drive end and on opposite drive end
- Class F insulation
- Class I, Div 2 hazardous locations
- cSAUS certified, CE
- Two-year warranty

www.automationdirect.com/motors

www.automationdirect.com

Go online or call to get complete information, request your free catalog, or place an order.

1-800-633-0405



Order Today, Ships Today!

* See our Web site for details and restrictions.
© Copyright 2011 AutomationDirect, Cumming, GA USA. All rights reserved.



AUTOMATIONDIRECT.com
the #1 value in automation