

AutomationDirect gives you ...

Value in Motion!



AC Servo Systems

start under \$1,000



The **SureServo family of brushless servo systems** from AutomationDirect is fully digital and offers a rich set of features at dynamite prices. Beginners to experienced users can take advantage of this easy-to-use family for as little as \$965* (100W system).

- Eight standard systems from 100 W to 3 kW
- Use with **DirectLOGIC PLCs** or any other host control
- Drives feature **on-board indexer** and adaptive tuning modes
- **Free set-up software**
- **2 year warranty**

CHECK OUT OUR PRICES

Note: All components sold separately.

Servo Systems	AutomationDirect Price/Part Number	US	Allen-Bradley Price/Part Number
Digital Servo Drive	\$479.00 SVA-2040		\$903.45 2096-DS2-005
100W Servo Motor with connectorized Leads	\$319.00 SVC-201		\$639.35 V-300-C-0000A
Breakout Board Kit for CMT Control Interface	\$89.00 ASD-BM-50A		\$192.85 2090-USBK-04401
10' Motor Feedback Cable	\$49.00 SVC-PFL-010		\$144.40 2090-USBK-04401
10' Motor Power Cable	\$29.00 SVC-PPL-010		\$84.00 2090-XXBPY-16503
Configuration Software	FREE SV-PRO2		\$76.95 2090-GWDP03
Complete 1-axis 100W System	\$965.00		\$2,041.00

*SureServo Pro software is FREE when downloaded and is also available for \$9 on a CD.
All prices are U.S. list prices. AutomationDirect prices are April 2008 prices. The Allen-Bradley 100W system consists of part numbers shown in table above with prices from <http://shoprockwellautomation.com> 7/2007.



For in-depth information, visit:

www.automationdirect.com/servos or www.sureservo.com

High-performance Stepper System fits your budget

The **SureStep open-loop stepping system** includes a high-performance microstepping drive, linear power supply, and high-torque motors. Implement practical motion control for as little as \$290!

One-size-fits-all microstepping drive

- Selectable step sizes of 400, 1,000 and 10,000 steps per revolution
- Optically isolated inputs ready for +5 VDC logic from DirectLOGIC PLCs or any other host control
- No software or add-on resistors required for drive configuration (9-position dipswitch setup)

Four standard motors with connectorized pigtail

- 2-phase technology with 200 full steps per revolution (1.8° per full step).


Power Supply

- Operates at least two SureStep stepping systems of any size
- Auxiliary +5 VDC supply

For in-depth information, visit:
www.automationdirect.com/stepper_systems

2-Phase Microstepping Drive

Phase current from 0.4 to 3.5 Amps
(switch selectable, 32 settings)

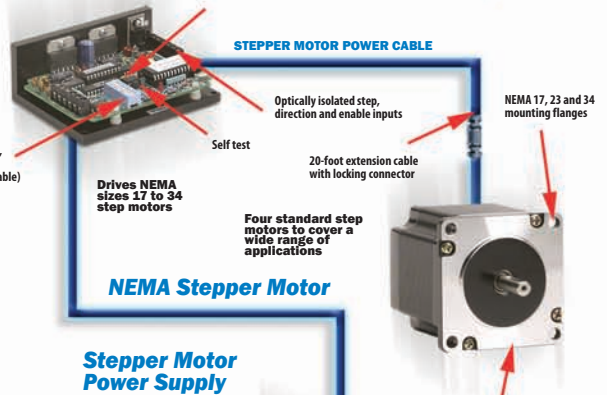

Stepper Motors

Model	Size	Price
STP-MTR-17048	NEMA size 17 83 oz-in	\$19.00
STP-MTR-23055	NEMA size 23 166 oz-in	\$29.00
STP-MTR-23079	NEMA size 23 276 oz-in	\$39.00
STP-MTR-34066	NEMA size 34 434 oz-in	\$99.00

Cable

Model	Price
STP-EXT-020	\$13.00

Drive

Model	Price
STP-DRV-4035	\$149.00

Power Supply

Model	Price
STP-PWR-3204	\$109.00

ORDER BY PHONE



ORDER ONLINE



BEST INDUSTRIAL
AUTOMATION DISTRIBUTOR

IEA Best Brand 2007

AUTOMATIONDIRECT.COM

www.automationdirect.com | 1-800-633-0405