

Save Money, Save Energy

with drives and motors from AutomationDirect

DRIVES



STARTING AT:
\$156.00
GS2-10P2

STARTING AT:
\$99.00
GS1-10P2

STARTING AT:
\$242.00
GS3-21P0

STARTING AT:
\$59.00
GSD3-240-2CL

Variable speed drives can improve your bottom line by reducing your motors' energy consumption. An investment of as little as \$59 can start paying off immediately.

GS1 AC drives (1/4 to 2 hp) offer simple Volts/Hertz control for general purpose applications. Built-in I/O, Modbus communications capability and programmable preset speeds increase their flexibility.

GS2 AC drives (0.5 to 10 hp) feature built-in PID control, dynamic braking and Modbus communications.



DURA DuraPULSE AC drives (1 to 100 hp) add sensorless vector control, a removable keypad that stores up to four different application programs and built-in discrete and analog I/O. Communicate via built-in Modbus or an optional Ethernet connection.




IRONHORSE

Ironhorse DC drives can accommodate 1/50 HP @ 12VDC all the way up to 3HP @ 240VAC. These drives deliver excellent low speed control and stability and are easily configured for your application.

Research, price, and buy at:

www.automationdirect.com/drives

MOTORS

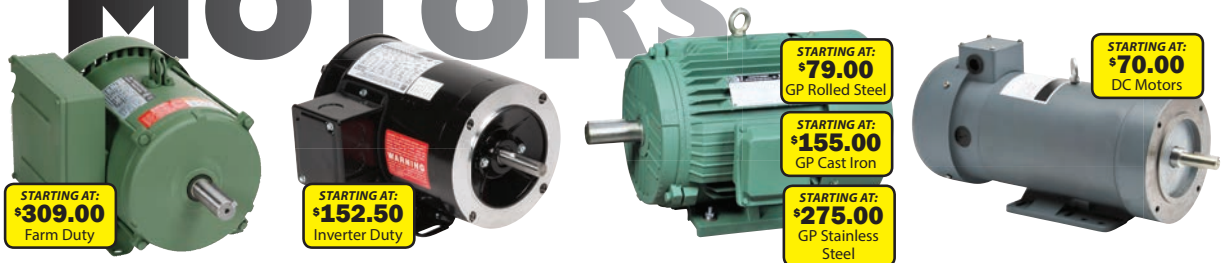

STARTING AT:
\$309.00
Farm Duty

STARTING AT:
\$152.50
Inverter Duty

STARTING AT:
\$79.00
GP Rolled Steel

STARTING AT:
\$155.00
GP Cast Iron

STARTING AT:
\$275.00
GP Stainless Steel

STARTING AT:
\$70.00
DC Motors

With a huge selection of high-quality industrial electric motors and the lowest prices to go with them, we have what you are looking for!

MARATHON ELECTRIC Marathon Electric inverter-duty motors have been carefully selected to be performance matched with our DURApulse and GS series AC drives. They are available in 1/4 to 100 hp with 1200 and 1800 RPM base speeds. Dual 230/460V and 575 VAC models are available and factory-mounted encoders are offered on select models. NEMA Premium Efficiency XRI series from 1 to 10 hp are compliant with Energy Independence and Security Act of 2007.



IRONHORSE

Ironhorse AC motors are available in rolled steel (1/3 to 2 hp), stainless steel (1/3 to 2 hp), cast iron (1 to 300 hp) and farm duty (2 to 5 hp) 1800 RPM models. 1200 and 3600 RPM units are also available in the most popular horsepower ratings. Our premium efficiency models meet current NEMA standards from 1 to 150 hp, and start at \$155.

Ironhorse DC motors are available in TENV and TEFC rolled steel enclosure styles. Their space-saving designs feature a NEMA 56C flange and removable mounting base.

Research, price, and buy at:

www.automationdirect.com/motors

Order Today, Ships Today!



AUTOMATIONDIRECT.com
1-800-633-0405 the #1 value in automation

* See our Web site for details and restrictions. © Copyright 2014 AutomationDirect, Cumming, GA USA. All rights reserved.