

# Stainless Steel AC Motors

... with IP56 environmental rating

## Ready for washdown and harsh environments!

IronHorse™ Stainless Steel AC motors are designed for use in applications where motors are frequently exposed to moisture, humidity, certain chemicals or other washdown environments. (NOT rated for direct contact with food.) All our Ironhorse motors are in stock and ready for **same-day** shipment; if your order is over \$49, you get **free shipping** too!



## IRONHORSE

starting at:  
**\$275.00** U.S.  
MTSS-P33-3BD18R



### Also Available




- **Cast Iron Premium Efficiency motors** up to 200 hp, starting at \$155



- **Single-phase and three-phase rolled steel general purpose motors** up to 2 hp, starting at \$79



- **Marathon Inverter-duty AC motors** up to 100 hp, starting at \$143

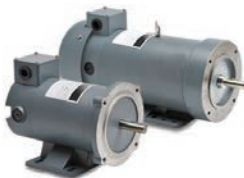

- **DC motors** up to 2 hp, starting at \$133

### Features

- 0.33 to 2 hp, three-phase
- 1800 and 3600 RPM
- Standard NEMA 56C frame
- Available with or without mounting feet
- Totally enclosed, fan cooled
- 304 stainless frame and base;
- 303 stainless motor shaft
- No restriction on mounting orientation
- IP66 cord grip included

Research, price, buy at:

[www.automationdirect.com/motors](http://www.automationdirect.com/motors)



<http://bit.ly/adcmotors>

**Order Today, Ships Today!**

\*See our Web site for details and restrictions. © Copyright 2013 AutomationDirect, Cumming, GA USA. All rights reserved.



**AUTOMATIONDIRECT**.com

1-800-633-0405

the #1 value in automation