



bit Filter-Regulator-Lubricators



Metal Work **bit** combination units come pre-assembled with the most popular modules.

Features

- Includes filter-regulator and lubricator
- Fluid - Compressed air or other inert gases
- Port sizes from 1/8in NPT to 1/4in NPT
- Gauges and/or hex plugs sold separately
- Replaceable 20 micron filter element (5 and 50 micron filters sold separately)
- Max. input pressure 188 psi
- Max. Temperature 122 °F [50 °C]



See www.AutomationDirect.com for a wide variety of fitting options









Metal Work bit Filter-Regulator-Lubricators										
Part No.	Price	Weight (lbs)	Inlet(s) (NPT)	Outlet(s) (NPT)	Drain Bowl	Drain Type	Setpoint Range	Filter	Drawing Link	Manufacturer Specifications
5104008U	\$74.00	0.81	1/8" FNPT	1/8" FNPT	Clear technopolymer	Manual/semi-automatic	0-120 psig	Replaceable 20 micron filter element	PDF	PDF
5104011U	\$74.00	0.81					0-180 psig		PDF	
5204008U	\$74.00	0.75	1/4" FNPT	1/4" FNPT			0-120 psig		PDF	
5204011U	\$74.00	0.75					0-180 psig		PDF	

For additional details see manufacturer's technical specifications.

Recommended Oils - ISO and UNI FD22 (Energol HPL; Spinesso; Mobil DTE; Tellus oil)



bit Accessories


Metal Work bit Accessories							
Item Photo	Part No.	Price	Description	Drawing Link	Manufacturer Specifications	Weight (lbs)	
	<u>9200701</u>	\$3.25	Metal Work mounting bracket, panel, plated steel. For use with Metal Work BIT series air prep components.	<u>PDF</u>		0.08	
	<u>9170201</u>	\$0.75	Metal Work assembly plates, component connection, plated steel. For use with Metal Work BIT series air prep components. Mounting hardware included.	<u>PDF</u>		0.02	
	<u>9170301</u>	\$5.25	Metal Work mounting brackets, panel, plated steel. For use with Metal Work BIT series air prep components. Mounting hardware included.	<u>PDF</u>		0.03	
	<u>9251708</u>	\$6.50	Metal Work particulate filter element, replacement, 5 micron particles, yellow HDPE. For use with Metal Work BIT series filters.	<u>PDF</u>		<u>PDF</u>	0.02
	<u>9251709</u>	\$6.00	Metal Work particulate filter element, replacement, 20 micron particles, white HDPE. For use with Metal Work BIT series filters.	<u>PDF</u>			0.02
	<u>9251710</u>	\$6.50	Metal Work particulate filter element, replacement, 50 micron particles, blue HDPE. For use with Metal Work BIT series filters.	<u>PDF</u>			0.02
	<u>9251712</u>	\$70.00	Metal Work coalescing oil removal filter element, replacement, 0.01 micron particles, borosilicate glass microfiber. For use with Metal Work BIT series filters.	<u>PDF</u>			0.07
	<u>88257C1</u>	\$1.75	Metal Work pneumatic threaded fitting, recessed hex plug, brass body, brass threads, Buna-N O-ring seal(s), G1/8 male BSPP.	<u>PDF</u>	<u>N/A</u>	0.60	

For additional details see manufacturer's technical specifications.



bit Air Distribution Block

Metal Work **bit** air distribution block adds two 1/8" NPT outlets to a modular air prep assembly.

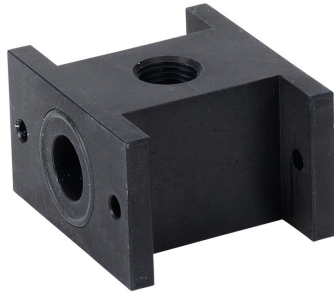

Features

- Fluid - Compressed air or other inert gases
- Max. input pressure 188 psi
- Max. Temperature 122 °F [50 °C]



See www.AutomationDirect.com for a wide variety of fitting options

Metal Work bit Air Distribution Block						
Part No.	Price	Weight (lbs)	Thru Port Diameter (in)	Outlet(s) (NPT)	Drawing Link	Manufacturer Specifications
9100401U	\$13.00	0.14	0.394 (10mm)	(1) 1/4in NPT axial (2) 1/8in NPT vertically opposing	PDF	PDF

For additional details see manufacturer's technical specifications.



bit Air Prep Components

The **bit** line of air prep components from Metal Work offers outstanding performance in a compact, lightweight design. Focus is on value and ease-of-use.

Features

- Lightweight yet durable bodies of technopolymer and nickel-plated brass
- Port sizes from 1/8in NPT to 1/4in NPT

