

Fiberglass In-Line Pushbutton Enclosures - Commander Series



30mm and 22mm with Lift-off Cover

Construction

- Hot compression molded fiberglass reinforced thermoset polyester
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- Recessed captive stainless steel screws
- 300 Series stainless steel used on all external hardware
- Workable material cuts, drills, punches and saws with ease and accuracy
- Optional mounting feet
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Metal grounding strap
- Submersible, non-corrosive environmental design
- Lift-off cover with four cover screws
- Non-conductive, impact resistant, UV resistant
- Temperature Range: -40°F to 250°F (-40°C to 120°C)
- Non-flame propagating
- Subpanel not required
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: Gray



Listings

- UL/cUL File # E64358
- NEMA Ratings 1, 3R, 4X, 6P, 12 (UL508A, UL50 & UL50e)
- CSA Std. C22.2 File # 1, 3R, 4X, 6P, 12 per CSA File# LR069014
- IEC 60529 Ratings IP66, IP67, IP68 per UL file# E362920
- UL 1741 File # E333478
- Temperature Range (-76°F to +274°F) (-60°C to +134°C)
- Flammability Rating UL94-5V
- Self extinguishing non-halogenated, non-flame propagating
- NFPA No. 101 Flame Spread Class A (1)
- Certifications cULus, CSA, IEC, REACH, RoHS
- Outdoor UV Exposure (UL 746C) (f1) Rated
- Plenum Space Rating (UL 2043) Yes



30mm Fiberglass In-Line Pushbutton with Lift-off Cover - Commander Series			
Part Number	Price	# Holes	Enclosure Overall Size HxWxD
C01PB	\$30.50	1	6.63 x 3.81 x 3.89 [168 x 97 x 99]
C02PB	\$31.50	2	6.63 x 3.81 x 3.89 [168 x 97 x 99]
C03PB	\$34.00	3	8.88 x 3.81 x 3.89 [226 x 97 x 99]
C04PB	\$35.00	4	11.13 x 3.81 x 3.89 [283 x 97 x 99]
C05PB	\$40.50	5	13.78 x 3.63 x 3.14 [350 x 92 x 80]
C06PB	\$46.50	6	17.35 x 3.63 x 3.14 [441 x 92 x 80]

*Notes: Subpanels not required.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.
Mounting foot kit (COMTGFTKIT) must be ordered separately.*



C01PB

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

22mm Fiberglass Pushbutton Enclosure with Lift-off Cover - Commander Series			
Part Number	Price	# Holes	Enclosure Overall Size HxWxD
C01PB22	\$30.50	1	6.63 x 3.81 x 3.89 [168 x 97 x 99]
C02PB22	\$31.50	2	6.63 x 3.81 x 3.89 [168 x 97 x 99]
C03PB22	\$34.00	3	6.63 x 3.81 x 3.89 [168 x 97 x 99]
C04PB22	\$35.00	4	8.88 x 3.81 x 3.89 [226 x 97 x 99]
C05PB22	\$40.00	5	11.13 x 3.81 x 3.89 [283 x 97 x 99]
C06PB22	\$46.50	6	11.13 x 3.81 x 3.89 [283 x 97 x 99]

*Notes: Subpanels not required.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.
Mounting foot kit (COMTGFTKIT) must be ordered separately.*




C04PB22


Fiberglass In-Line Pushbutton Enclosures - Commander Series



30mm dimensions

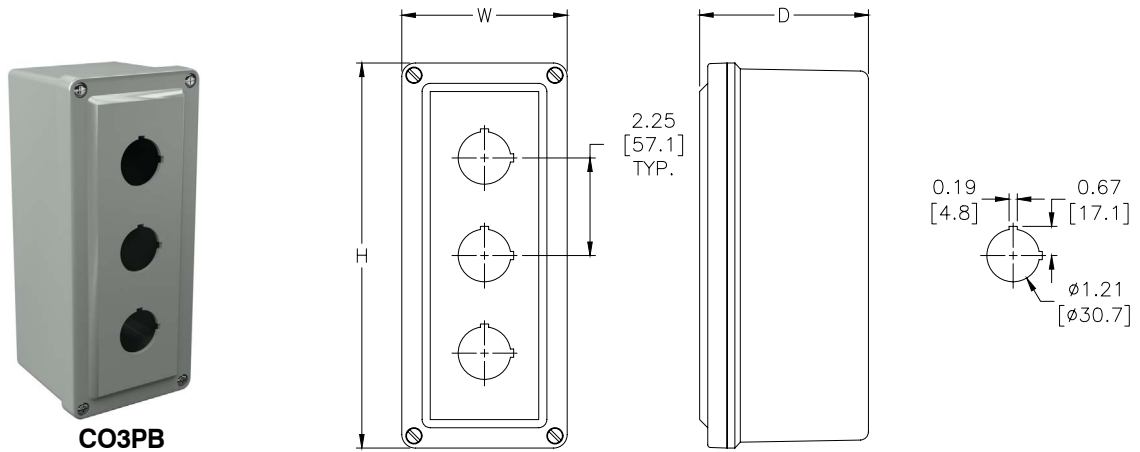

22mm dimensions

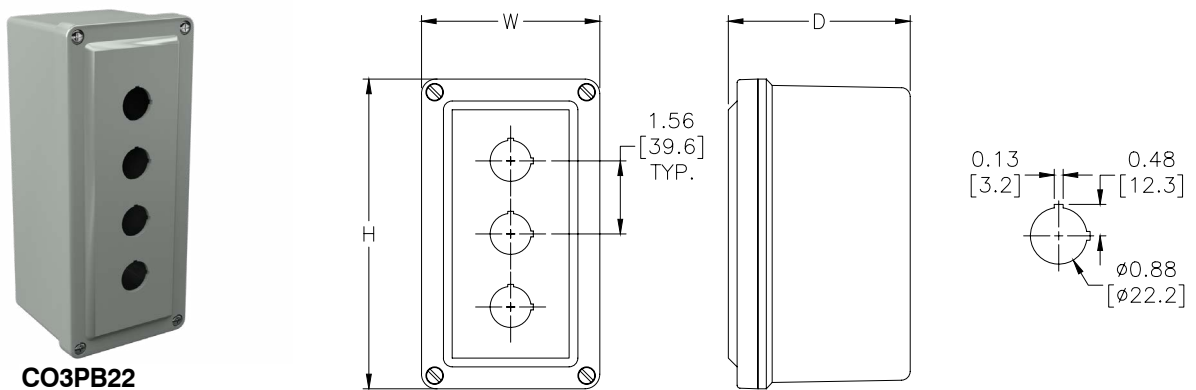

See our website: www.AutomationDirect.com for complete engineering drawings.