


Subpanels for Freedom, MachoBox and Centurion Series Fiberglass Enclosures

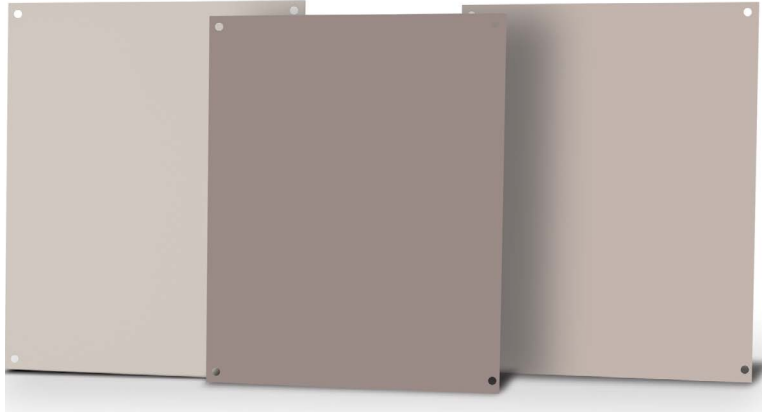

Subpanel Specifications		
Subpanel	Material	Color/Finish
Carbon Steel	Carbon Steel	White polyester powder Finish
Aluminum	3003H14 Aluminum	Mill Finish
Fiberglass	FRP (Fiberglass reinforced polyester)	Gray



Carbon steel subpanels

Fiberglass subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt (lb)
BP64CS	\$5.00	4.88 x 2.88 x 0.075 [124 x 73 x 1.9]	6 x 4	0.3
BP66CS	\$5.00	4.88 x 4.88 x 0.075 [124 x 124 x 1.9]	6 x 6	0.5
BP76CS	\$5.50	6.00 x 4.88 x 0.075 [152 x 124 x 1.9]	7 x 6	0.6
BP86CS	\$6.00	6.75 x 4.88 x 0.075 [152 x 124 x 1.9]	8 x 6	0.8
BP88CS	\$8.50	6.88 x 6.88 x 0.075 [175 x 175 x 1.9]	8 x 8	0.8
BP96CS	\$7.50	8.25 x 4.88 x 0.075 [175 x 124 x 1.9]	9 x 6	0.9
BP108CS	\$9.25	8.75 x 6.88 x 0.075 [225 x 175 x 1.9]	10 x 8	1.3
BP1210CS	\$11.00	10.88 x 8.75 x 0.075 [276 x 225 x 1.9]	12 x 10	2.1
BP1412CS	\$13.25	12.88 x 10.88 x 0.075 [327 x 276 x 1.9]	14 x 12	3.0
BP1614CS	\$17.25	14.88 x 12.88 x 0.075 [378 x 327 x 1.9]	16 x 14	4.1
BP1816CS	\$22.50	16.88 x 14.88 x 0.075 [429 x 378 x 1.9]	18 x 16	5.4
BPM2016CS	\$28.50	18.88 x 14.88 x 0.075 [479 x 378 x 1.9]	20 x 16	6.1
BPM2020CS	\$83.00	18.00 x 18.00 x 0.105 [457 x 457 x 2.7]	20 x 20	9.4
BPM2420CS	\$100.00	22.00 x 18.00 x 0.105 [558 x 457 x 2.7]	24 x 20	11
BPM2424CS	\$123.00	22.00 x 22.00 x 0.105 [558 x 558 x 2.7]	24 x 24	22

Note: Dimensions in inches [millimeters].

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
BP64FG	\$3.50	4.88 x 2.88 x 0.13 [124 x 73 x 3.2]	6 x 4	0.1
BP66FG	\$4.25	4.88 x 4.88 x 0.13 [124 x 124 x 3.2]	6 x 6	0.2
BP86FG	\$5.50	6.88 x 4.88 x 0.13 [175 x 124 x 3.2]	8 x 6	0.3
BP88FG	\$7.50	6.88 x 6.88 x 0.13 [175 x 175 x 3.2]	8 x 8	0.3
BP108FG	\$8.00	8.88 x 6.88 x 0.13 [225 x 175 x 3.2]	10 x 8	0.5
BP1210FG	\$10.50	10.88 x 8.88 x 0.13 [276 x 225 x 3.2]	12 x 10	0.9
BP1412FG	\$14.50	12.88 x 10.88 x 0.13 [327 x 276 x 3.2]	14 x 12	1.0
BP1614FG	\$18.25	14.88 x 12.88 x 0.13 [378 x 327 x 3.2]	16 x 14	0.8
BP1816FG	\$22.50	16.88 x 14.88 x 0.13 [429 x 378 x 3.2]	18 x 16	2.0
BPM2016FG	\$27.50	18.88 x 14.88 x 0.13 [479 x 378 x 3.2]	20 x 16	2.2
BPM2020FG	\$90.00	18.00 x 18.00 x 0.13 [457 x 457 x 3.2]	20 x 20	2.3
BPM2420FG	\$109.00	22.00 x 18.00 x 0.13 [558 x 457 x 3.2]	24 x 20	2.8
BPM2424FG	\$133.00	22.00 x 22.00 x 0.13 [558 x 558 x 3.2]	24 x 24	3.5

Note: Dimensions in inches [millimeters].

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for Freedom, MachoBox and Centurion Series Fiberglass Enclosures



Aluminum subpanels


Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
BP64A	\$5.00	4.88 x 2.88 x 0.081 [124 x 73 x 2.0]	6 x 4	0.1
BP66A	\$5.00	4.88 x 4.88 x 0.081 [124 x 124 2.0]	6 x 6	0.2
BP86A	\$6.00	6.88 x 4.88 x 0.081 [175 x 124] 2.0]	8 x 6	0.3
BP108A	\$9.25	8.88 x 6.88 x 0.081 [225 x 175 x 2.0]	10 x 8	0.5
BP1210A	\$11.00	10.88 x 8.88 x 0.081 [276 x 225 x 2.0]	12 x 10	0.8
BP1412A	\$13.25	12.88 x 10.88 x 0.081 [327 x 276 x 2.0]	14 x 12	1.1
BP1614A	\$17.25	14.88 x 12.88 x 0.081 [378 x 327 x 2.0]	16 x 14	1.5
BP1816A	\$22.50	16.88 x 14.88 x 0.081 [429 x 378 x 2.0]	18 x 16	2.5
BPM2016A	\$28.50	18.88 x 14.88 x 0.081 [479 x 378 x 2.0]	20 x 16	2.4
BPM2020A	\$79.00	18.0 x 18.0 x 0.129 [457 x 457 x 3.3]	20 x 20	3.7
BPM2420A	\$96.00	22.0 x 18.0 x 0.129 [558 x 457 x 3.3]	24 x 20	4.5
BPM2424A	\$118.00	22.0 x 22.0 x 0.129 [558 x 558 x 3.3]	24 x 24	5.4

Note: Dimensions in inches [millimeters].

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Dimensions

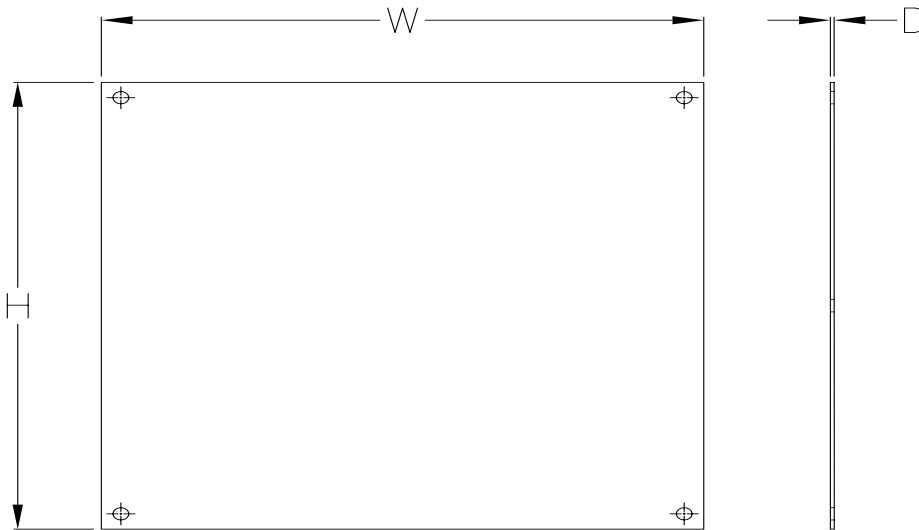

See our website: www.AutomationDirect.com for complete engineering drawings.

Subpanels for Triton Series Fiberglass Enclosures



Carbon steel subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Panel Type	Wt. (lb)
BPT1610CS	\$21.50	13.00 x 8.50 x 0.105 [330 x 216 x 2.7]	16 x 10	Flat	3.3
BPT2016CS	\$37.00	17.00 x 13.00 x 0.105 [432 x 330 x 2.7]	20 x 16	Flat	6.7
BPT2412CS	\$36.00	21.00 x 9.00 x 0.105 [533 x 229 x 2.7]	24 x 12	Flat	8.7
BPT2420CS	\$73.00	21.00 x 17.00 x 0.105 [533 x 432 x 2.7]	24 x 20	Flat	11
BPT2424CS	\$90.00	21.00 x 21.00 x 0.105 [533 x 533 x 2.7]	24 x 24	Flat	13
BPT3020CS	\$93.00	27.00 x 17.00 x 0.105 [686 x 432 x 2.7]	30 x 20	Flat	14
BPT3024CS	\$115.00	27.00 x 21.00 x 0.105 [686 x 533 x 2.7]	30 x 24	Flat	17
BPT3630CS	\$179.00	33.00 x 27.00 x 0.105 [838 x 686 x 2.7]	36 x 30	Flat	27
BPT4836CS	\$260.00	33.00 x 45.00 x 0.105 [838 x 1143 x 2.7]	48 x 36	Formed	41
BPT6036CS	\$322.00	57.00 x 33.00 x 0.105 [1448 x 838 x 2.7]	60 x 36	Formed	60

Note: Dimensions in inches [millimeters].

Subpanel Specifications		
Subpanel	Material	Finish
Carbon Steel	Carbon Steel	White polyester powder Finish
Aluminum	3003H14 Aluminum	Mill Finish


Aluminum subpanels



Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Panel Type	Wt. (lb)
BPT1610A	\$33.00	13.00 x 8.50 x 0.081 [330 x 216 x 2.0]	16 x 10	Flat	1.0
BPT2016A	\$37.00	17.00 x 13.00 x 0.081 [432 x 330 x 2.0]	20 x 16	Flat	2.0
BPT2412A	\$36.00	21.00 x 9.00 x 0.081 [533 x 229 x 2.0]	24 x 12	Flat	4.5
BPT2420A	\$73.00	21.00 x 17.00 x 0.129 [533 x 432 x 3.3]	24 x 20	Flat	4.5
BPT2424A	\$90.00	21.00 x 21.00 x 0.129 [533 x 533 x 3.3]	24 x 24	Flat	5.5
BPT3020A	\$93.00	27.00 x 17.00 x 0.129 [686 x 432 x 3.3]	30 x 20	Flat	5.8
BPT3024A	\$115.00	27.00 x 21.00 x 0.129 [686 x 533 x 3.3]	30 x 24	Flat	7.0
BPT3630A	\$179.00	33.00 x 27.00 x 0.129 [838 x 686 x 3.3]	36 x 30	Flat	11
BPT4836A	\$260.00	33.00 x 45.00 x 0.129 [838 x 1143 x 3.3]	48 x 36	Formed	22
BPT6036A	\$322.00	57.00 x 33.00 x 0.129 [1448 x 838 x 3.3]	60 x 36	Formed	23

Note: Dimensions in inches [millimeters].

Dimensions

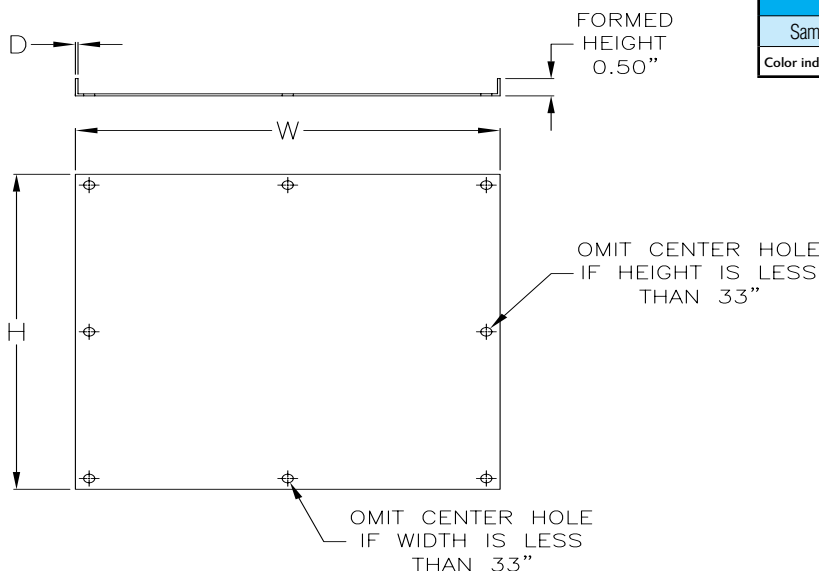

Enclosure Shipping Schedule

Same day	1 - 5 days	1 - 15 days	1 - 20 days
----------	------------	-------------	-------------

Color indicates shipping lead time in business days.

See our website: www.AutomationDirect.com for complete engineering drawings.