


Heartland Series – Polycarbonate Enclosures

Opaque Door with Polycarbonate Latches

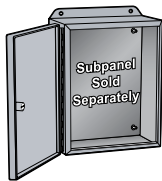

AH12106




Construction

- Polycarbonate with UV inhibitors
- Neoprene rope style gasket.
- Poured polyurethane seamless gasket in select sizes
- 304 stainless steel cover screw
- Panel mounting capability for fixed rear panel
- Rear wall mounting screw size #10-32x3/8 screws
- All threaded brass inserts accept #10-32 screws
- #10-32x5/8 cover screw size
- 20-24in-lbs cover screw torque
- 1/4-20x1/2 mounting feet inserts
- 10-14 in-lbs mounting feet torque
- Polycarbonate with UV inhibitors hinge and latch hardware
- Variable depth side mount capability

Listings

- cULus File E319779
- NEMA Ratings 1, 3R, 4, 4X, 12 [UL508A, UL50 & UL50e]
- IEC 60529 Ratings IP66
- Temperature Range [-40°F to +248°F] [-40°C to +120°C]
- Flammability Rating UL94-5V
- Self Extinguishing non-halogenated, non-flame propagating
- Certifications cULus, CE, REACH
- Outdoor UV Exposure [UL 746C] [f1] Rated

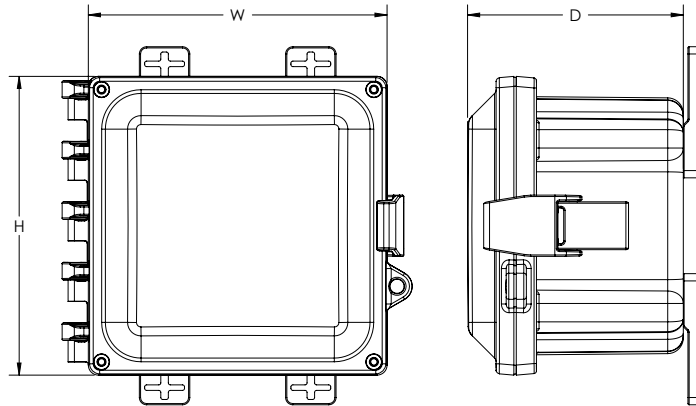

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Heartland Series Polycarbonate Enclosures - Opaque Door with Polycarbonate Latches						
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Aluminum Subpanel
AH664	\$49.00	7.40 x 7.41 x 5.35 [188 x 188 x 136]	2.5 lb	BP66CS	BP66FG	BP66A
AH864	\$52.00	9.40 x 7.40 x 5.32 [239 x 188 x 135]	3.2 lb	BP86CS	BP86FG	BP86A
AH884	\$55.00	9.41 x 9.41 x 5.36 [239 x 239 x 136]	3.8 lb	BP88CS	BP88FG	-
AH1084	\$64.00	11.41 x 9.41 x 5.89 [290 x 239 x 150]	4.3 lb	BP108CS	BP108FG	BP108A
AH1086	\$66.00	11.41 x 9.41 x 7.39 [290 x 239 x 188]	5.2 lb	BP108CS	BP108FG	BP108A
AH10106	\$70.00	11.41 x 11.41 x 6.47 [290 x 290 x 164]	5.7 lb	-	-	BP1010A
AH12106	\$88.00	13.41 x 11.41 x 7.38 [341 x 290 x 187]	6.2 lb	BP1210CS	BP1210FG	BP1210A
AH14126	\$104.00	15.40 x 13.40 x 7.39 [391 x 340 x 188]	8 lb	BP1412CS	BP1412FG	BP1412A
AH16148	\$117.00	17.41 x 15.41 x 9.40 [442 x 391 x 239]	10 lb	BP1614CS	BP1614FG	BP1614A
AH18164	\$127.00	19.40 x 17.41 x 5.41 [493 x 442 x 137]	4.5 lb	BP1816CS	BP1816FG	BP1816A
AH181610	\$138.00	19.41 x 17.41 x 11.41 [493 x 442 x 290]	11.25 lb	BP1816CS	BP1816FG	BP1816A
AH20168	\$203.00	21.41 x 17.41 x 9.47 [544 x 442 x 241]	14 lb	BPM2016CS	BPM2016FG	BPM2016A
AH242410	\$363.00	25.41 x 25.41 x 11.41 [645 x 645 x 290]	23.6 lb	BPM2424CS	BPM2424FG	BPM2424A


Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].

Heartland Series – Polycarbonate Enclosures

Smoked Door with Polycarbonate Latches



AH12106C

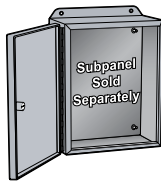


Construction

- Polycarbonate with UV inhibitors
- Neoprene rope style gasket.
- Poured polyurethane seamless gasket in select sizes
- 304 stainless steel cover screw
- Panel mounting capability for fixed rear panel
- Rear wall mounting screw size #10-32x3/8
- All threaded brass inserts accept #10-32 screws
- #10-32x5/8 cover screw size
- 20-24 in-lbs cover screw torque
- 1/4-20x1/2 mounting feet inserts
- 10-14 in-lbs mounting feet torque
- Polycarbonate with UV inhibitors hinge and latch hardware
- Variable depth side mount capability

Listings

- cULus File E319779
- NEMA Ratings 1, 3R, 4, 4X, 12 [UL508A, UL50 & UL50e]
- IEC 60529 Ratings IP66
- Temperature Range [-40°F to +248°F] [-40°C to +120°C]
- Flammability Rating UL94-5V
- Self Extinguishing non-halogenated, non-flame propagating
- Certifications cULus, CE, REACH
- Outdoor UV Exposure [UL 746C] [f1] Rated

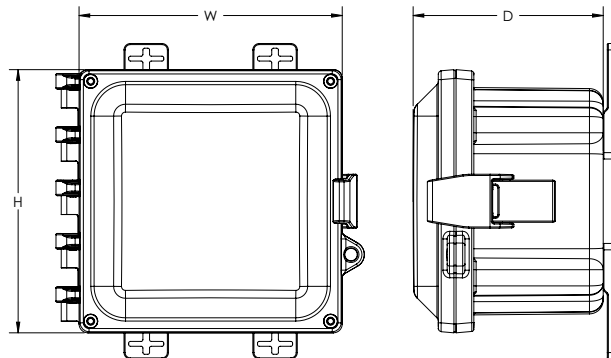

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Heartland Series Polycarbonate Enclosures - Smoked Door with Polycarbonate Latches							
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Aluminum Subpanel	
AH664C	\$53.00	7.40 x 7.41 x 5.35 [188 x 188 x 136]	2.5 lb	BP66CS	BP66FG	BP66A	
AH864C	\$59.00	9.40 x 7.40 x 5.32 [239 x 188 x 135]	3.2 lb	BP86CS	BP86FG	BP86A	
AH884C	\$63.00	9.41 x 9.41 x 5.36 [239 x 239 x 136]	3.75 lb	BP88CS	BP88FG	-	
AH1084C	\$75.00	11.41 x 9.41 x 5.89 [290 x 239 x 150]	4.3 lb	BP108CS	BP108FG	BP108A	
AH1086C	\$78.00	11.41 x 9.41 x 7.39 [290 x 239 x 188]	5.2 lb	BP108CS	BP108FG	BP108A	
AH10106C	\$82.00	11.41 x 11.41 x 6.47 [290 x 290 x 164]	5.7 lb	-	-	BP1010A	
AH12106C	\$98.00	13.41 x 11.41 x 7.38 [341 x 290 x 187]	6.2 lb	BP1210CS	BP1210FG	BP1210A	
AH14126C	\$108.00	15.40 x 13.40 x 7.39 [391 x 340 x 188]	8 lb	BP1412CS	BP1412FG	BP1412A	
AH16148C	\$133.00	17.41 x 15.41 x 9.40 [442 x 391 x 239]	10 lb	BP1614CS	BP1614FG	BP1614A	
AH18164C	\$149.00	19.40 x 17.41 x 5.41 [493 x 442 x 137]	4.5 lb	BP1816CS	BP1816FG	BP1816A	
AH181610C	\$154.00	19.41 x 17.41 x 11.41 [493 x 442 x 290]	11.25 lb	BP1816CS	BP1816FG	BP1816A	
AH20168C	\$237.00	21.41 x 17.41 x 9.47 [544 x 442 x 241]	14 lb	BPM2016CS	BPM2016FG	BPM2016A	
AH242410C	\$389.00	25.41 x 25.41 x 11.41 [645 x 645 x 290]	23.6 lb	BPM2424CS	BPM2424FG	BPM2424A	


Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].

Heartland Series – Polycarbonate Enclosures

Opaque Door with Stainless Steel Latches



AH12106SS

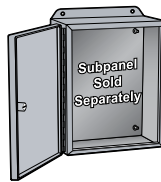

Construction

- Polycarbonate with UV inhibitors
- Neoprene rope style gasket.
- Poured polyurethane seamless gasket in select sizes
- 316 stainless steel cover screws and latches
- Panel mounting capability for fixed rear panel
- Rear wall mounting screw size - #10-32x3/8
- All threaded brass inserts accept #10-32 screws
- #10-32x5/8 cover screw size
- 20-24 in-lbs cover screw torque
- 1/4-20x1/2 mounting feet inserts
- 10-14 in-lbs mounting feet torque
- Variable depth side mount capability


Listings

- cULus File E319779
- NEMA Ratings 1, 3R, 4, 4X, 12 [UL508A, UL50 & UL50e]
- IEC 60529 Ratings IP66
- Temperature Range [-40°F to +248°F] [-40°C to +120°C]
- Flammability Rating UL94-5V
- Self Extinguishing non-halogenated, non-flame propagating
- Certifications cULus, CE, REACH
- Outdoor UV Exposure [UL 746C] [f1] Rated



Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

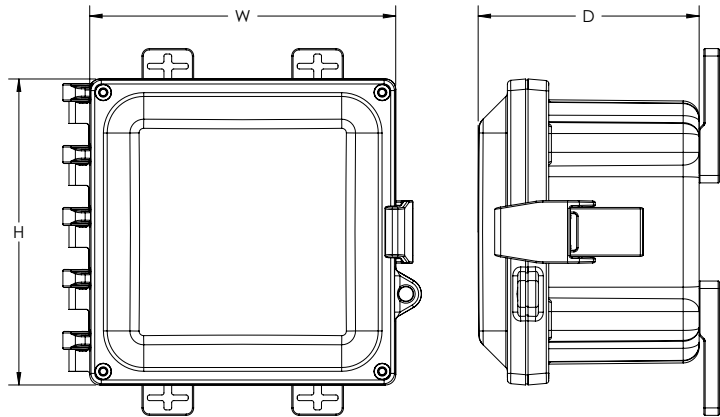

Heartland Series Polycarbonate Enclosures - Opaque Door with Stainless Steel Latches

Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Aluminum Subpanel
AH664SS	\$53.00	7.40 x 7.41 x 5.35 [188 x 188 x 136]	2.5 lb	BP66CS	BP66FG	BP66A
AH864SS	\$56.00	9.40 x 7.40 x 5.32 [239 x 188 x 135]	3.2 lb	BP86CS	BP86FG	BP86A
AH884SS	\$59.00	9.41 x 9.41 x 5.36 [239 x 239 x 136]	3.75 lb	BP88CS	BP88FG	-
AH1084SS	\$69.00	11.41 x 9.41 x 5.89 [290 x 239 x 150]	4.3 lb	BP108CS	BP108FG	BP108A
AH1086SS	\$71.00	11.41 x 9.41 x 7.39 [290 x 239 x 188]	5.2 lb	BP108CS	BP108FG	BP108A
AH10106SS	\$75.00	11.41 x 11.41 x 6.47 [290 x 290 x 164]	5.7 lb	-	-	BP1010A
AH12106SS	\$95.00	13.41 x 11.41 x 7.38 [341 x 290 x 187]	6.2 lb	BP1210CS	BP1210FG	BP1210A
AH14126SS	\$111.00	15.40 x 13.40 x 7.39 [391 x 340 x 188]	8 lb	BP1412CS	BP1412FG	BP1412A
AH16148SS	\$126.00	17.41 x 15.41 x 9.40 [442 x 391 x 239]	10 lb	BP1614CS	BP1614FG	BP1614A
AH18164SS	\$137.00	19.40 x 17.41 x 5.41 [493 x 442 x 137]	4.5 lb	BP1816CS	BP1816FG	BP1816A
AH181610SS	\$149.00	19.41 x 17.41 x 11.41 [493 x 442 x 290]	11.25 lb	BP1816CS	BP1816FG	BP1816A
AH20168SS	\$218.00	21.41 x 17.41 x 9.47 [544 x 442 x 241]	14 lb	BPM2016CS	BPM2016FG	BPM2016A
AH242410SS	\$390.00	25.41 x 25.41 x 11.41 [645 x 645 x 290]	23.6 lb	BPM2424CS	BPM2424FG	BPM2424A


Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].

Heartland Series – Polycarbonate Enclosures

Smoked Door with Stainless Steel Latches



AH12106CSS

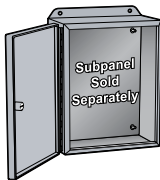


Construction

- Polycarbonate with UV inhibitors
- Neoprene rope style gasket.
- Poured polyurethane seamless gasket in select sizes
- 316 stainless steel cover screw and latches
- Panel mounting capability for fixed rear panel
- Rear wall mounting screw size #10-32x3/8
- All threaded brass inserts accept #10-32 screws
- #10-32x5/8 cover screw size
- 20-24 in-lbs cover screw torque
- 1/4-20x1/2 mounting feet inserts
- 10-14 in-lbs mounting feet torque
- Variable depth side mount capability

Listings

- cULus File E319779
- NEMA Ratings 1, 3R, 4, 4X, 12 [UL508A, UL50 & UL50e]
- IEC 60529 Ratings IP66
- Temperature Range [-40°F to +248°F] [-40°C to +120°C]
- Flammability Rating UL94-5V
- Self Extinguishing non-halogenated, non-flame propagating
- Certifications cULus, CE, REACH
- Outdoor UV Exposure [UL 746C] [f1] Rated

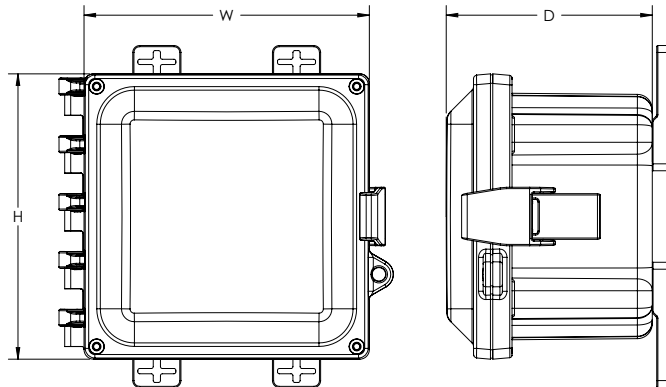

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Heartland Series Polycarbonate Enclosures - Smoked Door with Stainless Steel Latches						
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Aluminum Subpanel
AH664CSS	\$57.00	7.40 x 7.41 x 5.35 [188 x 188 x 136]	2.5 lb	BP66CS	BP66FG	BP66A
AH864CSS	\$64.00	9.40 x 7.40 x 5.32 [239 x 188 x 135]	3.2 lb	BP86CS	BP86FG	BP86A
AH884CSS	\$67.00	9.41 x 9.41 x 5.36 [239 x 239 x 136]	3.75 lb	BP88CS	BP88FG	-
AH1084CSS	\$81.00	11.41 x 9.41 x 5.89 [290 x 239 x 150]	4.3 lb	BP108CS	BP108FG	BP108A
AH1086CSS	\$84.00	11.41 x 9.41 x 7.39 [290 x 239 x 188]	5.2 lb	BP108CS	BP108FG	BP108A
AH10106CSS	\$88.00	11.41 x 11.41 x 6.47 [290 x 290 x 164]	5.7 lb	-	-	BP1010A
AH12106CSS	\$106.00	13.41 x 11.41 x 7.38 [341 x 290 x 187]	6.2 lb	BP1210CS	BP1210FG	BP1210A
AH14126CSS	\$116.00	15.40 x 13.40 x 7.39 [391 x 340 x 188]	8 lb	BP1412CS	BP1412FG	BP1412A
AH16148CSS	\$143.00	17.41 x 15.41 x 9.40 [442 x 391 x 239]	10 lb	BP1614CS	BP1614FG	BP1614A
AH18164CSS	\$160.00	19.40 x 17.41 x 5.41 [493 x 442 x 137]	4.5 lb	BP1816CS	BP1816FG	BP1816A
AH181610CSS	\$165.00	19.41 x 17.41 x 11.41 [493 x 442 x 290]	11.25 lb	BP1816CS	BP1816FG	BP1816A
AH20168CSS	\$255.00	21.41 x 17.41 x 9.47 [544 x 442 x 241]	14 lb	BPM2016CS	BPM2016FG	BPM2016A
AH242410CSS	\$418.00	25.41 x 25.41 x 11.41 [645 x 645 x 290]	23.6 lb	BPM2424CS	BPM2424FG	BPM2424A

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].



Aluminum Swing Panel Kits

- 3003H14 aluminum
- Includes panel, mounts and screws

Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.



AH1210SPK

Aluminum Swing Panel Kits		
Part Number	Price	Fits Enclosure Size [HxW]
AH66SPK	\$29.50	6 x 6in
AH86SPK	\$30.00	8 x 6in
AH88SPK	\$43.00	8 x 8in
AH108SPK	\$32.50	10 x 8in
AH1010SPK	\$47.50	10 x 10in
AH1210SPK	\$35.50	12 x 10in
AH1412SPK	\$38.00	14 x 12in
AH1614SPK	\$41.00	16 x 14in
AH1816SPK	\$43.50	18 x 16in
AH2016SPK	\$46.50	20 x 16in
AH2424SPK	\$49.00	24 x 24in


Heartland Series – Enclosure Accessories



Enclosure Shipping Schedule			
Same day	1 - 5 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Heartland Series Enclosure Latch Kits		
Part Number	Price	Description
AHLKSS	\$8.00	AttaBox enclosure latch, replacement, quick-release, 304 stainless steel. Package of 2. For use with Heartland series enclosures.
AHLK	\$6.25	AttaBox enclosure latch, replacement, quick-release, polycarbonate. Package of 2. For use with Heartland series enclosures.

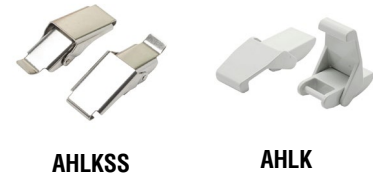

Heartland Series Enclosure Accessory Kit		
Part Number	Price	Description
AHAK	\$7.75	AttaBox mounting feet kit, polycarbonate. For use with Heartland series enclosures. Includes (4) mounting feet and mounting hardware.



Heartland Series Enclosure Pole Mount Kits			
Part Number	Price	For Pole Diameter	Fits Enclosure Width
PM6-8	\$37.50	3 to 12in	6 to 8in
PM10-12	\$40.50	3 to 12in	10 to 12in
PM14-16	\$43.50	3 to 12in	14 to 16in
PM18-24	\$46.50	3 to 12in	18 to 24in



Heartland Series Enclosure Accesories		
Part Number	Price	Description
AHSNK	\$13.00	AttaBox slot nut kit, #10-32 UNF x 0.375in, Phillips pan head, zinc plated steel. Package of 2. For use with Heartland series enclosures. Includes screw and galvanized steel slot nut.
AHTSKSS	\$6.25	AttaBox thumb screw, replacement, #10-32 UNF x 0.375in, stainless steel. Package of 2. For use with Heartland series enclosures. Nylon washer included.
AHTSKAL	\$3.75	AttaBox thumb screw, replacement, #10-32 UNF x 0.375in, aluminum. Package of 2. For use with Heartland series enclosures. Nylon washer included.
RE2PKTBS	\$3.00	AttaBox trilobular self-tapping screw, replacement, #10-14 x 0.375in, Phillips pan head, aluminum. Package of 2. For use with Heartland series enclosures.



Heartland Series Enclosure Swing Panel Mounts		
Part Number	Price	Description
AHSPM	\$18.25	AttaBox Heartland series swing panel bracket, package of 4. For use with Heartland series enclosures. Mounting screws included.



Heartland Series Enclosure Accesories		
Part Number	Price	Description
REAH-V60	\$8.75	AttaBox enclosure vent, 60mm, polycarbonate. Maintains NEMA 3R rating.
REAH-V80	\$11.50	AttaBox enclosure vent, 80mm, polycarbonate. Not UL rated, Enclosure is NEMA 1 when vent is installed
REAVP12	\$25.50	AttaBox enclosure vent gland, 12mm, polycarbonate. Not UL rated, Enclosure is NEMA 1 when vent is installed

