


Cable Ties

Cable ties are a simple, convenient and economical wire management solution. We offer several styles and sizes, as well as tie mounts and installation tools. Our selection, from basic nylon 6.6 ties to UV-rated, and from releasable to ID tag or lashing tie styles, will cover most of your cable tie requirements.

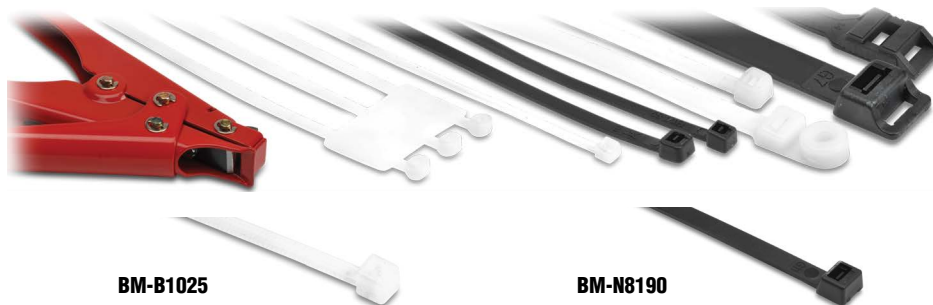

BM-B1025

BM-N8190

Standard Cable Ties

Resistant to oils, grease, solvents and petroleum products

- Material: 6.6 Nylon MIL-M-20693
- Operating Temperature: -40° to 185°F (-40° to 85°C).
- MIL-S-23190
- Self-extinguishing UL 94V-2
- UL Recognized, File E223175 (No UL for Releasable and Marker Tag type)
- All nylon 6.6 ties are CE and RoHS compliant

Cable Ties, Natural Nylon 6.6												
Part Number	Package Quantity	Price	Part Number	Package Quantity	Price	Min. Loop Tensile Strength N (lbs)	Length mm (in.)	Width mm (in.)	Max. Bundle Diameter mm (in.)	Installation Tools	Accessories	
BM-B1025	100	\$2.00	BM-B1025M	1000	\$6.00	80 (18)	100 (3.94)	2.5 (0.10)	18 (0.71)	BM-1100	BM-B0901 BM-N0901 BM-B0902 BM-N0902 BM-B0903 BM-N0903	
BM-B1625	100	\$1.75	BM-B1625M	1000	\$13.00	80 (18)	160 (6.30)	2.5 (0.10)	40 (1.57)			
BM-B2025	100	\$2.00	BM-B2025M	1000	\$14.00	80 (18)	200 (7.90)	2.5 (0.10)	50 (1.97)			
BM-B1436	100	\$2.00	BM-B1436M	1000	\$16.00	180 (40)	140 (5.51)	3.6 (0.14)	33 (1.30)			
BM-B2036	100	\$2.25	BM-B2036M	1000	\$19.00	180 (40)	200 (7.87)	3.6 (0.14)	50 (1.97)			
BM-B2936	100	\$3.25	BM-B2936M	1000	\$28.00	180 (40)	290 (11.42)	3.6 (0.14)	76 (2.99)			
BM-B3736	100	\$5.00	Not available in bulk pack			180 (40)	370 (14.57)	3.6 (0.14)	102 (4.02)			
BM-B1648	100	\$3.00	BM-B1648M	1000	\$21.00	220 (50)	160 (6.30)	4.8 (0.19)	38 (1.50)			BM-B0902 BM-N0902 BM-B0903 BM-N0903
BM-B1948	100	\$3.25	BM-B1948M	1000	\$26.00	220 (50)	190 (7.48)	4.8 (0.19)	43 (1.69)			
BM-B3048	100	\$4.75	BM-B3048M	1000	\$38.00	220 (50)	300 (11.81)	4.8 (0.19)	76 (2.99)			
BM-B3748	100	\$5.50	Not available in bulk pack			220 (50)	370 (14.57)	4.8 (0.19)	102 (4.02)	BM-1101	None	
BM-B3776	100	\$10.00	Not available in bulk pack			540 (120)	370 (14.57)	7.6 (0.30)	102 (4.02)			
BM-B7190	100	\$31.00	Not available in bulk pack			790 (175)	710 (27.95)	9 (0.35)	190 (7.48)			
BM-B8190	100	\$38.00	Not available in bulk pack			790 (175)	810 (31.90)	9 (0.35)	239 (9.41)			

Cable Ties, Black Nylon 6.6												
Part Number	Package Quantity	Price	Part Number	Package Quantity	Price	Min. Loop Tensile Strength N (lbs)	Length mm (in.)	Width mm (in.)	Max. Bundle Diameter mm (in.)	Installation Tools	Accessories	
BM-N1025	100	\$2.00	BM-N1025M	1000	\$6.00	80 (18)	100 (3.94)	2.5 (0.10)	18 (0.71)	BM-1100	BM-B0901 BM-N0901 BM-B0902 BM-N0902 BM-B0903 BM-N0903	
BM-N1625	100	\$1.75	BM-N1625M	1000	\$13.00	80 (18)	160 (6.30)	2.5 (0.10)	40 (1.57)			
BM-N2025	100	\$2.00	Not available in bulk pack			80 (18)	200 (7.90)	2.5 (0.10)	50 (1.97)			
BM-N1436	100	\$2.00	BM-N1436M	1000	\$16.00	180 (40)	140 (5.51)	3.6 (0.14)	33 (1.30)			
BM-N2036	100	\$2.25	Not available in bulk pack			180 (40)	200 (7.87)	3.6 (0.14)	50 (1.97)			
BM-N2936	100	\$3.25	BM-N2936M	1000	\$28.00	180 (40)	290 (11.42)	3.6 (0.14)	76 (2.99)			
BM-N3736	100	\$5.00	Not available in bulk pack			180 (40)	370 (14.57)	3.6 (0.14)	102 (4.02)			
BM-N1648	100	\$2.75	Not available in bulk pack			220 (50)	160 (6.30)	4.8 (0.19)	38 (1.50)			BM-B0902 BM-N0902 BM-B0903 BM-N0903
BM-N1948	100	\$3.50	Not available in bulk pack			220 (50)	190 (7.48)	4.8 (0.19)	43 (1.69)			
BM-N3048	100	\$4.75	BM-N3048M	1000	\$38.00	220 (50)	300 (11.81)	4.8 (0.19)	76 (2.99)			
BM-N3748	100	\$5.50	Not available in bulk pack			220 (50)	370 (14.57)	4.8 (0.19)	102 (4.02)	BM-1101	None	
BM-N3776	100	\$10.00	Not available in bulk pack			540 (120)	370 (14.57)	7.6 (0.30)	102 (4.02)			
BM-N7190	100	\$31.00	Not available in bulk pack			790 (175)	710 (27.95)	9 (0.35)	190 (7.48)			
BM-N8190	100	\$38.00	Not available in bulk pack			790 (175)	810 (31.90)	9 (0.35)	239 (9.41)			

Cable Ties

Lashing Ties

Resistant to oils, grease, solvents and petroleum products.

* BM-N2412, BM-N4912, BM-N7412 are UL recognized, File E223175.

*No UL recognition on BM-N8912 or BM-N1012.

BM-N2412



Lashing Ties, Black Nylon 6.6										
Part Number	Pkg Qty	Price	Part Number	Package Quantity	Price	Min. Loop Tensile Strength N (lbs)	Length mm (in.)	Width mm (in.)	Max. Bundle Diameter mm (in.)	Installation Tools
BM-N2412	100	\$25.00	<i>Not available in bulk pack</i>			1120 (250)	240 (9.45)	12.6 (0.50)	50 (1.97)	Hand install only
BM-N4912	100	\$43.00	<i>Not available in bulk pack</i>			1120 (250)	490 (19.29)	12.6 (0.50)	135 (5.32)	
BM-N7412	100	\$54.00	<i>Not available in bulk pack</i>			1120 (250)	740 (29.13)	12.6 (0.50)	204 (8.03)	
*BM-N8912	100	\$62.00	<i>Not available in bulk pack</i>			1120 (250)	890 (35.04)	12.6 (0.50)	248 (9.76)	
*BM-N1012	100	\$69.00	<i>Not available in bulk pack</i>			1120 (250)	1040 (40.94)	12.6 (0.50)	295 (11.61)	


Releasable Ties

Easy-release tab for removing, repositioning or reuse.

BM-R1576



Releasable Cable Ties, Natural Nylon 6.6										
Part Number	Pkg Qty	Price	Part Number	Pkg Qty	Price	Min. Loop Tensile Strength N (lbs)	Length mm (in.)	Width mm (in.)	Max. Bundle Diameter mm (in.)	Installation Tools
BM-R1576	100	\$7.25	<i>Not available in bulk pack</i>			220 (50)	150 (5.9)	7.6 (0.30)	35 (1.38)	Hand install only
BM-R2076	100	\$8.75	<i>Not available in bulk pack</i>			220 (50)	200 (7.9)	7.6 (0.30)	50 (1.97)	
BM-R3076	100	\$13.00	<i>Not available in bulk pack</i>			220 (50)	300 (11.8)	7.6 (0.30)	80 (3.15)	

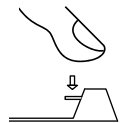

Mounting Head Ties

One-piece mounting head and cable tie. No separate mounting accessory needed.

• UL Recognized, File E223175

BM-H1125



Mounting Head Cable Ties, Natural Nylon 6.6											
Part Number	Pkg Qty	Price	Part Number	Pkg Qty	Price	Min. Loop Tensile Strength N (lbs)w	Length mm (in.)	Width mm (in.)	Mounting Head Hole mm (in.)	Max. Bundle Diameter mm (in.)	Accessories and Installation Tools
BM-H1125	100	\$2.75	<i>Not available in bulk pack</i>			80 (18)	110 (4.33)	2.5 (0.10)	3.25 (0.13) for #5 screw (not included)	22 (0.87)	BM-B0901, BM-N0901 BM-B0902, BM-N0902 BM-B0903, BM-N0903 BM-1100
BM-H2048	100	\$5.25	<i>Not available in bulk pack</i>			220 (50)	200 (7.87)	4.8 (0.19)	5.3 (0.21) for #10 screw (not included)	50 (1.97)	BM-B0902, BM-N0902 BM-B0903, BM-N0903 BM-1100
BM-H3076	100	\$19.00	<i>Not available in bulk pack</i>			540 (121)	305 (12.01)	7.6 (0.30)	5.8 (0.23) for #12 screw (not included)	76 (3.00)	BM-1101

UV-Resistant Ties

For outdoor installation requiring high tensile strength and high locking system resistance. Resistant to oils, grease, atmospheric agents and salt. Using the hand tool P/N BM-1101 is required due to the amount of strength needed for bundling.

- Material: Nylon 12
- Operating Temperature: -22° to 176°F (-30° to 80°C)
- Self-extinguishing UL 94-HB
- CE and RoHS compliant



BM-N1890



BM-N2690


UV Resistant Cable Ties, Black Nylon 12										
Part Number	Pkg Qty	Price	Part Number	Package Quantity	Price	Min. Loop Tensile Strength N (lbs)	Length mm (in.)	Width mm (in.)	Max. Bundle Diameter mm (in.)	Installation Tools
BM-N1890	100	\$14.00	<i>Not available in bulk pack</i>			350 (79)	180 (7.1)	9 (0.35)	43 (1.69)	BM-1101
BM-N2690	100	\$23.00	<i>Not available in bulk pack</i>			500 (112)	265 (10.4)	9 (0.35)	65 (2.56)	
BM-N3690	100	\$26.00	<i>Not available in bulk pack</i>			500 (112)	360 (14.2)	9 (0.35)	93 (3.67)	

Cable Ties

Identification Tags

Write-on marker ties for quick identification of wires and cables.

- Vertical tags in one, two or three-leg options
- Horizontal tags in single top-mount or bottom-mount options

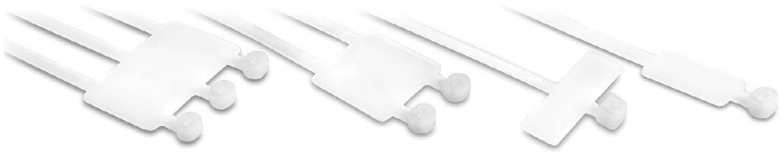

ID Tag Style Cable Ties, Natural Nylon 6.6												
Part Number	Pkg Qty	Price	Part Number	Package Quantity	Price	Min. Loop Tensile Strength N (lbs)	Length mm (in.)	Width mm (in.)	Max. Bundle Dia. mm (in.)	Tag Description mm (in.)	Installation Tools	Mounting Accessories
BM-T12248	100	\$7.75	Not available in bulk pack			220 (50)	220 (8.66)	4.8 (0.19)	54 (2.13)	One leg 13x28 (0.51x1.10) vertical ID tag	BM-1100	BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T22248	100	\$19.00	Not available in bulk pack			220 (50)	220 (8.66)	4.8 (0.19)	54 (2.13)	Two leg 30x28 (1.18x1.10) vertical ID tag		BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T32248	100	\$23.00	Not available in bulk pack			220 (50)	220 (8.66)	4.8 (0.19)	54 (2.13)	Three leg 47x28 (1.85 x1.10) vertical ID tag		BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T23048	100	\$27.00	Not available in bulk pack			220 (50)	300 (11.81)	4.8 (0.19)	76 (2.99)	Two leg 30x28 (1.18x1.10) vertical ID tag		BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T33048	100	\$36.00	Not available in bulk pack			220 (50)	300 (11.81)	4.8 (0.19)	76 (2.99)	Three leg 47x28 (1.85 x1.10) vertical ID tag		BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T11125	100	\$4.50	Not available in bulk pack			80 (18)	110 (4.33)	2.5 (0.10)	18 (0.71)	One leg 20.4x9.1 (0.80x0.36) top-mounted horizontal ID tag		BM-B0901, BM-N0901 BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T21025	100	\$4.50	Not available in bulk pack			80 (18)	100 (3.94)	2.5 (0.10)	18 (0.71)	One leg 25.4x8 (1.0x0.31) bottom-mounted horizontal ID tag		BM-B0901, BM-N0901 BM-B0902, BM-N0902 BM-B0903, BM-N0903
BM-T22025	100	\$6.50	Not available in bulk pack			80 (18)	200 (7.87)	2.5 (0.10)	50 (1.97)	One leg 25.4x8 (1.0x0.31) bottom-mounted horizontal ID tag		BM-B0901, BM-N0901 BM-B0902, BM-N0902 BM-B0903, BM-N0903


Cable Tie Accessories and Tools

Cable Tie Mounts

- 4-way entry for convenient cable tie installation
- Adhesive-mount - for use where drilling

- mounting holes is not possible
- Screw-mount - #6 Flathead screw recommended (not included)

Cable Tie Mounts, Nylon 6.6						
Part Number	Color	Package Quantity	Price	Size mm (in.)	Use with Cable Ties mm(in.)	Mounting Method
BM-B0901	Natural	100	\$7.75	19x190. (0.75x0.75)	3.6 (0.14) wide, max.	Adhesive
BM-N0901	Black	100	\$7.75	19x190. (0.75x0.75)	3.6 (0.14) wide, max.	Adhesive
BM-B0902	Natural	100	\$10.00	28x28 (1.1x1.1)	4.8 (0.19) wide, max.	Adhesive
BM-N0902	Black	100	\$9.50	28x28 (1.1x1.1)	4.8 (0.19) wide, max.	Adhesive
BM-B0903	Natural	100	\$8.25	28x28 (1.1x1.1)	4.8 (0.19) wide, max.	screw
BM-N0903	Black	100	\$8.25	28x28 (1.1x1.1)	4.8 (0.19) wide, max.	screw

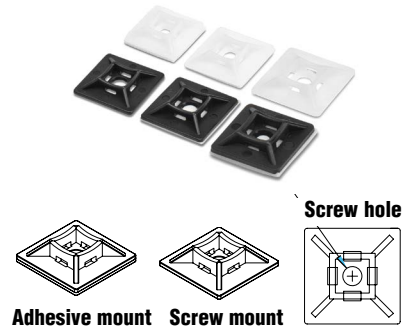

Cable Tie Hand Tools

Cable Tie Installation Tools					
Part Number	Color	Package Quantity	Price	Description	
BM-1100	Blue	1	\$28.00	For use with cable ties from 2.5 mm (0.10 in.) wide to 4.8 mm (0.19 in.) wide	
BM-1101	Red	1	\$33.00	For use with cable ties from 7.6 mm (0.30 in.) wide to 9 mm (0.35 in.) wide	

