





Pliers & Cutting Tools

V-Jaw Pliers

CHANNELLOCK® V-Jaw tongue and groove pliers feature a unique jaw design that creates more points of contact on round stock and tubing for a superior grip. These pliers are built to last with a PERMALOCK® fastener to eliminate nut and bolt failure, a patented reinforcing edge to minimize stress breakage, and laser-hardened teeth to provide a better, longer lasting grip. CHANNELLOCK V-Jaw pliers are forged from high-carbon U.S. steel that is specially coated for ultimate rust prevention.

Features

- V-Jaw design provides more points of contact on pipe, round stock, and tubing
- Reliable PERMALOCK fastener eliminates nut and bolt failure
- Strong 90-degree, laser-hardened teeth for superior grip and longevity
- Undercut tongue and groove won't slip

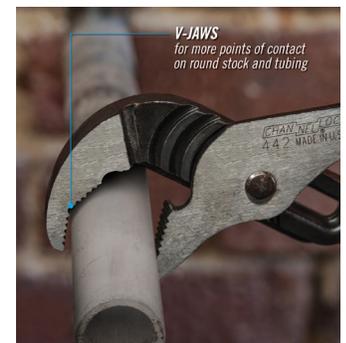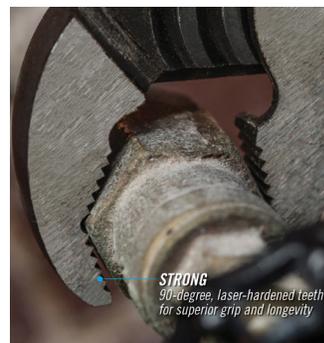

V-Jaw Pliers							
Part Number	Part Image	Overall Length	Jaw Length	Jaw Capacity	Jaw Thickness	Price	
412		6.5in [165mm]	0.81in [20.6mm]	0.94in	0.47in [11.9mm]	\$15.50	
422		9.5in [241mm]	1.12in [28.5mm]	1.5in	0.43in [10.9mm]	\$18.50	
432		10.0in [254mm]	1.37in [34.8mm]	2in	0.50in [12.7mm]	\$20.00	
442		12.0in [305mm]	1.50in [38.1mm]	2.25in	0.51in [13.0mm]	\$21.50	