

CT Series NEMA 3R Single-Door Hinge Cover



CT Series NEMA 3R Single-Door Hinge Cover			
Part Number	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
CTSD121810	\$299.00	14/14	18.38 x 12.38 x 10.06 [467 x 314 x 256]
CTSD182410	\$305.00		24.38 x 18.38 x 10.06 [619 x 467 x 256]
CTSD202010	\$306.00		20.38 x 20.38 x 10.06 [518 x 518 x 256]
CTSD202412	\$315.00		24.38 x 20.38 x 12.06 [619 x 518 x 306]
CTSD242412	\$328.00		24.38 x 24.38 x 12.06 [619 x 619 x 306]
CTSD243012	\$339.00		30.38 x 24.38 x 12.06 [772 x 619 x 306]
CTSD243612	\$359.00	12/12	36.38 x 24.38 x 12.06 [924 x 619 x 306]
CTSD303612	\$420.00		36.38 x 30.37 x 12.08 [924 x 771 x 306]

Note: Dimensions in inches [millimeters]
Letters in table correspond to letters on dimensional drawings.

Applications

Designed as a housing for transformers, recorders, meters, relays and/or for terminal instrumentation. Can also be used as a service or junction box.

Construction

- Manufactured from 14 and 12 gauge carbon steel
- Fully seam welded and ground smooth, with weep hole
- Drip shield
- Lift-off hinges, gasketed doors
- Supplied with non-locking 1/4 turn latch
- Meter seal provisions
- Mounting holes in back
- Supplied with studs in back of enclosure to support optional wood sub panel [available from Hubbell Wiegmann]
- [Uses NIC14 series latches](#)

Finish

- ANSI-61 gray polyester powder light texture inside and out over phosphatized surfaces

Listings

- UL Listed Type 3R [UL file E23553]
- CSA file LL66078




Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Dimensions

in [mm]

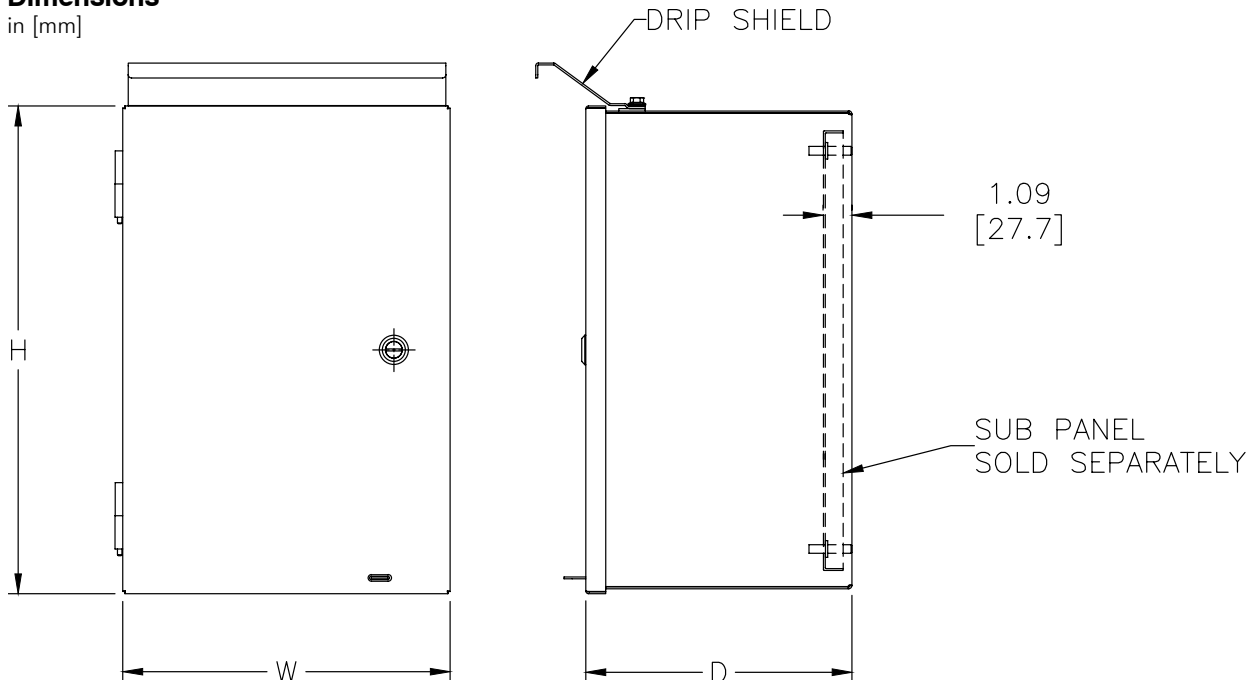

See our website: www.AutomationDirect.com for complete engineering drawings.