

CT Series NEMA 3R Single-Door Hinge Cover



Part Number	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
CTSD121810	\$289.00	14/14	18x12x10 [457x305x254]
CTSD182410	\$294.00		24x18x10 [610x457x254]
CTSD202010	\$295.00		20x20x10 [508x508x254]
CTSD202412	\$304.00		24x20x12 [610x508x305]
CTSD242412	\$316.00		24x24x12 [610x610x305]
CTSD243012	\$327.00		30x24x12 [762x610x305]
CTSD243612	\$347.00	12/12	36x24x12 [914x610x305]
CTSD303612	\$405.00		36x30x12 [914x762x305]

Note: Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.

Applications

Designed as a housing for transformers, recorders, meters, relays and/or for terminal instrumentation. Can also be used as a service or junction box.

Construction

- Manufactured from 14 and 12 gauge carbon steel
- Fully seam welded and ground smooth, with weep hole
- Drip shield
- Lift-off hinges, gasketed doors
- Supplied with non-locking 1/4 turn latch
- Meter seal provisions
- Mounting holes in back
- Supplied with studs in back of enclosure to support optional wood sub panel [available from Hubbell Wiegmann]

Finish

- ANSI-61 gray polyester powder light texture inside and out over phosphatized surfaces

Listings


- UL Listed Type 3R [UL file E23553]
- CSA file LL66078



Enclosure Shipping Schedule
1 -10 days
Color indicates shipping lead time in business days.

Dimensions

in [mm]

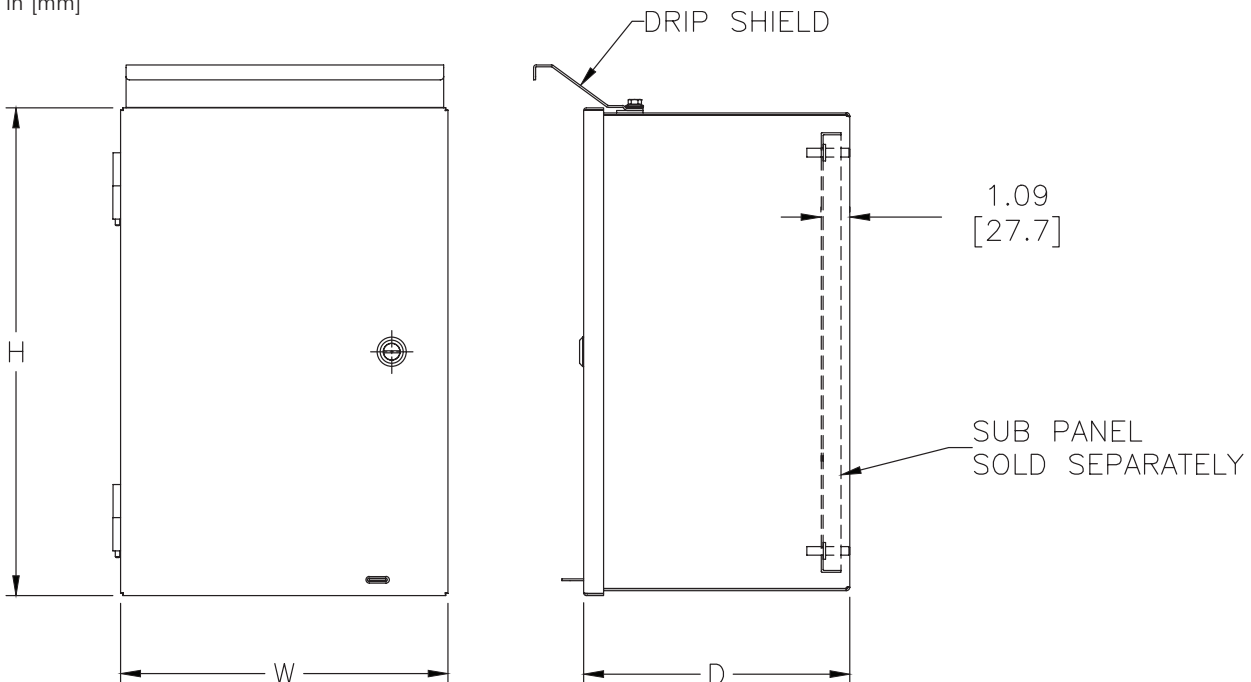

SEE OUR WEBSITE: WWW.AUTOMATIONDIRECT.COM FOR COMPLETE ENGINEERING DRAWINGS.