


011851-00 Cut Sheet

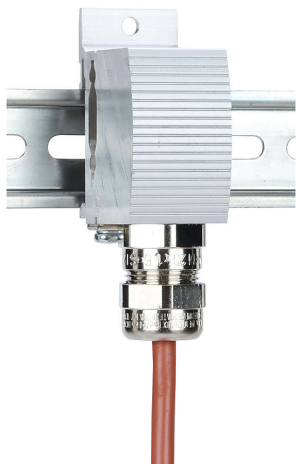

Stego thermostat, hazardous location rated, fixed, N.C. (open on rise) 77 deg F (25 deg C) switch-off, 9 deg F (5K) switching differential, 35mm DIN rail or panel mount, for electrical enclosure climate control.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/011851-00>

Technical Specifications

Brand	Stego
Item	Thermostat
Environmental Requirements	Hazardous location rated
IP Rating	IP66
Setpoint Type	Fixed
Contact 1	N.C. (open on rise) 77 deg F (25 deg C) switch-off
Switching Differential	9 deg F (5K)
Switching Tolerance	+/-5 deg F (+/-3K)
Maximum Switching Capacity	10A at 250 VAC
Connection	3.3ft silicone cable with (3) 18 AWG conductors
Mounting	35mm DIN rail or panel
Application	For electrical enclosure climate control

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/011851-00.pdf>
See store item page for other formats.