


# 011851-00 Cut Sheet

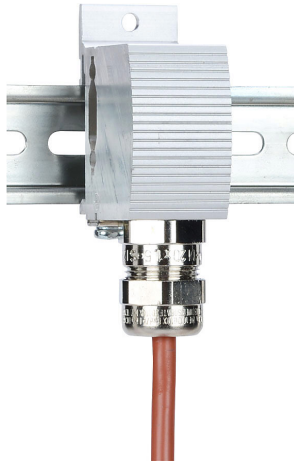

Stego thermostat, hazardous location rated, fixed, N.C. (open on rise) 77 deg F (25 deg C) switch-off, 9 deg F (5K) switching differential, 35mm DIN rail or panel mount, for electrical enclosure climate control.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/011851-00>

## Technical Specifications

<b>Brand</b>	Stego
<b>Item</b>	Thermostat
<b>Environmental Requirements</b>	Hazardous location rated
<b>IP Rating</b>	IP66
<b>Setpoint Type</b>	Fixed
<b>Contact 1</b>	N.C. (open on rise) 77 deg F (25 deg C) switch-off
<b>Switching Differential</b>	9 deg F (5K)
<b>Switching Tolerance</b>	+/-5 deg F (+/-3K)
<b>Maximum Switching Capacity</b>	10A at 250 VAC
<b>Connection</b>	3.3ft silicone cable with (3) 18 AWG conductors
<b>Mounting</b>	35mm DIN rail or panel
<b>Application</b>	For electrical enclosure climate control

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>