


# 016020-00 Cut Sheet

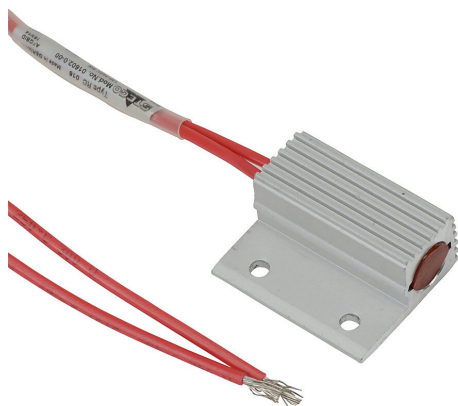

Stego enclosure heater, 8W heating capacity, PTC resistor heating element, 120-240 VAC/VDC operating voltage, panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/016020-00>

## Technical Specifications

Brand	Stego
Item	Enclosure heater
IP Rating	IP54
Heating Capacity	8W
Heating Element	PTC resistor
Operating Voltage	120-240 VAC/VDC
Connection	(2) 18 AWG x 11.8in long wires
Mounting	Panel

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E234324 & E150057
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>