


016240-03 Cut Sheet

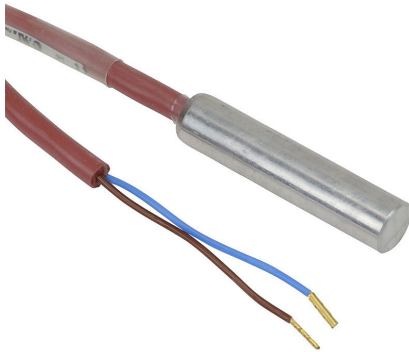

Stego enclosure heater, 5W heating capacity, PTC resistor heating element, 12-24 VAC/VDC operating voltage, panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/016240-03>

Technical Specifications

Brand	Stego
Item	Enclosure heater
IP Rating	IP54
Heating Capacity	5W
Heating Element	PTC resistor
Operating Voltage	12-24 VAC/VDC
Connection	(2) 22 AWG x 19.7in long wires
Mounting	Panel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E234324 & E150057
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/016240-03.pdf>
See store item page for other formats.