


018000-01 Cut Sheet



Stego Filter Fan intake fan, side mount, 14 CFM, 115 VAC operating voltage, G4 (coarse) filter mat, NEMA 12, indoor use only, 3.82 x 3.82in cutout, RAL 7035 light gray.

For complete product information, please see this item on our store at the following link:

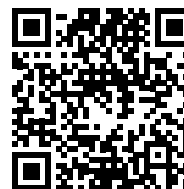

<https://www.automationdirect.com/pn/018000-01>

Technical Specifications

Brand	Stego
Series	Filter Fan
Airflow Direction	Intake
Item	Fan
Mounting	Side
With Air Flaps	No
Filter Media	G4 (coarse) filter mat
Free Airflow	14 CFM
Airflow with Grill and Filter(s)	11 CFM
Operating Voltage	115 VAC
Frequency	60 Hz
Power Consumption	13W

Current Draw	160 mA
Electrical Connection	(2) AWG 14 x 4in long wires with cage clamps
Maximum Static Pressure	18Pa
Operating Temperature	14 to 158 deg F
Average Noise Level	31 dBA
NEMA Rating	12
Application	Indoor use only
IP Rating	IP54 (IP55 with optional M5 filter media)
Enclosure Cutout	3.82 x 3.82in
Color	RAL 7035 light gray
Includes	Optional mounting screws
Additional Information	Purchase exhaust grille separately. Fan will also safely operate at 50Hz, but with reduced airflow. Contact manufacturer for 50Hz performance data

Agency Approvals

UL Listed File #	None
UL Recognized File #	E234324
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None