


086340-00 Cut Sheet

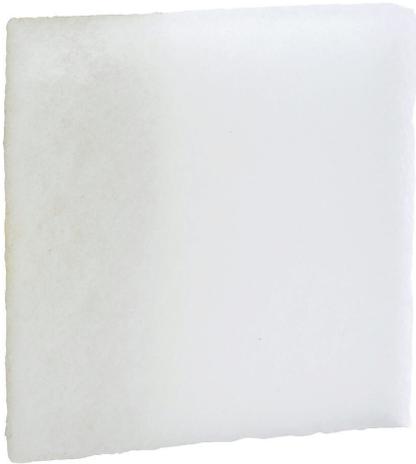

Stego filter, replacement, 4.64 x 4.64in, synthetic fiber, washable, G3 (coarse). Package of 5. For use with 4.88 x 4.88in Stego Filter Fan Plus fans and intake grilles and 4.92 x 4.92in Stego Filter Fan fans and exhaust grilles.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/086340-00>

Technical Specifications

Brand	Stego
Item	Filter
Replacement	Yes
Size	4.64 x 4.64in
Filter Element	Synthetic fiber
Washable	Yes
Average Arrestance	84%
Filter Density	200 g/m2

Filter Rating	G3 (coarse)
Other Filter Characteristics	Temperature resistant to 212F, moisture resistant to 100% RH
Quantity per Pack	5
For Use With	4.88 x 4.88in Stego Filter Fan Plus fans and intake grilles and 4.92 x 4.92in Stego Filter Fan fans and exhaust grilles

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document