


# 086340-00 Cut Sheet

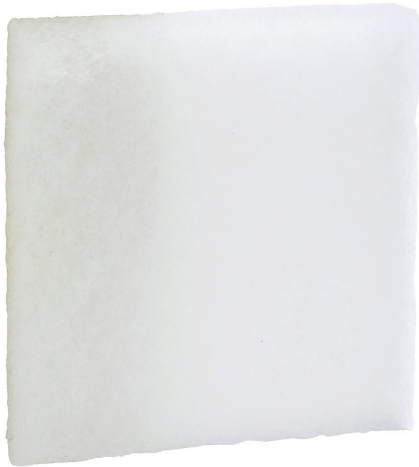

Stego filter, replacement, 4.64 x 4.64in, synthetic fiber, washable, G3 (coarse). Package of 5. For use with 4.88 x 4.88in Stego Filter Fan Plus fans and intake grilles and 4.92 x 4.92in Stego Filter Fan fans and exhaust grilles.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/086340-00>

## Technical Specifications

<b>Brand</b>	Stego
<b>Item</b>	Filter
<b>Replacement</b>	Yes
<b>Size</b>	4.64 x 4.64in
<b>Filter Element</b>	Synthetic fiber
<b>Washable</b>	Yes
<b>Average Arrestance</b>	84%
<b>Filter Density</b>	200 g/m2
<b>Filter Rating</b>	G3 (coarse)
<b>Other Filter Characteristics</b>	Temperature resistant to 212F, moisture resistant to 100% RH
<b>Quantity per Pack</b>	5
<b>For Use With</b>	4.88 x 4.88in Stego Filter Fan Plus fans and intake grilles and 4.92 x 4.92in Stego Filter Fan fans and exhaust grilles

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>