


# 100222019524002 Cut Sheet

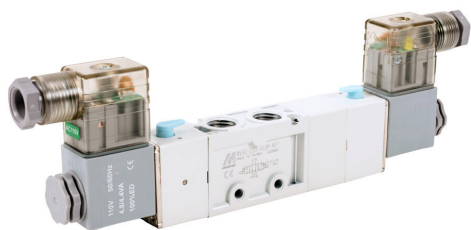

Mindman pneumatic solenoid valve, 5-port (4-way), 3-position, center exhaust, double solenoid, 1/4in female NPT inlet(s), (2) 1/4in female NPT outlet(s), (2) 1/8in female NPT exhaust(s), Cv=0.89, 110 VAC, 4.4 VA, 11mm DIN style wiring plug.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/100222019524002>

## Technical Specifications

<b>Brand</b>	Mindman
<b>Item</b>	Valve
<b>Working Fluid</b>	Air
<b>Valve Type</b>	Solenoid directional control
<b>Port Quantity</b>	5-port (4-way)
<b>Number Of Positions</b>	3
<b>Valve Configuration</b>	Center exhaust
<b>Action</b>	Double solenoid
<b>Body Material</b>	Aluminum
<b>Body Width</b>	22mm
<b>Seal Material</b>	Nitrile
<b>Mounting</b>	Optional manifold
<b>Inlet Port</b>	1/4in female NPT

<b>Outlet Port</b>	(2) 1/4in female NPT
<b>Exhaust Port</b>	(2) 1/8in female NPT
<b>Manual Override Type</b>	Locking
<b>Flow Coefficient</b>	0.89
<b>Maximum Operating Pressure</b>	116 psi
<b>Minimum Operating Pressure</b>	44 psi
<b>Working Fluid Temperature</b>	-5 to +50 °C (23-122 °F)
<b>Operating Voltage</b>	110 VAC
<b>Power Rating</b>	4.4 VA
<b>Electrical Connection</b>	11mm DIN style wiring plug
<b>Indicating Type</b>	LED indication
<b>Manufacturer Part Number</b>	MVSC-220-4E2R-AC110-L-NPT

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/100222019524002.pdf>  
See store item page for other formats.