


100230015524004 Cut Sheet

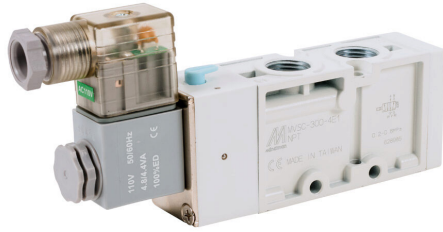

Mindman pneumatic solenoid valve, 5-port (4-way), 2-position, single solenoid spring return, 3/8in female NPT inlet(s), (2) 3/8in female NPT outlet(s), (2) 3/8in female NPT exhaust(s), Cv=1.94, 110 VAC, 4.4 VA, 11mm DIN style wiring plug.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/100230015524004>

Technical Specifications

Brand	Mindman	Outlet Port	(2) 3/8in female NPT
Item	Valve	Exhaust Port	(2) 3/8in female NPT
Working Fluid	Air	Manual Override Type	Locking
Valve Type	Solenoid directional control	Flow Coefficient	1.94
Port Quantity	5-port (4-way)	Maximum Operating Pressure	116 psi
Number Of Positions	2	Minimum Operating Pressure	29 psi
Action	Single solenoid spring return	Working Fluid Temperature	-5 to +50 °C (23-122 °F)
Body Material	Aluminum	Operating Voltage	110 VAC
Body Width	30mm	Power Rating	4.4 VA
Seal Material	Nitrile	Electrical Connection	11mm DIN style wiring plug
Mounting	Optional manifold	Indicating Type	LED indication
Inlet Port	3/8in female NPT	Manufacturer Part Number	MVSC-300-4E1-AC110-L-NPT

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/100230015524004.pdf>
See store item page for other formats.