


101702T Cut Sheet

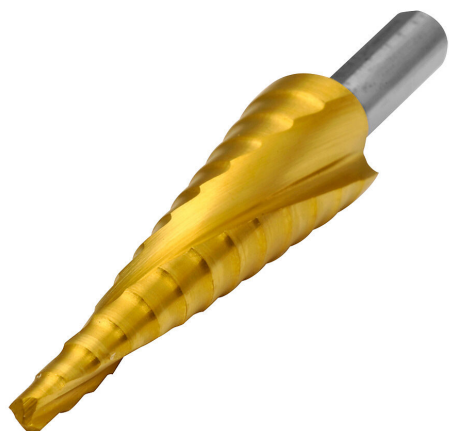

RUKO step drill bit, 13 steps, 1/8in, 5/32in, 3/16in, 7/32in, 1/4in, 9/32in, 5/16in, 11/32in, 3/8in, 13/32in, 7/16in, 15/32in and 1/2in, split point, high-speed steel (HSS), Titanium-Nitride (TiN) coated finish, 1/4in diameter 3-surface shank.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/101702T>

Technical Specifications

| | |
|-----------------------------|--|
| Brand | RUKO |
| Item | Drill bit |
| Replacement | No |
| Drill Bit Type | Step |
| Step Drill Size | #1 |
| Number Of Hole Sizes | 13 |
| Drill Bit Size | 1/8in, 5/32in, 3/16in, 7/32in, 1/4in, 9/32in, 5/16in, 11/32in, 3/8in, 13/32in, 7/16in, 15/32in and 1/2in |
| Material | High-speed steel (HSS) |

| | |
|-----------------------|--|
| Finish | Titanium-Nitride (TiN) coated |
| Point Angle | 118 degrees |
| Point Cut | Split |
| Shank Type | 1/4in diameter 3-surface |
| Overall Length | 3.1in (79mm) |
| For Use On | Steel, brass, plastic, stainless steel, bronze and cast iron |
| Application | Hole cutting |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |