


# 101702 Cut Sheet

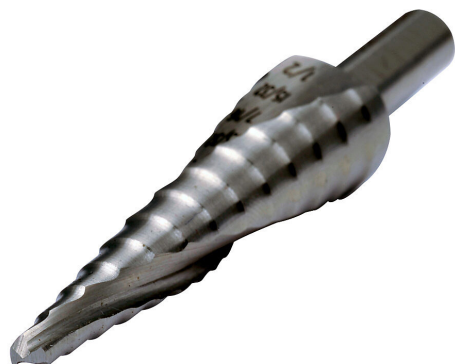

RUKO step drill bit, 13 steps, 1/8in, 5/32in, 3/16in, 7/32in, 1/4in, 9/32in, 5/16in, 11/32in, 3/8in, 13/32in, 7/16in, 15/32in and 1/2in, split point, high-speed steel (HSS), bright finish, 1/4in diameter 3-surface shank.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/101702>

## Technical Specifications

<b>Brand</b>	RUKO
<b>Item</b>	Drill bit
<b>Replacement</b>	No
<b>Drill Bit Type</b>	Step
<b>Step Drill Size</b>	#1
<b>Number Of Hole Sizes</b>	13
<b>Drill Bit Size</b>	1/8in, 5/32in, 3/16in, 7/32in, 1/4in, 9/32in, 5/16in, 11/32in, 3/8in, 13/32in, 7/16in, 15/32in and 1/2in
<b>Material</b>	High-speed steel (HSS)

<b>Finish</b>	Bright
<b>Point Angle</b>	118 degrees
<b>Point Cut</b>	Split
<b>Shank Type</b>	1/4in diameter 3-surface
<b>Overall Length</b>	3.1in (79mm)
<b>For Use On</b>	Aluminum, brass, plastic, steel, bronze and cast iron
<b>Application</b>	Hole cutting

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/101702.pdf>  
See store item page for other formats.