


106031103034001 Cut Sheet

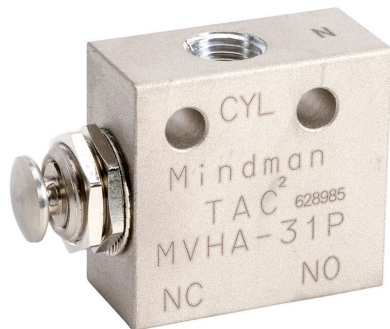

Mindman pneumatic manual valve, 3-port (3-way), 2-position, N.O./N.C., pushbutton, spring return, 1/8in female NPT inlet(s), 1/8in female NPT outlet(s), 1/8in female NPT exhaust(s), Cv=0.25, through panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/106031103034001>

Technical Specifications

| | |
|----------------------------|----------------------------|
| Brand | Mindman |
| Item | Valve |
| Working Fluid | Air |
| Valve Type | Manual directional control |
| Port Quantity | 3-port (3-way) |
| Number Of Positions | 2 |
| Valve Configuration | N.O./N.C. |
| Operator Type | Pushbutton |
| Action | Spring return |
| Body Material | Aluminum |
| Seal Material | Nitrile |

| | |
|-----------------------------------|--------------------------|
| Mounting | Through panel |
| Inlet Port | 1/8in female NPT |
| Outlet Port | 1/8in female NPT |
| Exhaust Port | 1/8in female NPT |
| Flow Coefficient | 0.25 |
| Maximum Operating Pressure | 130 psi |
| Minimum Operating Pressure | 0 psi |
| Working Fluid Temperature | -5 to +60 °C (23-140 °F) |
| Includes | Mounting hardware |
| Manufacturer Part Number | MVHA-31P-NPT |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/106031103034001.pdf>
See store item page for other formats.