


# 106041205034001 Cut Sheet

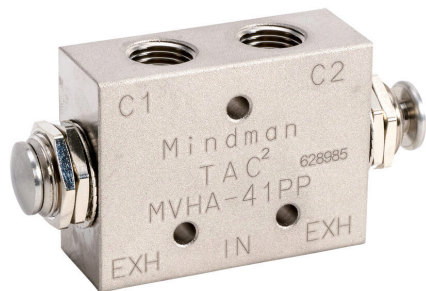

Mindman pneumatic manual valve, 5-port (4-way), 2-position, double pushbutton, 1/8in female NPT inlet(s), (2) 1/8in female NPT outlet(s), (2) M5 x 0.8 female ISO exhaust(s), Cv=0.31, through panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/106041205034001>

## Technical Specifications

|                            |                            |
|----------------------------|----------------------------|
| <b>Brand</b>               | Mindman                    |
| <b>Item</b>                | Valve                      |
| <b>Working Fluid</b>       | Air                        |
| <b>Valve Type</b>          | Manual directional control |
| <b>Port Quantity</b>       | 5-port (4-way)             |
| <b>Number Of Positions</b> | 2                          |
| <b>Operator Type</b>       | Double pushbutton          |
| <b>Body Material</b>       | Aluminum                   |
| <b>Seal Material</b>       | Nitrile                    |
| <b>Mounting</b>            | Through panel              |

|                                   |                          |
|-----------------------------------|--------------------------|
| <b>Inlet Port</b>                 | 1/8in female NPT         |
| <b>Outlet Port</b>                | (2) 1/8in female NPT     |
| <b>Exhaust Port</b>               | (2) M5 x 0.8 female ISO  |
| <b>Flow Coefficient</b>           | 0.31                     |
| <b>Maximum Operating Pressure</b> | 130 psi                  |
| <b>Minimum Operating Pressure</b> | 0 psi                    |
| <b>Working Fluid Temperature</b>  | -5 to +60 °C (23-140 °F) |
| <b>Includes</b>                   | Mounting hardware        |
| <b>Manufacturer Part Number</b>   | MVHA-41PP-NPT            |

## Agency Approvals

|                             |   |
|-----------------------------|---|
| <b>UL Listed File #</b>     | None  |
| <b>UL Recognized File #</b> | None  |
| <b>UL Hazardous File #</b>  | None  |
| <b>CE</b>                   | None  |
| <b>CSA File #</b>           | None  |
| <b>RoHS Status</b>          | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a>                              |
| <b>Other</b>                | <a href="#">RoHS Statement</a>                                      |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/106041205034001.pdf>  
See store item page for other formats.