


12MJ-12FJX90 Cut Sheet

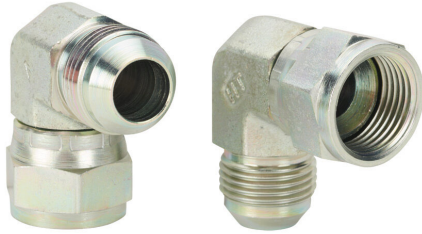

HY-TECH hydraulic fluid adapter, elbow, plated steel body, (1)
-12 male JIC 37 deg and (1) -12 female JIC 37 deg. Package of 2.

For complete product information, please see this item on our
store at the following link:



<https://www.automationdirect.com/pn/12MJ-12FJX90>

Technical Specifications

Brand	HY-TECH
Item	Adapter
Working Fluid	Hydraulic fluid
Adapter Type	Elbow
Body Material	Plated steel
Thread Material	Plated steel
Measurement Type	SAE
Connection	(1) -12 male JIC 37 deg and (1) -12 female JIC 37 deg
Quantity per Pack	2

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document